

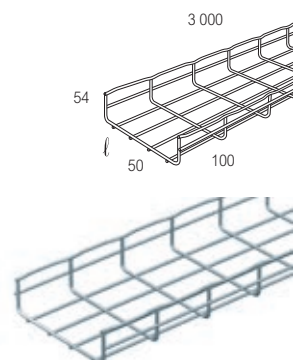
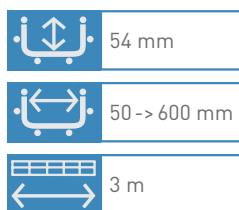


CF 54 draadgoten

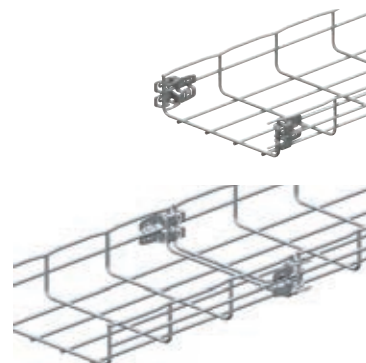

FCFA 54 draadgoten met voorgemonteerde koppelingen

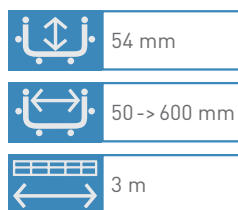

Technische gegevens: www.ecatalog.be
Voldoet aan norm IEC/EN61537

Ref. CF 54 standaard

Ref.	EZ	EZ+	Breedte (mm)	Gewicht KG/m
CM000061	CM000062	CF 54/50	50	0,63
CM000071	CM000072	CF 54/100	100	0,78
CM000081	CM000082	CF 54/150	150	1,04
CM000091	CM000092	CF 54/200	200	1,36
CM000101	CM000102	CF 54/300	300	2,04
CM000201	CM000202	CF 54/400	400	3,05
CM000301	CM000302	CF 54/500	500	3,47
CM000401	CM000402	CF 54/600	600	3,90

Ref. CF 54 standaard

Ref.	GC	ZnAl	Breedte (mm)	Gewicht KG/m
CM000063	CM000066	CF 54/50	50	0,63
CM000073	CM000076	CF 54/100	100	0,78
CM000083	CM000086	CF 54/150	150	1,04
CM000093	CM000096	CF 54/200	200	1,36
CM000103	CM000106	CF 54/300	300	2,04
CM000203	CM000206	CF 54/400	400	3,05
CM000303	CM000306	CF 54/500	500	3,47
CM000403	CM000406	CF 54/600	600	3,90


Ref. CF 54 RVS

Ref.	304L	316L	Breedte (mm)	Gewicht KG/m
CM000068	CM000064	CF 54/50	50	0,63
CM000078	CM000074	CF 54/100	100	0,78
CM000088	CM000084	CF 54/150	150	1,04
CM000098	CM000094	CF 54/200	200	1,36
CM000108	CM000104	CF 54/300	300	2,04
CM000208	CM000204	CF 54/400	400	3,05
CM000308	CM000304	CF 54/500	500	3,47
CM000408	CM000404	CF 54/600	600	3,90

Ref. FCFA 54 met voorgemonteerde koppelingen

Ref.	EZ	Breedte (mm)	Gewicht KG/m
Vanaf breedte 50 mm inclusief bodemkoppeling			
CM082061	FC 54/50	50	0,64
CM082071	FC 54/100	100	0,78
CM082081	FC 54/150	150	1,05
CM082091	FC 54/200	200	1,37
CM082101	FC 54/300	300	2,3
CM082201	FC 54/400	400	2,96
CM082301	FC 54/500	500	3,5
CM082401	FC 54/600	600	3,78

 Snelkoppeling **blz. 868**



Deksels en scheidingschotten **blz. 871**

