

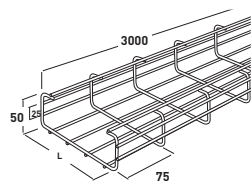
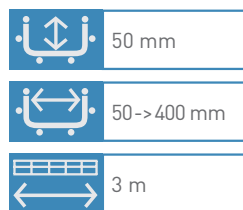


CFC 50, CF 150 draadgoten

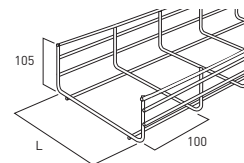

HDF 105 draadgoten

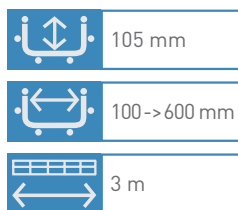


Technische gegevens: www.ecatalog.be
Voldoet aan norm IEC/EN61537

Réf.			CFC 50
GC	304L	316L	
CM004063	CM004068	CM004064	CFC 50
CM004073	CM004078	CM004074	CFC 100
CM004093	CM004098	CM004094	CFC 200
CM004103	CM004108	CM004104	CFC 300
CM004203	CM004208	CM004204	CFC 400

Breedte (mm)	Gewicht KG/m
50	1,30
100	1,40
200	1,80
300	2,20
400	2,40

Réf.		HDF 105
EZ	GC	
CM450621	CM450623	HDF 105/100
CM450631	CM450633	HDF 105/150
CM450641	CM450643	HDF 105/200
CM450661	CM450663	HDF 105/300
CM450681	CM450683	HDF 105/400
CM450701	CM450703	HDF 105/500
CM450721	CM450723	HDF 105/600

Breedte (mm)	Gewicht KG/m
100	2,48
150	2,59
200	2,70
300	3,83
400	4,57
500	4,88
600	5,69

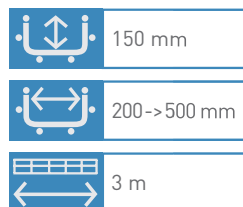

Réf.		HDF 105 RVS
316L		
CM450624		HDF 105/100
CM450634		HDF 105/150
CM450644		HDF 105/200
CM450664		HDF 105/300
CM450684		HDF 105/400
CM450704		HDF 105/500
CM450724		HDF 105/600

Breedte (mm)	Gewicht KG/m
100	2,48
150	2,59
200	2,70
300	3,83
400	4,57
500	4,88
600	5,69

Réf.			CF 150 standaard
EZ	GC		
CM000951	CM000953	CF 150/200	
CM000961	CM000963	CF 150/300	
CM000971	CM000973	CF 150/400	
CM001021	CM001023	CF 150/500	

Breedte (mm)	Gewicht KG/m
200	3,10
300	3,50
400	3,90
500	4,40

Snelkoppeling **blz. 868**



Toebereiden **blz. 871**