

Keuzetabel koppelingen Cablofil

bochten en andere aftakkingen

■ Koppelplaat Faslock auto

CF 30 - CF 54 - CF 105 - CF 150 100 - 600 mm


Faslock S 100 t/m 200mm		GS EZ	CM558340		
		ZnNi	CM558346	316L	CM558344
Faslock XL 300 t/m 600mm		GS EZ	CM558320		
		ZnNi	CM558326	316L	CM558324



■ Snelkoppeling CE 25 - CE 30

CF 30 - CF 54 - CF 105 - CF 150 50 - 600 mm


KITASSTR CE 25+CE 30+BTRCC		GS EZ	CM558081		
		ZnMg	CM350424		
KITASSVS CE 25VS+CE 30ES		GS EZ	CM558071		
		ZnMg	CM350427		
KITINOX				316L	CM558954
CE 25		GS EZ	CM558011	304L	CM558018
		ZnMg	CM350569	316L	CM558014
CE 30		GS EZ	CM558041	304L	CM558048
		ZnMg	CM350570	316L	CM558044
BTRCC 6X20		GS EZ	CM801011	304L	CM801018
		ZnNi	CM350402	316L	CM801014

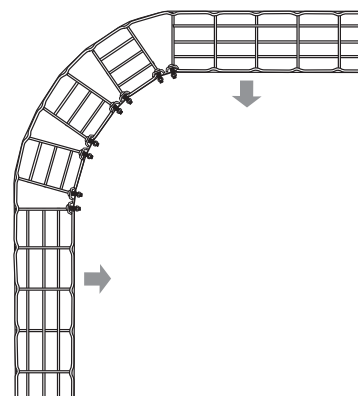

■ Hoekkorf PA

CF 30 - CF 54 - CF 105 50 - 600 mm


PA 1 H30		GS EZ	CM840101		
		DC GC	CM840103		
PA 2 H54		GS EZ	CM840111		
		DC GC	CM840113		
PA 4 H105		GS EZ	CM840131		
		DC GC	CM840133		
RADT90KIT H150		GS EZ	CM942942		

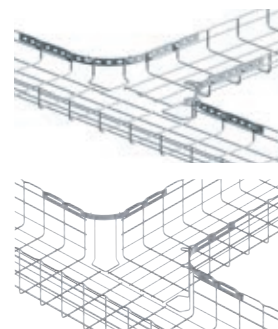

■ Universeel koppelplaat ED 275

CF 54 - CF 105 - CF 150 50 - 600 mm


ED 275		GS EZ	CM558221		
		DC GC	CM558223		
CE 25		GS EZ	CM558011		
		ZnMg	CM350569		
BTRCC 6X20		GS EZ	CM801011		
		ZnNi	CM350402		

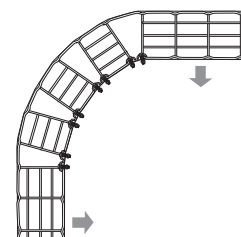

■ Koppelplaat CE 40

CF 30 - CF 54 100 - 200 mm

CE 40		GS EZ	CM558051	316L	CM558054
		ZnMg	CM558056	304L	CM558058

 

■ Hoekprofiel EZT 90 - ED250/90 - ED 1100

CF 30 - CF 54 - CF 105 - CF 150 50 - 600 mm

Hoekprofiel EZT 90		GS EZ	CM840231		
		DC GC	CM840233		
Rechte koppelplaat ED250/90		GS EZ	CM558211		
		DC GC	CM558213		
Montagestrip flexibel ED 1100		GS EZ	CM558201		
		DC GC	CM558203	316L	CM558204

