




Potentiaalvereffening en aarding

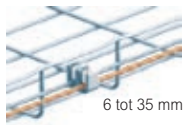


GRIFEQUIP



 GRIFEQUIP2

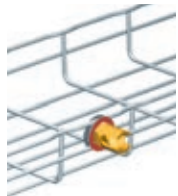

BLF

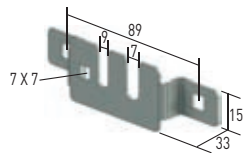

SBU



SCMT

Ref. Aardconnector aluminium

Ref.

ALU

CM585327
CM585427

GRIFEQUIP
GRIFEQUIP2 "zonder schroeven"

Aardconnector koper

16, 35 en 50 mm²
BLF : direct te bevestigen op draadgoot

koper

CM585387
CM585397
CM585407

BLF 8/16
BLF 8/35
BLF 8/50

Ø (mm ²)	L (mm)
16	22
35	24
50	26

Beugel voor connector

GS

ZnL

CM585090¹ CM585093¹ SBU

Haak SCMT

GS

CM585080

Spanwijdte (dikte) :
EF11/400 : 1 tot 11 mm
EF15/600 : 1 tot 15 mm
SCMT

1 : **316L** op aanvraag


SPECIALE BEUGELS

SPECIALE BEUGELS voor voedingindustrie

KENMERKEN

- Ideaal om te reinigen (hygiënisch)
- Verticale & horizontale plaatsing
- Verschillende afmetingen/types
- Klikbaar met draadgoot (montage vriendelijk)
- Verkrijgbaar in ZnMg en RVS304L


CM 100/100

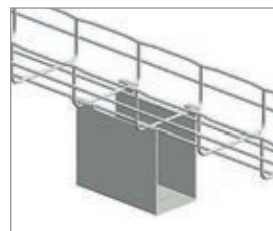

CM595927

ZnMg


CM 100/50

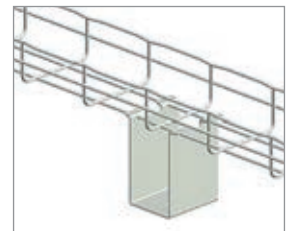

CM595917

ZnMg


CM 100/25

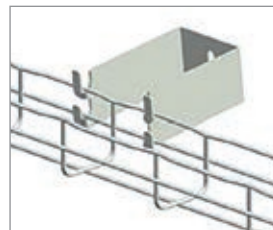

CM595907

ZnMg


UC 100/50

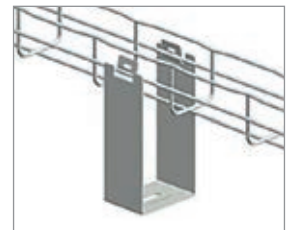

CM595937

ZnMg


FBH 50

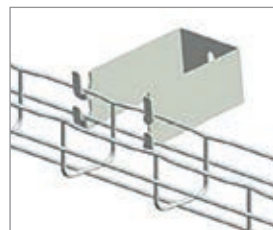

CM595900

304L

FBV 50

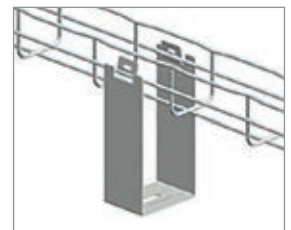


CM595930

304L

FBH 100/600

N

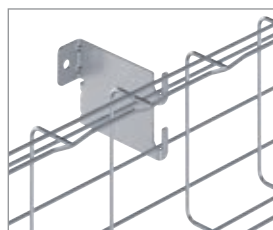

CM350585

304L

FBV 100/600

N



CM350586

304L