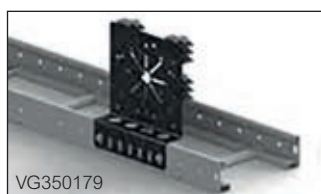


	Deksel	Dekselklem Let op, RVS	Binnenbocht	Buitenbocht	Aftakstuk	T-stuk	Stijg-/vervalstuk	
	Lengte 2000 mm							Breedte
	8211120	8236000	8312112	8312122	8312312	8312132	8312152	200 mm
	8211130		8312113	8312123	8312313	8312133	8312153	300 mm
	8211140		8312114	8312124	8312314	8312134	8312154	400 mm
	8211150		8312115	8312125	8312315	8312135	8312155	500 mm
	8211160		8312116	8312126	8312316	8312136	8312156	600 mm
	4x		4x	4x	4x	6x	4x	
	P31+ H = 25 mm als scheidingsgoot			Universele aanzetbocht	Klem- montageplaat	Montageplaat universeel	Montageplaat horizontaal⁽⁴⁾	
	Breedte 75 mm	Breedte 100 mm	Breedte 200 mm					Breedte
	VG480045	VG480046	VG480048	8312190	8312010	8235200	8312020	200 - 600 mm
	Bevestigen met Colring kabelbanden			2x		2x		

Toepassing montageplaat steekverbinding

Ophangsystemen (blz. 894)

Colring kabelbanden (zie www.ecatalog.be)