
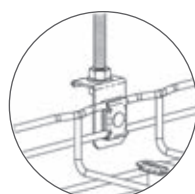


E30 - E90 constructies							Breedte
SF50	Steun U55 thermisch verzinkt	Wand-/ plafondconsole CSN/CSNC	Console CB	Bevestigings- hoek voor draadstang	Draadstang M10 Lengte 1000 mm	Draadstang M8 Lengte 1000 mm	
CM586140	-	-	-	-	-	8234008	50 mm
-	VG348362 t/m VG348372 (zie blz. 951)	-	VG350810	VG350122	8234000	-	100 mm
-		-	VG350820			-	150 mm
-		-	VG350830			-	200 mm
-		-	VG350840			-	300 mm
-		-	VG350850			-	400 mm
-	-	-	VG350810	-	8234000	-	100 mm
-	-	-	VG350820	-		-	150 mm
-	-	-	VG350830	-		-	200 mm
-	-	-	VG350840	-		-	300 mm
-	-	-	VG350850	-		-	400 mm
-	-	CM556310 of CM556110	-	-	-	8234008	100 mm
-	-	CM556320 of CM556120	-	-	-		150 mm
-	-	CM556330 of CM556130	-	-	-		200 mm
-	2x M6 x 10 mm ⁽³⁾			-	2x M10 ⁽⁷⁾	2x M8 ⁽⁸⁾	-
-	Plafond: 2x M10 ⁽⁴⁾	1x M8 ⁽⁵⁾	Wand: 1x M8 ⁽⁵⁾	2x M8 ⁽⁶⁾	-	-	-

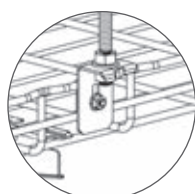

Bevestigingshoek voor draadstang
Bevestiging aan draadgoot met BRTCC 6x20 (CM801011) + 2x CE35 (CM558180)