



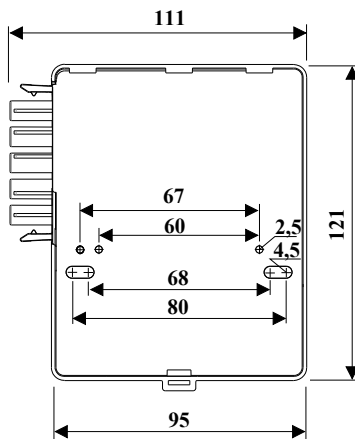

EnstoNet
KDN 506
250/400V MAX.16A IP21

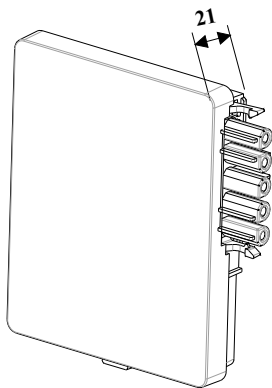

KDN506

Mounting box for panel heater, 3-phase continuous, 1 x 3-phase output

With this mounting box a 3-phase heater is connected in a permanent installation. The heater is connected with a 5 pole EnstoNet coupler. The wire connector in the box allows through-wiring connection to several heaters.

The box is fastened to the base with 2 screws max \varnothing 4,5 mm.

List of components:

1. Mounting box, base PMR2370.4
2. Mounting box, lid PMR2371
3. Socket NAC52.R/L3
4. Wire connector 1617, KD160.04

It is possible to raise the protection class to IP24 by using the cover KDNIP.

Type	KDN506 mounting box
Description	3 phase -o- , 3 phase output
Voltage	U = 250/400 VAC
Current	I = 16 A max -o-
IP class	IP21
EAN code	6418677722547
Sstl No.	
E No. (SE)	
EI No. (NO)	
Weight/ pce	83 g
Package qty	100 st