


AVR4

TC | E27



AVR4 universal splash proof luminaires are designed for both wet and dry premises. They can be used both in indoor and outdoor applications. Luminaires fit excellent to corridors, staircases, bathrooms and swimming pools. Due to its shock proof materials application areas can be also different public premises, hotels, staircases in block of houses. The luminaire itself can be modified with different kinds of accessories.

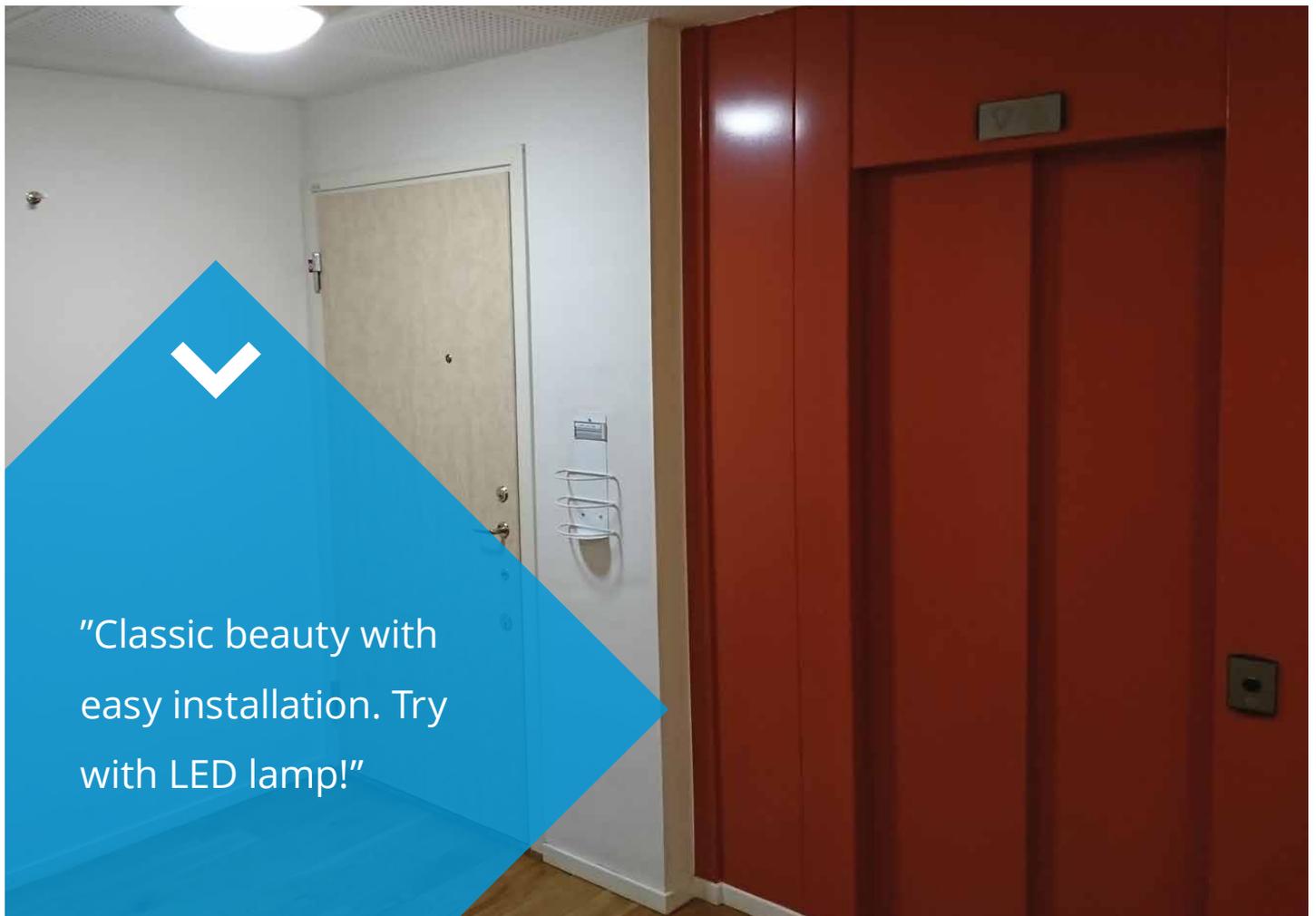

“Classic beauty with easy installation. Try with LED lamp!”



AVL28 decorative frame





AVL21 recess frame

Structure


- › Diffuser and body polycarbonate
- › Light sources colour temperature 830 included in the delivery, except incandescent lamp models AVR4 and AVR4MP

Mounting


- › To the ceiling or to the wall or partly recessed
- › Recess mounting bracket AVL21 to be ordered separately
- › Recess depth 40 mm, recess hole \varnothing 270 mm, diffuser diameter \varnothing 295 mm
- › Snap-in terminal block 3x2,5 mm² with through wiring

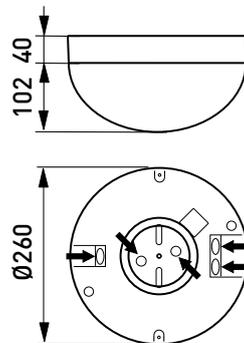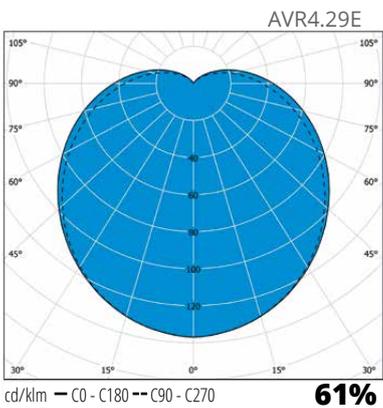

AVR4

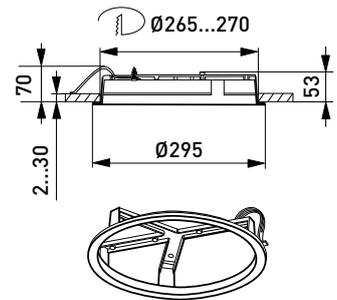

AVL21 recess frame

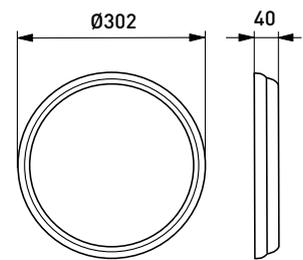

AVL28 decorative frame

E number	Type	Product name	Base	Kg	Additional information
AVR4 luminaire for E27					
41 170 00	AVR4	1x60W A60/E27 230V	E27	0,8	
41 172 96	AVR4MP	6xAVR4 1x60W A60/E27	E27	4,4	
AVR4 luminaires with electronic control gear					
41 172 36	AVR4.29E	2x9W TC-E/2G7 230/240V 0-50/60Hz	2G7	0,8	
AVR4 recess frame polycarbonate					
41 173 69	AVL21				white
AVR4 decorative frames polycarbonate					
41 170 09	AVL28				white

