

Aaria

LED | E27

Stylish garden luminaire designed for LED-light source. Aaria is suitable for large and small yards. Its anti-glare lighting is carefully directed to the illuminated area and the disturbing portion of scattered lighting has been minimized.



AA01APLED



“Lights up your garden with energy efficient light. Suits great with Opera in public places.”



AA01LED



AA03GH



AA03M

Structure

- › Base and top powder coated aluminium
- › Wall brackets powder coated zinked aluminium
- › Diffuser is ribbed, light-scattering UV resistant acrylic
- › Colours: white, black, graphite grey and antique bronze
- › LED-models:
connected load 10W, luminaire luminous flux 650 lm, neutral 4000 K
Ra>80, Power factor 0,92
Temperature - 20 °C - + 50 °C
Lifespan 30 000 h (L70), T_a=30 °C
- › E27-based models:
Max. 60W, LED and energy saving light bulbs 8-20W are recommended. Max measurements for light source width 98 mm and length 173 mm



Mounting

- › Can be mounted to a ø 50 mm pole, see poles at www.ensto.com - Gala
- › Wall models can be wired through a connection box, 4 punch holes for 78 mm screw spacing
- › -o- 3x2,5 mm²
- ›


E number	Type	Product name	Base	Model	Colour	Kg
LED-models						
41 031 43	AA01LED	AA01LED IP44 10W/840 AC C WH	LED	pole	white	2,3
41 031 46	AA01MLED	AA01MLED IP44 10W/840 AC C BK	LED	pole	black	2,3
41 031 42	AA01GHLED	AA01GHLED IP44 10W/840 AC C GH	LED	pole	graphite grey	2,3
41 031 39	AA01APLED	AA01APLED IP44 10W/840 AC C BR	LED	pole	antique bronze	2,3
LED wall models						
41 031 64	AA03LED	AA03LED IP44 10W/840 AC C WH	LED	wall	white	2,7
41 031 67	AA03MLED	AA03MLED IP44 10W/840 AC C BK	LED	wall	black	2,7
41 031 63	AA03GHLED	AA03GHLED IP44 10W/840 AC C GH	LED	wall	graphite grey	2,7
41 031 60	AA03APLED	AA03APLED IP44 10W/840 AC C BR	LED	wall	antique bronze	2,7



Snro	Tyyppi	Tuotenimi	Kanta	Malli	Väri	Kg
E27-models						
41 031 36	AA01	AA01 IP44 60W E27 AC C WH	E27	pole	white	2,1
41 031 45	AA01M	AA01M IP44 60W E27 AC C BK	E27	pole	black	2,1
41 031 40	AA01GH	AA01GH IP44 60W E27 AC C GH	E27	pole	graphite grey	2,1
41 031 37	AA01AP	AA01AP IP44 60W E27 AC C BR	E27	pole	antique bronze	2,1
E27 wall models						
41 031 57	AA03	AA03 IP44 60W E27 AC C WH	E27	wall	white	2,5
41 031 66	AA03M	AA03M IP44 60W E27 AC C BK	E27	wall	black	2,5
41 031 61	AA03GH	AA03GH IP44 60W E27 AC C GH	E27	wall	graphite grey	2,5
41 031 58	AA03AP	AA03AP IP44 60W E27 AC C BR	E27	wall	antique bronze	2,5

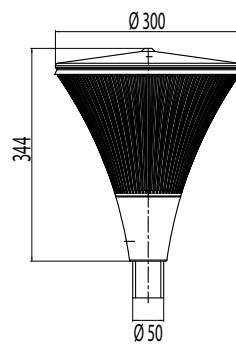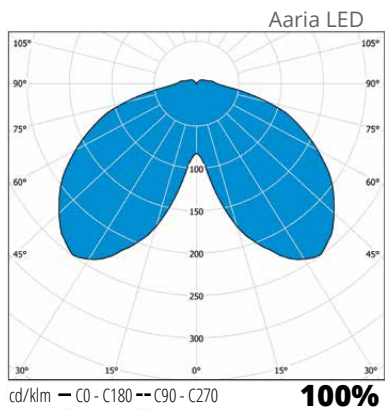

Aaria pole model

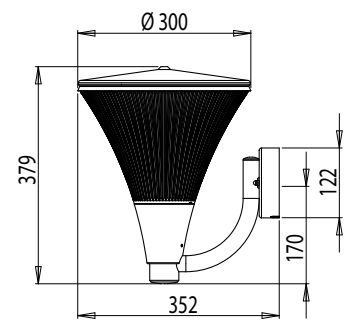

Aaria wall model



Aria fits to every yard and will light up your garden set up as you want. prismatic dif-fuser makes light distribution even and smooth.