



AL132-series

Ali

LED

Streamlined and elegant universal LED work point luminaire for kitchens. All luminaires of these series are drip-proof. The shape of the luminaire bottom allows it's installation in 45 degrees angle as well as directly on the surface.


DualWhite

Ensto luminaires with DualWhite -solution are equipped with integrated option for light colour temperature switching. You can easily switch between 3000K and 4000K which saves your SKUs and gives you possibility to change colour temperature according to project, with one luminaire.



Dual
White

1 Luminaire,
2 Colour temperatures

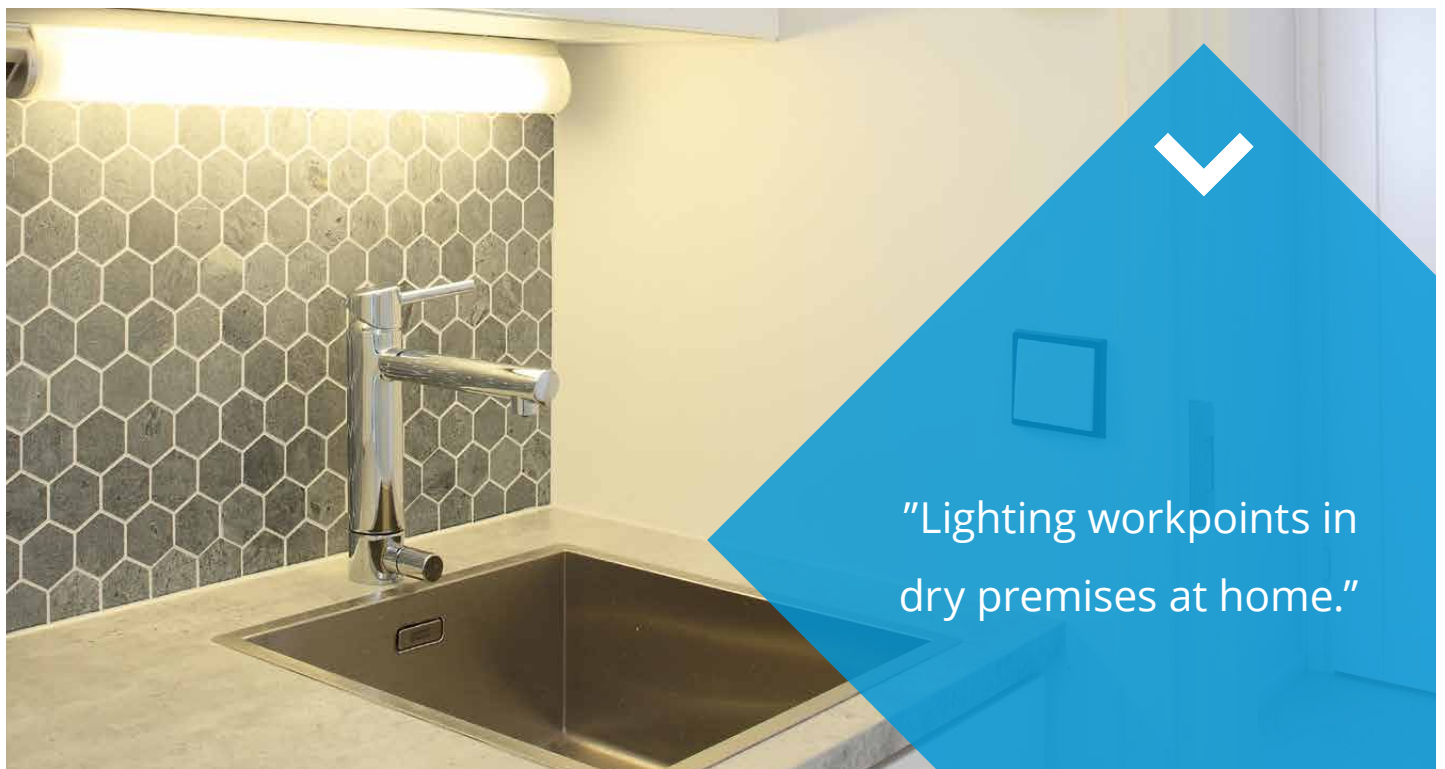

"Lighting workpoints in
dry premises at home."



AL134-series




Cover strip

Structure


- › Body - White powder-coated aluminium
- › End caps - UV resistant polycarbonate
- › Diffuser - UV resistant opal acrylic plastic or satinated acrylic plastic (grey models)
- › Accessories:
 - AL132 with earthed double socket outlet and switch
 - AL134 with earthed double socket outlets at both ends of the luminaire and one switch
- › In AL132-series earthed safety double socket outlet. Horizontal outlet holes. Switch is next to socket outlet. Side of the switch can be changed by turning the luminaire 180 degrees (without separate connection)
- › LED-models DualWhite:
 - 3000K or 4000K selected from circuit board
 - switch under diffuser
 - 6W - 400/420 lm
 - 7W - 560/610 lm
 - 9W - 670/750 lm
 - 21W - 1640/1690 lm
 - Ra > 80, power factor 0,92
 - Ambient temperature - 20 °C - + 30 °C
 - LED-module lifespan 30 000 h (L70), T_a=25 °C

Mounting


- › On the wall. In 45° angle to the corner
- › Connection point next to the cable entry
- › 2 cable entry holes at the bottom of the luminaire
- › Equipped with spacious cable mounting slot across the luminaire body
- › Blind cable entries in end caps
- › Constant voltage can be connected to luminaire's socket outlets

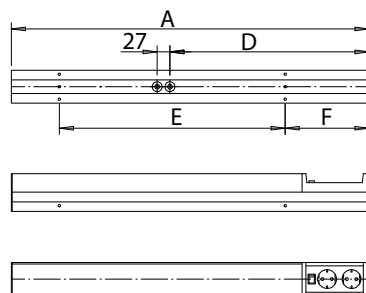

AL132-series

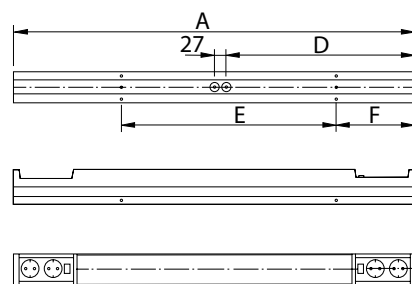

AL134-series

 

E number	Type	Product name	Base	Kg	A	D	E	F
AL132 LED DW with earthed double socket outlet and switch								
41 033 83	AL13211LED/DW	AL13211LED/DW LED 6W/8DW DSO	LED	0,9	475	318	190	198
41 033 85	AL13215LED/DW	AL13215LED/DW LED 8W/8DW DSO	LED	1,3	615	315	400	183
41 033 86	AL13218LED/DW	AL13218LED/DW LED 9W/8DW DSO	LED	1,4	768	319	480	186
41 033 88	AL13236LED/DW	AL13236LED/DW LED 21W/8DW DSO	LED	1,9	1377	520	772	303
AL134 LED DW with earthed double socket outlets at the both ends and switch								
41 033 89	AL13418LED/DW	AL13418LED/DW LED 9W/8DW 2DSO	LED	1,8	907	319	537	186

