

# Alunette

E27



AL250

Alunette E27 universal luminaire for both indoor and outdoor use in public and private applications. Luminaires can be used among others in staircases, kitchens, bathrooms, storage rooms, toilets, corridors, shelters and terraces.



“Universal luminaire  
for every purpose.”



AL250 + AL250KL-V



AL250 + AL250K-V

### Structure

- › Diffuser – UV and shock resistant acrylic
- › Body – UV resistant polycarbonate
- › E27-base model CL1

### Mounting


- › To the ceiling and to the wall
- › Suitable for surface or recess mounting
- › Recess mounting bracket included in the packing
- › Recess depth 27 mm, recess hole  $\varnothing$  240 mm, diffuser diameter  $\varnothing$  255 mm
- › Snap-in terminal block with through wiring  $3 \times 2,5 \text{ mm}^2$

### Decorative frame

- › Model: ring frame
- › Material: aluminium
- › Colour: white
- › Diameter: 340 mm

### Decorative frame with eyelid

- › Model: so called frame with eyelid
- › Material: aluminium
- › Colour: white
- › Diameter: 340 mm

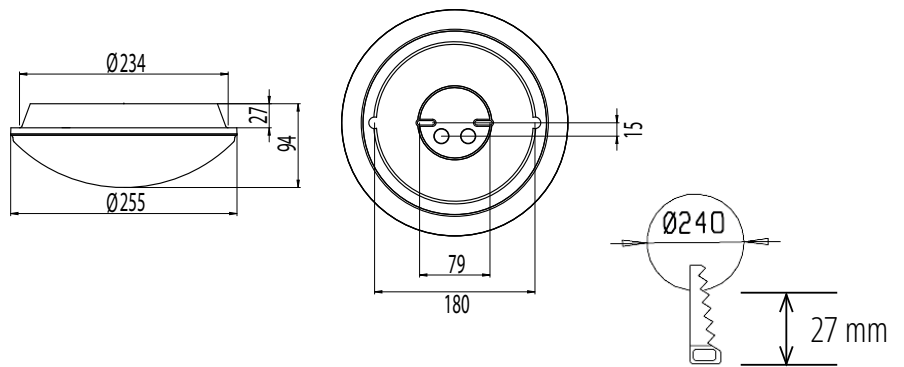

E number	Type	Product name	Base	Additional information
Alunette E27 base (light source is not included in the delivery)				
41 033 80	AL250	AL250 IP54 E27 AC O	E27	
Decorative frame				
41 607 00	AL250K-V	AL250K-V FRAME WH		white
Decorative frame with eyelid				
41 607 03	AL250KL-V	AL250KL-V FRAME WH		white

