


AVH15

E14

AVH15 luminaires are designed especially for private saunas. It can also be used in locations where a durable basic luminaire is required.



AVH15.1

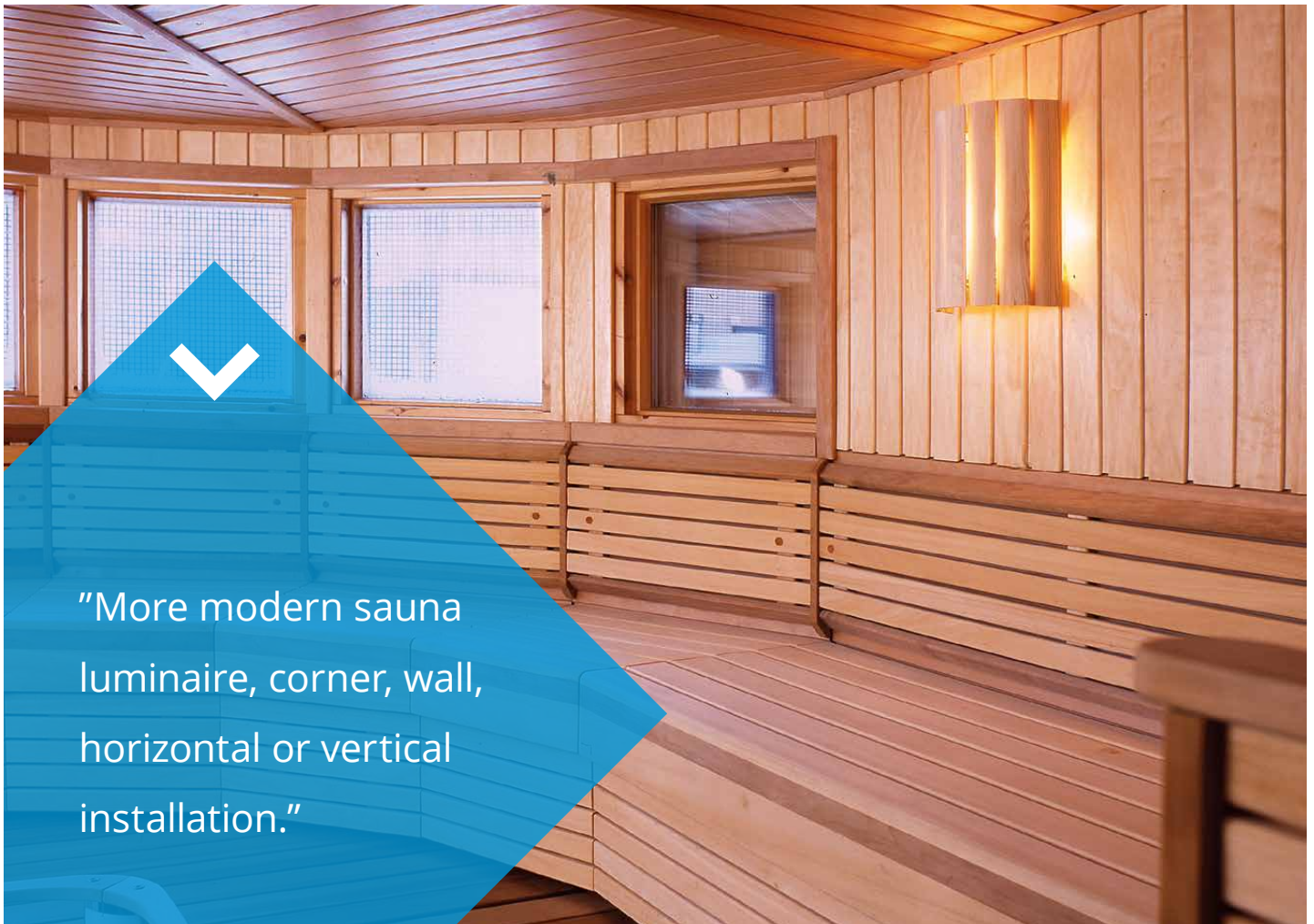

"More modern sauna luminaire, corner, wall, horizontal or vertical installation."



AVH15.10



AVH15.2




AVH15.20

Structure


- › Diffuser glass
- › Body thermo resistant technical plastic
- › Vizor : pine or aspen grill

Mounting


- › Wall installation, min. 100 mm from the ceiling
- › Not to the ceiling!
- › Screw terminal block 2x1,5 mm² -o

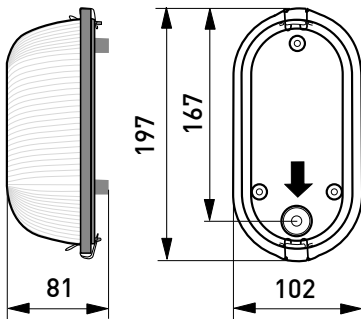

AVH15

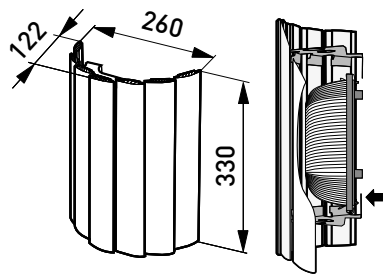

AVH15.1

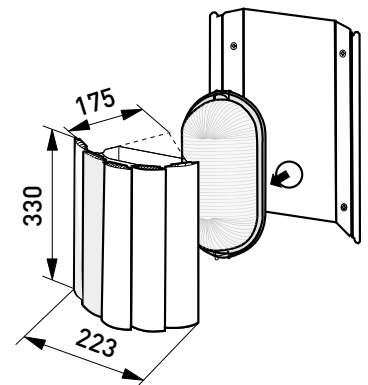

AVH15.2

E number	Type	Product name	Base	Kg	Additional information
Sauna luminaire					
41 171 42	AVH15	1x30/60W C35/E14 IP44, ta125 °C	E14	0,5	
Sauna luminaire with pine grill for wall mounting					
41 171 43	AVH15.1	1x30/60W C35/E14 IP44, ta125 °C	E14	1,2	
Sauna luminaire with aspen grill for wall mounting					
41 170 16	AVH15.10	1x30/60W C35/E14 IP44, ta125 °C	E14	1,2	
Sauna luminaire with pine grill for corner mounting					
41 171 45	AVH15.2	1x30/60W C35/E14 IP44, ta125 °C	E14	1,3	
Sauna luminaire with aspen grill for corner mounting					
41 170 17	AVH15.20	1x30/60W C35/E14 IP44, ta125 °C	E14	1,3	

