

## AVR51/52

LED



AVR51.11L

Energy efficient LED-signal luminaires are compact, durable and suitable for versatile use, including both indoor and outdoor applications, when there is a need for a sign to be light up. An excellent light source to light up the blade, where the information can be displayed with stickers or by engraving directly to the blade.



“Use for house numbering or as a info plate.”



AVR51.11LV



AVR52.11L




AVR52.11LV

### Structure

- ▶ Body casted aluminium
- ▶ Number blade acrylic
- ▶ LED-model:
  - Connected load 2W,
  - 4000 K
  - Ra>80
  - Ambient temperature - 30 °C - + 30 °C
  - LED-module lifespan 50 000 h (L70), T<sub>a</sub>=30 °C

### Mounting

- ▶ To the surface
- ▶ -o Snap-in terminal block 3x2,5 mm<sup>2</sup>

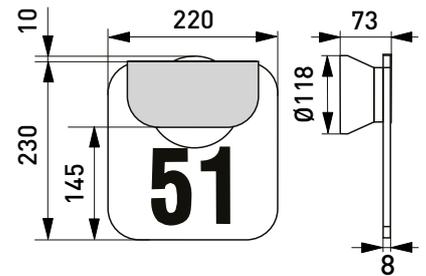

E number	Type	Product name	Base	Model	Colour	Kg
<b>LED-signal luminaires</b>						
41 170 55	AVR51.11L	LED luminaire 1W square black	LED	square	black	1,2
41 170 56	AVR51.11LV	LED luminaire 1W square white	LED	square	white	1,2
41 170 57	AVR52.11L	LED luminaire 1W rectangular black	LED	rectangular	black	1,3
41 170 58	AVR52.11LV	LED luminaire 1W rectangular white	LED	rectangular	white	1,3

