
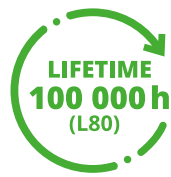


# AVR67

LED

Jono with square diffuser is a stylish universal luminaire available in LED for indoor and outdoor use.

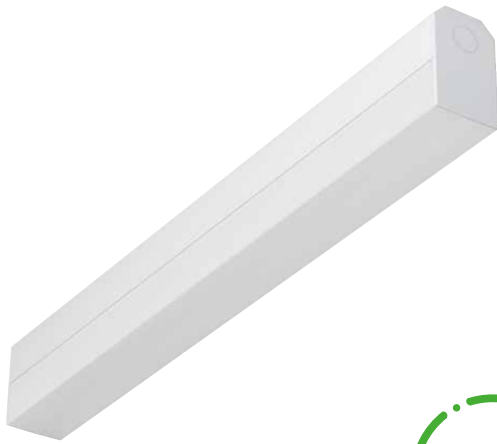


## DALI

DALI drivers enable luminaires to be connected to DALI based control systems and Smart Buildings. Compared to a fixed output installation, the dimming and individual control capability provided by DALI enables considerable energy savings and control, depending on luminaire specifications.

## Dimming

Ensto can provide many dimming possibilities for luminaires. 1-10V, Switch Dim, DALI and base light are just few examples of possibilities to change the light output to fit your premises.



“Classic linear luminaire with square shaped diffuser. Sharp alternative for all areas.”



AVR67 + wire suspension set

### Structure



- › Diffuser polycarbonate
- › Body aluminium
- › Connected load
  - 10W, luminaire luminous flux 895 lm (3000 K), 950 lm (4000 K)
  - 15W, luminaire luminous flux 1342 lm (3000 K), 1425 lm (4000 K)
  - 20W, luminaire luminous flux 1790 lm (3000 K), 1900 lm (4000 K)
  - 3000 K and 4000 K, Ra > 80, power factor 0,94
- › Ambient temperature - 20 °C - + 25 °C
- › LED module lifespan  $T_a=25\text{ °C}$ :
  - >100 000 h (L70)
  - 100 000 h (L80)
  - 71 000 h (L90)
- › LED driver lifetime  $T_a=25\text{ °C}$ :
  - 100 000 h (max. 10 % failure rate)

### Control

- › DALI
- › Switch-control

### Mounting

- › To the ceiling and to the wall
- › Snap-in terminal block 5x2,5 mm<sup>2</sup> with through wiring

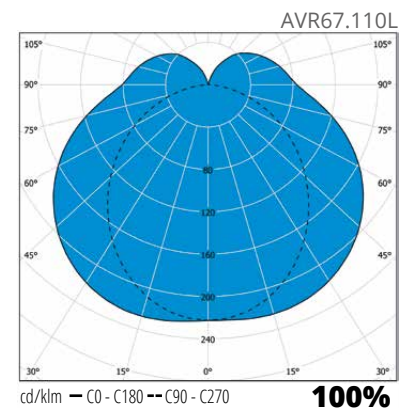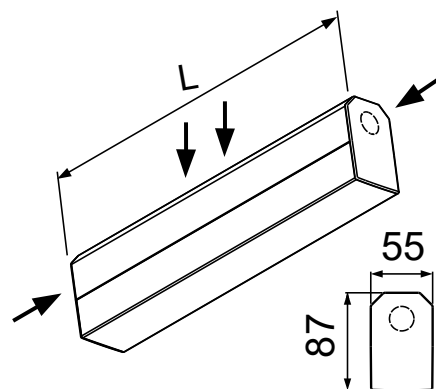

E number	Type	Product name	Base	Kg	Length	Luminous flux	Additional information
<b>Jono LED with opal diffuser</b>							
42 903 20	AVR67.110L	AVR67 IP44 LED10W/840 E	LED	0,8	600	950 lm	
42 903 22	AVR67.110L/3K	AVR67 IP44 LED10W/830 E	LED	0,8	600	895 lm	
42 903 25	AVR67.115L	AVR67 IP44 LED15W/840 E	LED	1,2	900	1425 lm	
42 903 26	AVR67.115L/3K	AVR67 IP44 LED15W/830 E	LED	1,2	900	1342 lm	
42 903 29	AVR67.120L	AVR67 IP44 LED20W/840 E	LED	1,6	1200	1900 lm	
42 903 35	AVR67.120L/3K	AVR67 IP44 LED20W/830 E	LED	1,6	1200	1790 lm	
<b>Jono LED with opal diffuser, DALI</b>							
42 903 23	AVR67.115DDL	AVR67 IP44 LED15W/840 DALI	LED	1,2	900	1425 lm	
42 903 28	AVR67.115DDL/3K	AVR67 IP44 LED15W/830 DALI	LED	1,2	900	1342 lm	
42 903 43	AVR67.120DDL	AVR67 IP44 LED20W/840 DALI	LED	1,6	1200	1900 lm	
42 903 49	AVR67.120DDL/3K	AVR67 IP44 LED20W/830 DALI	LED	1,6	1200	1790 lm	
<b>Jono accessories</b>							
42 175 56	AVL601	Wire suspension set for JONO AVR66					
42 175 59	AVL605	In-line connector set for JONO AVR66					
42 174 53	AVL608	90° angle connector pair for JONO AVR66					

