

AVR8

LED | E27



AVR8.114LA



AVR8 is a modern, clear lined, durable and energy-efficient luminaire for outdoor lighting. Wall-mounted luminaire fit excellent for lighting entrances of multi-store buildings and areas nearby of industrial premises.



“Wonderful fixture for facades and for house number use.”



AVR8.114L




AVR8.114LAL

Structure

- ▶ Diffuser polycarbonat
- ▶ Body casted aluminium
- ▶ LED-model:
 - The power can be selected by changing the connection at the installation site
 - Connected load: 9W/13W/18W
 - Luminaire luminous flux (4K): 790 lm/1080 lm/1450 lm
 - Preset: 9W/790 lm
 - 3000 K and 4000 K, Ra>80, power factor 0,92
 - Ambient temperature - 40 °C - + 25 °C
- ▶ LED module lifespan $T_a=25\text{ °C}$:
 - >100 000 h (L70)
 - 100 000 h (L80)
 - 71 000 h (L90)
- ▶ LED driver lifetime $T_a=25\text{ °C}$:
 - 100 000 h (max. 10 % failure rate)

Mounting

- ▶ To the surface
- ▶ Snap-in terminal block 3x2,5 mm² with through wiring
- ▶ To the outer corner with AVL820 bracket

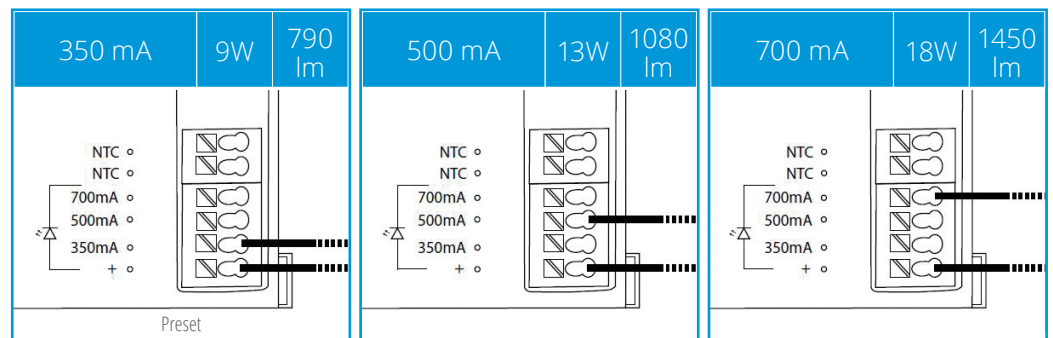

Ability to change luminous flux and power in the same luminaire.

E number	Type	Product name	Base	Kg	Luminous flux	Additional information
AVR8 LED						
45 170 07	AVR8.114L	AVR8 IP44 LED 9W/840 PCO WH	LED	2,4	790 lm/1080 lm/1450 lm	white
45 170 08	AVR8.114LA	AVR8 IP44 LED 9W/840 PCO BG	LED	2,4	790 lm/1080 lm/1450 lm	blackgrey (RAL7021)
45 170 10	AVR8.114LAL	AVR8 IP44 LED 9W/840 PCO AL	LED	2,4	790 lm/1080 lm/1450 lm	aluminium
45 170 32	AVR8.114L/3K	AVR8 IP44 LED 9W/830 PCO WH	LED	2,4	770 lm/1050 lm/1410 lm	white
45 170 34	AVR8.114LA/3K	AVR8 IP44 LED 9W/830 PCO BG	LED	2,4	770 lm/1050 lm/1410 lm	blackgrey (RAL7021)
45 170 35	AVR8.114LAL/3K	AVR8 IP44 LED 9W/830 PCO AL	LED	2,4	770 lm/1050 lm/1410 lm	aluminium
AVR8 luminaire with E27 base						
45 170 01	AVR8	AVR8 IP44 TC-TSE/E27 PCO WH	E27	2,0		white
45 170 02	AVR8.A	AVR8 IP44 TC-TSE/E27 PCO BG	E27	2,0		blackgrey (RAL7021)
45 170 04	AVR8.AL	AVR8 IP44 TC-TSE/E27 PCO AL	E27	2,0		aluminium
AVR8 accessories and spare parts						
45 170 17	AVL8	Number sign for AVR8 luminaire		0,2		white
45 170 31	AVL8.A	Number sign for AVR8 luminaire, graphite		0,2		graphite
45 170 38	AVL8.AL	Number sign for AVR8, aluminium		0,2		aluminium
45 170 40	AVL820	Corner bracket AVR8, white		1,4		white
45 170 26	AVL820.A	Corner bracket AVR8, graphite		1,4		graphite
45 170 19	AVV8	Diffuser for AVR8 luminaire		0,2		white








AVL8




AVL820

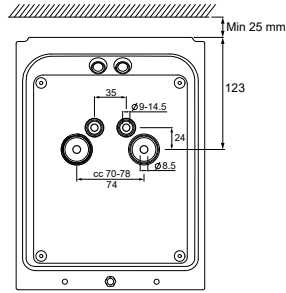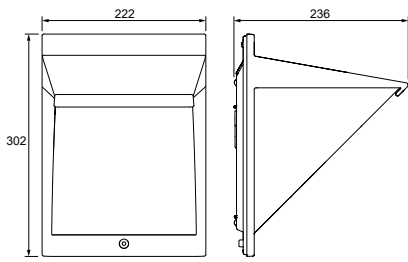

AVR8 luminaire

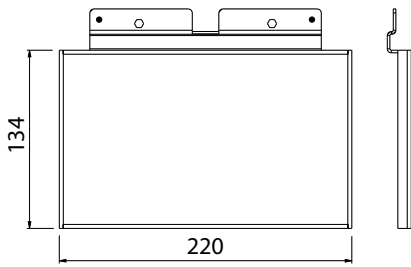

AVL8 number sign

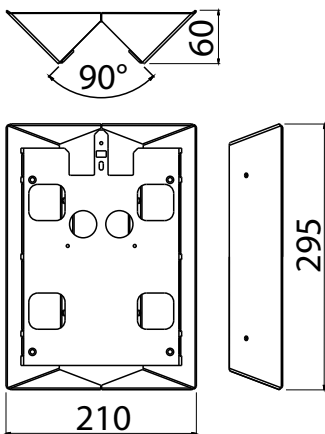

AVL820 corner bracket



When you are after a stylish and modern fixture, take a look at AVR8. Durable aluminium body complemented with energy efficient light is a beautiful option for facades around the town.

