

Gala

E27

Gala outdoor lighting series provide elegant luminaires for the entire garden area. The range consists of a coherent selection of wall, roof and pole luminaires. The basic material is durable aluminum.



AVG01M



“Wide variety of shapes and colours. Classic white for most, black takes you to next level.”



AVG03



AVG07M



AVG01GHLED

Structure

- › Body and anti-glare rings powder coated aluminium
- › Colours: white, black and graphite grey
- › Diffusers: transparent or matte glass, matte glass used with black and graphite grey luminaires and other models with clear glass diffuser
- › Wall brackets: powder-coated galvanised steel
- › Poles and support legs (ordered separately); powder-coated aluzink steel
- › LED- and energy-saving bulbs 8-20W are recommended with E27 base; Max measurements for light source: width 68 mm and length 188 mm.

Mounting

- › To the wall, ceiling, support leg ø 50 mm or pole ø 50 mm.
- › Wall and ceiling models can be wired through a connection box, 4 punch holes for 78 mm screw spacing
- › AVG01 pole models; Can be mounted to a ø 50 mm pole (1,5 m VP150050/colour or 2,0 m VP225050/colour). Ground support MT (ø 50 mm). Can be mounted to support leg; MJ-5/colour. Support legs available in 13,5 cm and 120 cm height. Mounting accessories are not included in the delivery.
- › Connection: Wall and ceiling luminaires: 3x2,5 mm² terminal block for through wiring in the luminaire body, knockouts for surface wiring Pole luminaires: 3x2,5 mm² terminal block for through wiring inside the luminaire


Made to order

- › Pearl grey, antique silver and antique bronze models
- › AVGP05 Majakka pole (white, black and graphite grey)


E number	Type	Product name	Base	Model	Colour	Kg
Pole mounting luminaire (pole ø 50 mm ordered separately)						
45 032 00	AVG01	AVG01 IP44 75W E27 G C VA	E27	pole	white	0,8
45 032 06	AVG01M	AVG01M IP44 75W E27 G O MU	E27	pole	black	0,8
41 031 21	AVG01GH	AVG01GH IP44 75W E27 G C GH	E27	pole	graphite grey	0,8
Majakka pole luminaire (ø 50 mm pole ordered separately)						
41 030 80	AVGP05	AVGP05 IP44 60W E27 G C WH	E27	pole	white	0,8
41 030 83	AVGP05M	AVGP05M IP44 60W E27 G O BK	E27	pole	black	0,8
41 030 82	AVGP05GH	AVGP05GH IP44 60W E27 G O GH	E27	pole	graphite grey	0,8
Wall mounting luminaire, light up						
41 030 36	AVG03	AVG03 IP44 75W E27 G C WH	E27	wall	white	1,2
45 032 15	AVG03M	AVG03M IP44 75W E27 G O BK	E27	wall	black	1,2
41 031 25	AVG03GH	AVG03GH IP44 75W E27 G O GH	E27	wall	graphite grey	1,2
Wall mounting luminaire, light down						
41 030 48	AVG07	AVG07 IP44 75W E27 G C WH	E27	wall	white	1,4
45 602 70	AVG07M	AVG07M IP44 75W E27 G O BK	E27	wall	black	1,4
41 030 67	AVG07GH	AVG07GH IP44 75W E27 G O GH	E27	wall	graphite grey	1,4
Wall mounting luminaire, light up, Majakka						
45 602 50	AVGP03	AVGP03 IP44 75W E27 G C WH	E27	wall	white	1,3
45 602 52	AVGP03M	AVGP03M IP44 75W E27 G O BK	E27	wall	black	1,3
41 030 76	AVGP03GH	AVGP03GH IP44 75W E27 G O GH	E27	wall	graphite grey	1,3

E number	Type	Product name	Base	Model	Colour	Kg
Poles ø 50 mm fit to AVG01 and AVGP05 models				Height, m		
46 031 21	VP150050/V	VP150050/V 1.5M 50MM WH		1,5	white	2,5
46 031 24	VP150050/M	VP150050/M 1.5M 50MM BK		1,5	black	2,5
46 030 04	VP150050/GH	VP150050/GH 1.5M 50MM GH		1,5	graphite grey	2,5
46 031 27	VP150050/AP	VP150050/AP 1.5M 50MM BR		1,5	antique bronze	2,5
46 031 09	VP225050/V	VP225050/V 2M 50MM WH		2,0	white	3,5
46 031 12	VP225050/M	VP225050/M 2M 50MM BK		2,0	black	3,5
46 030 05	VP225050/GH	VP225050/GH 2M 50MM GH		2,0	graphite grey	3,5
46 031 15	VP225050/AP	VP225050/AP 2M 50MM BR		2,0	antique bronze	3,5
Support legs ø 50 mm fit to AVG01 model				Height, cm		
46 601 44	MJ-5V	MJ-5V 50.8 WH		13,5	white	0,4
46 601 42	MJ-5M	MJ-5M 50.8 BK		13,5	black	0,4
46 030 01	MJ-5GH	MJ-5GH 50.8 GH		13,5	graphite grey	0,4
46 601 40	MJ-5AP	MJ-5AP 50.8 BR		13,5	antique bronze	0,4
46 601 06	MJ-5V/120	MJ-5V/120 50.8 VA 1200MM		120	white	2,2
46 601 05	MJ-5M/120	MJ-5M/120 50.8 MU 1200MM		120	black	2,2
46 030 02	MJ-5GH/120	MJ-5GH/120 50.8 GH 1200MM		120	graphite grey	2,2
46 601 03	MJ-5AP/120	MJ-5AP/120 50.8 ANTPRONS1200MM		120	antique bronze	2,2
Ground supports for poles						
46 030 09	MT	MT GROUND SUPP. 50MM		Terrafix ø 50 mm		0,45


G=clear glass diffuser, C=clear, O=opal/matte. Power indicated as max. incandescent lamp effect, use of energy saving or LED lamps recommended

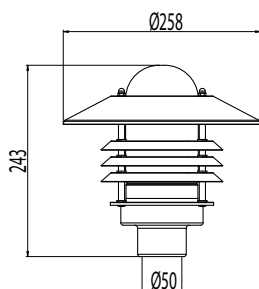


AVG01

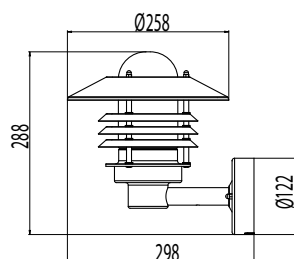


AVG03

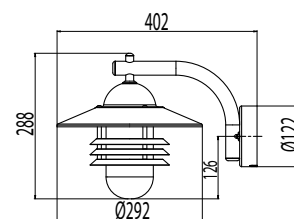


AVG07

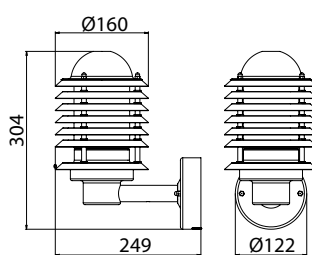


AVGP03

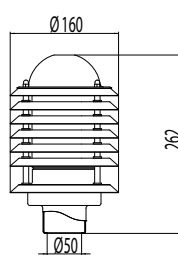

AVGP05

 


MJ-5

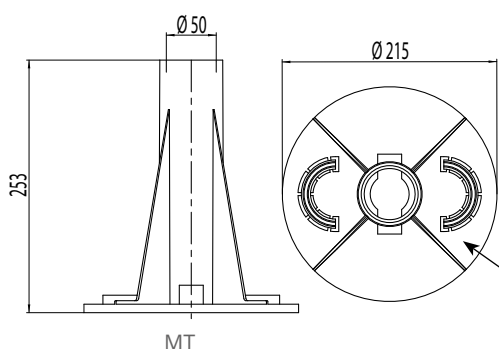

MT

Remove the curved locating pieces (2 pcs) from the ground mount base and fasten them around the mouth of the ground mount.

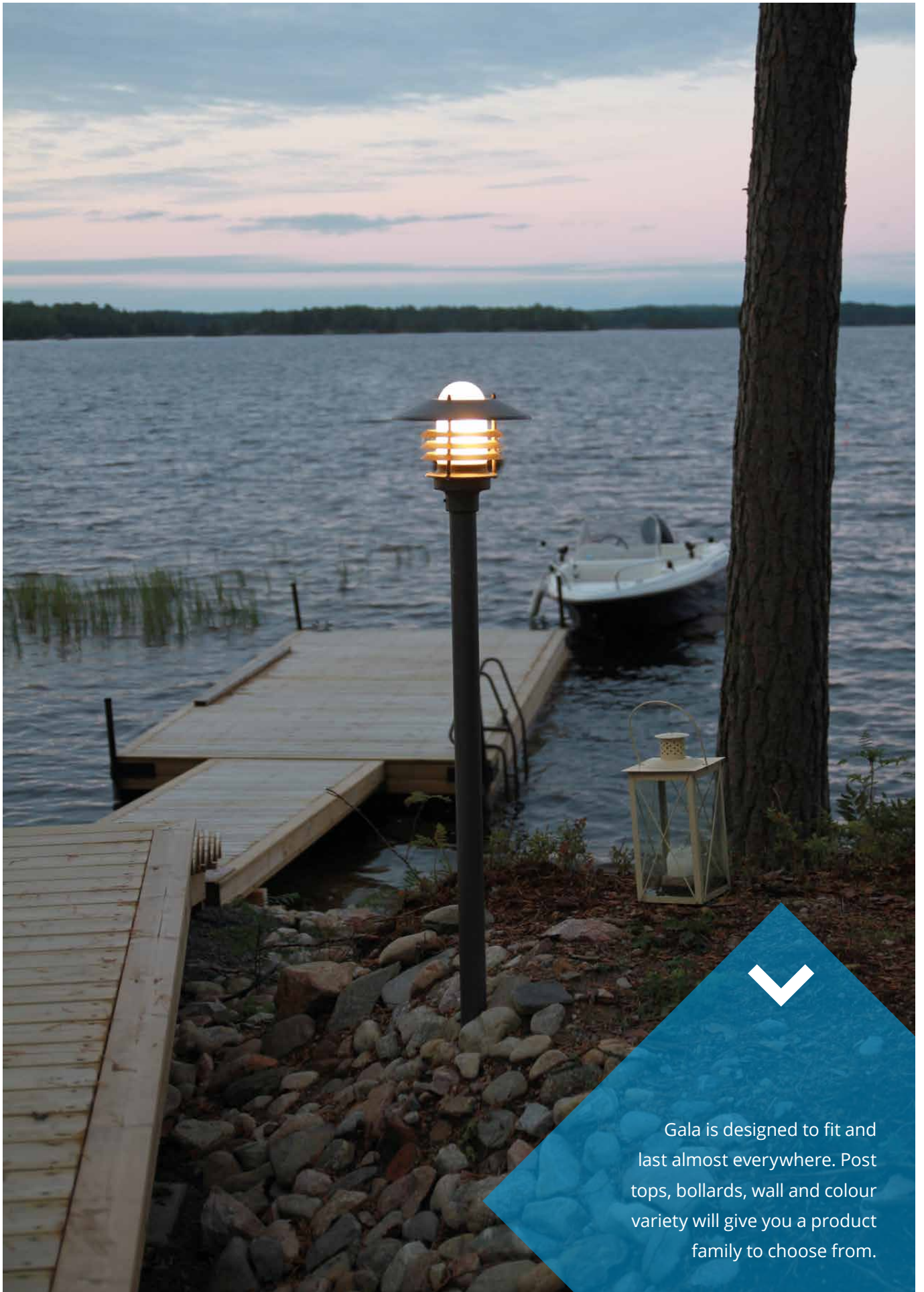

Gala is designed to fit and last almost everywhere. Post tops, bollards, wall and colour variety will give you a product family to choose from.

