

Käpy

E27

Traditional garden lighting pole luminaire, which creates atmosphere. Käpy cone shape luminaires are an ideal choice for lighting pathways and planting areas.



AT101ALAP



“Lighting gardens for decades, Käpy has never looked better and still does.”



AT101ALV



AT103ALM



AT103ALAP

Structure

- ▶ Body and anti-glare rings powder coated aluminium.
- ▶ Poles: powder-coated aluzink steel
- ▶ Colours: antique bronze, black and white
- ▶ Luminaires are delivered without light source. LED- and energy-saving bulbs designed for outdoor use 8-20W are recommended with E27 base

Mounting


- ▶ Pole models:
 - Can be mounted to a ø 50 mm pole (1,5 m VP150050/colour or 2,0 m VP225050/colour).
 - MT ground support (ø 50 mm).
 - Can be mounted to a support legs; MJ-5/colour available in 13,5 cm and 120 cm height
 - Can be mounted to the wall with wall supports; SK-5/colour
 - Mounting accessories to be ordered separately
- ▶ Wall models directly to the wall
- ▶ 3x2,5 mm² terminal block for through wiring inside the luminaire.

E number	Type	Product name	Base	Colour	Kg	
Käpy (4 anti-glare rings)						
45 033 06	AT101ALAP	AT101ALAP 100W E27 BR	E27	antique bronze	1,4	
45 033 09	AT101ALM	AT101ALM 100W E27 BK	E27	black	1,4	
45 033 12	AT101ALV	AT101ALV 100W W27 WH	E27	white	1,4	
Käpy, wall models						
45 033 24	AT103ALAP	AT103ALAP 100W E27 BR	E27	antique bronze	0,7	
45 033 27	AT103ALM	AT103ALM 100W E27 BK	E27	black	0,7	
45 033 30	AT103ALV	AT103ALV 100W E27 WH	E27	white	0,7	
Poles ø 50 mm						
			Height	ø mm		
46 031 27	VP150050/AP	VP150050/AP 1.5M 50MM BR	1,5	50,8	antique bronze	2,5
46 031 24	VP150050/M	VP150050/M 1.5M 50MM BK	1,5	50,8	black	2,5
46 031 21	VP150050/V	VP150050/V 1.5M 50MM WH	1,5	50,8	white	2,5
46 031 15	VP225050/AP	VP225050/AP 2M 50MM BR	2	50,8	antique bronze	3,5
46 031 12	VP225050/M	VP225050/M 2M 50MM BK	2	50,8	black	3,5
46 031 09	VP225050/V	VP225050/V 2M 50MM WH	2	50,8	white	3,5




E number	Type	Product name	Base	Colour	Kg	
Ground supports for poles			∅ mm			
46 030 09	MT	MT GROUND SUPP. 50MM	Terrafix	50	0,5	
Wall supports ∅ 50 mm			∅ mm			
46 031 54	SK-5AP	SK-5AP WALL SUPPORT BR		50,8	antique bronze	0,8
46 031 51	SK-5M	SK-5M WALL SUPPORT BK		50,8	black	0,8
46 031 48	SK-5V	SK-5V WALL SUPPORT WH		50,8	white	0,8
Support legs ∅ 50 mm			Height	∅ mm		
46 601 40	MJ-5AP	MJ-5AP 50.8 BR	13,5	50,8	antique bronze	0,4
46 601 42	MJ-5M	MJ-5M 50.8 BK	13,5	50,8	black	0,4
46 601 44	MJ-5V	MJ-5V 50.8 WH	13,5	50,8	white	0,4
46 601 03	MJ-5AP/120	MJ-5AP/120 50.8 ANTPRONS1200MM	120	50,8	antique bronze	2,2
46 601 05	MJ-5M/120	MJ-5M/120 50.8 MU 1200MM	120	50,8	black	2,2
46 601 06	MJ-5V/120	MJ-5V/120 50.8 VA 1200MM	120	50,8	white	2,2


Power indicated as max. incandescent lamp effect, use of energy saving or LED lamps recommended 8-20W

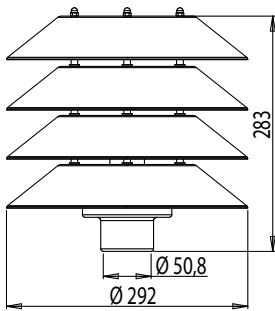


AT101

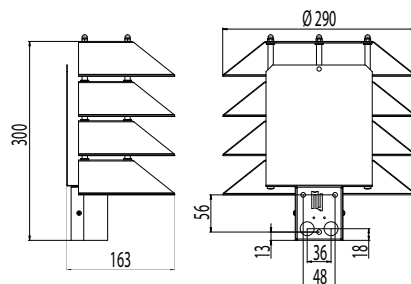

AT103 wall model

 


MJ-5

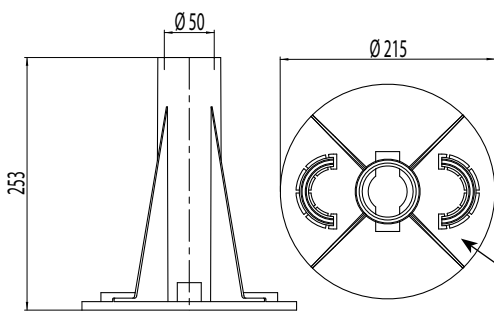


MT

Remove the curved locating pieces (2 pcs) from the ground mount base and fasten them around the mouth of the ground mount.

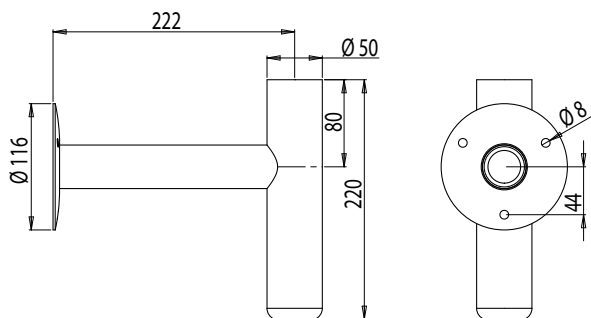

SK-5

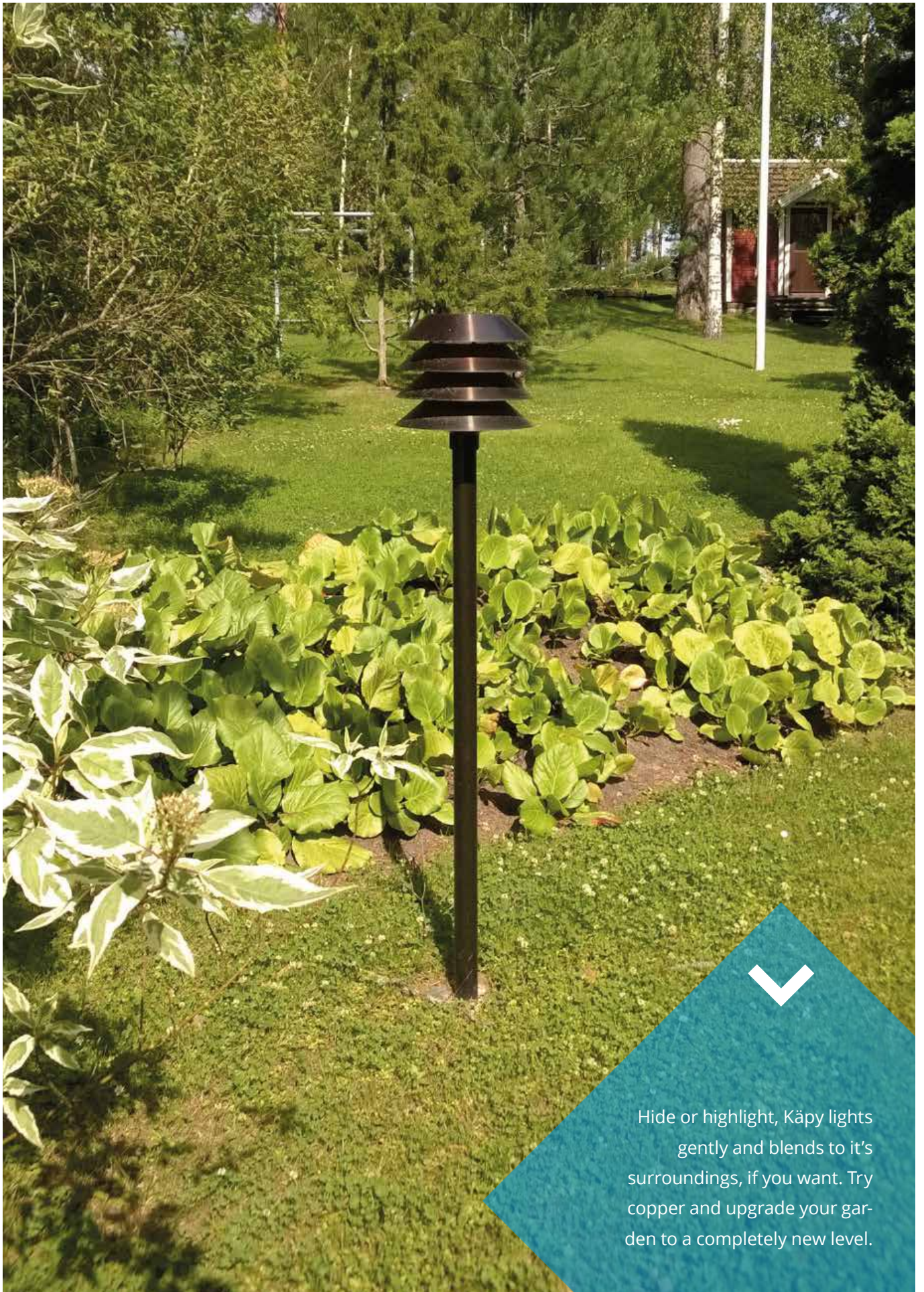

Hide or highlight, KÄPY lights gently and blends to its surroundings, if you want. Try copper and upgrade your garden to a completely new level.

