


# Forte

LED

Strong and stylish outdoor LED luminaire for residential and public premises.



FO265.14LGH

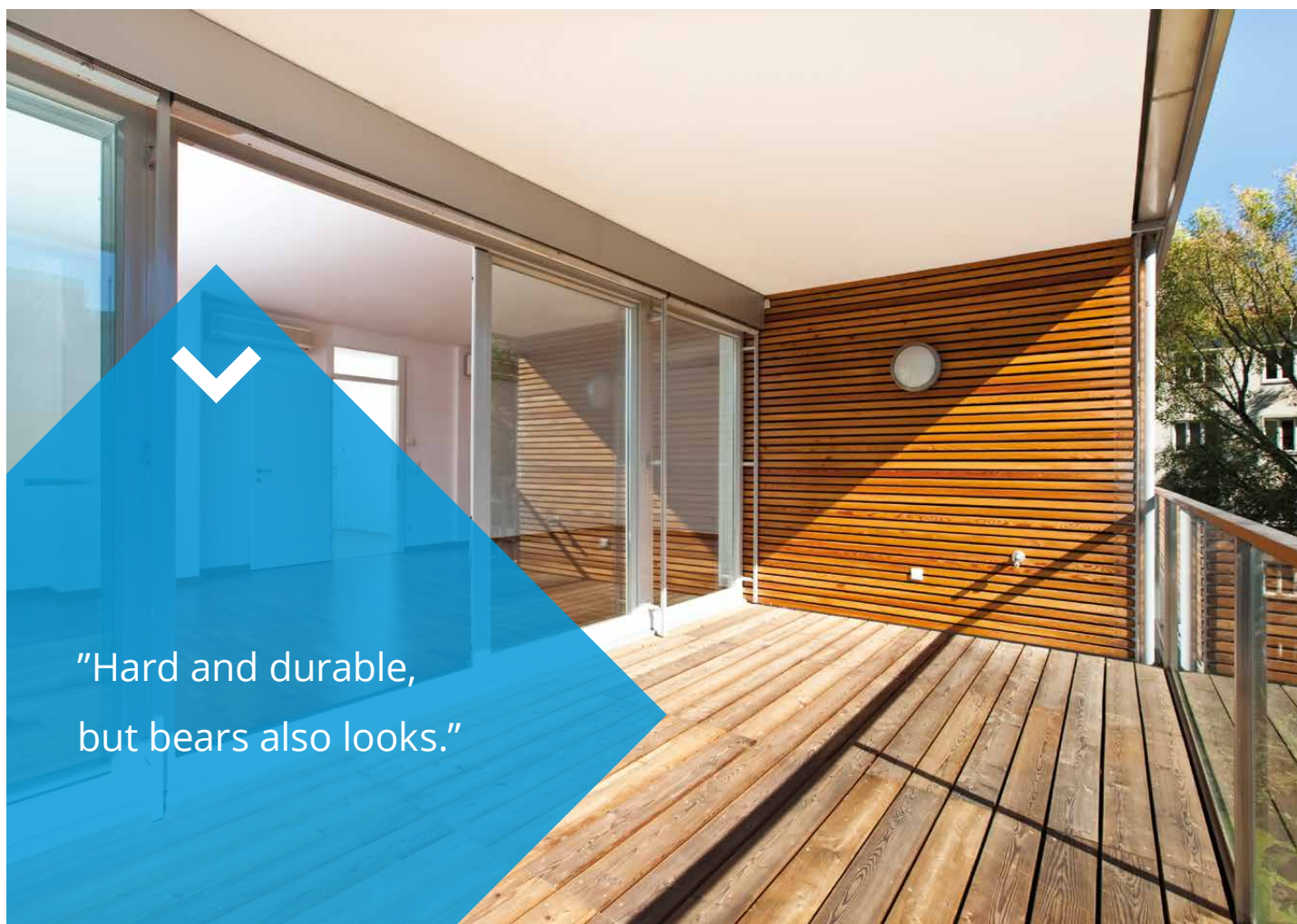

"Hard and durable,  
but bears also looks."



FO265.14LV



FO265.14GH




### Structure

- › Body die-cast aluminium
- › Diffuser UV-protected polycarbonate
- › Colours: Graphite grey (GH) and white (V)
- › LED-models:  
 Connected power 9,5W and 19W, see the luminaire luminous flux from the table  
 Colour temperature 3000K and 4000K  
 Ra>80, power factor 0,9  
 Ambient temperature -20 °C - +30 °C  
 LED-module lifetime 50 000h (L70), T<sub>a</sub>=25 °C


### Mounting

- › To the wall and to the ceiling, -o- 3x2,5 mm<sup>2</sup>
- › Breakthroughs on luminaires side
- › Cable holes at the bottom of the luminaire and sides also


E number	Type	Product name	Output	Base	Kg	Colour	Luminous flux
<b>Forte LED S</b>							
45 031 95	FO265.14GH	FO265.14GH 9.5W/840 IP65	9,5W	LED	1,30	Graphite grey	1100 lm
45 031 96	FO265.14GH/3K	FO265.14GH/3K 9.5W/830 IP65	9,5W	LED	1,30	Graphite grey	1000 lm
45 032 02	FO265.14V	FO265.14V 9.5W/840 IP65	9,5W	LED	1,30	White	1100 lm
45 032 04	FO265.14V/3K	FO265.14V/3K 9.5W/830 IP65	9,5W	LED	1,30	White	1000 lm
<b>Forte LED S with eye-lid</b>							
45 031 97	FO265.14LGH	FO265.14LGH 9.5W/840 IP65	9,5W	LED	1,40	Graphite grey	750 lm
45 031 98	FO265.14LGH/3K	FO265.14LGH/3K 9.5W/830 IP65	9,5W	LED	1,40	Graphite grey	650 lm
45 031 99	FO265.14LV	FO265.14LV 9.5W/840 IP65	9,5W	LED	1,40	White	750 lm
45 032 01	FO265.14LV/3K	FO265.14LV/3K 9.5W/830 IP65	9,5W	LED	1,40	White	650 lm
<b>Forte LED L</b>							
45 032 05	FO360.19GH	FO360.19GH 19W/840 LED IP65 PC	19W	LED	2,60	Graphite grey	1500 lm
45 032 07	FO360.19GH/3K	FO360.19GH/3K 19W/830 LED IP65	19W	LED	2,60	Graphite grey	1400 lm
45 032 17	FO360.19V	FO360.19V 19W/840 LED IP65 PC	19W	LED	2,60	White	1500 lm
45 032 19	FO360.19V/3K	FO360.19V/3K 19W/830 LED IP65	19W	LED	2,60	White	1400 lm
<b>Forte LED L with eye-lid</b>							
45 032 08	FO360.19LGH	FO360.19LGH 19W/840 LED IP65	19W	LED	2,80	Graphite grey	1000 lm
45 032 10	FO360.19LGH/3K	FO360.19LGH/3K 19W/83 LED IP65	19W	LED	2,80	Graphite grey	900 lm

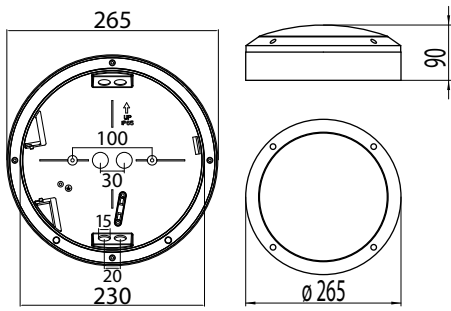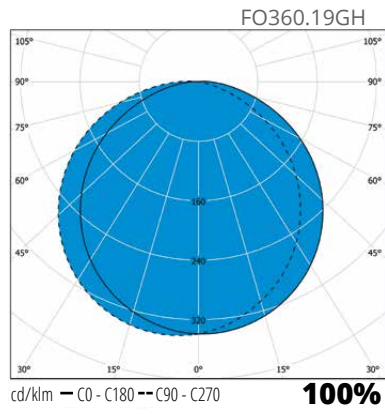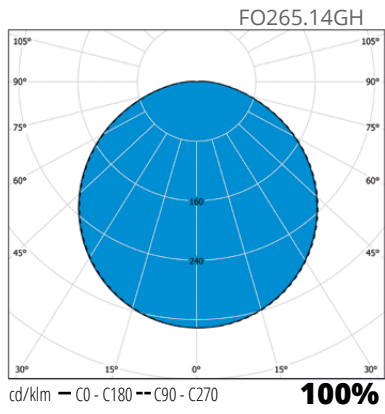


Forte S

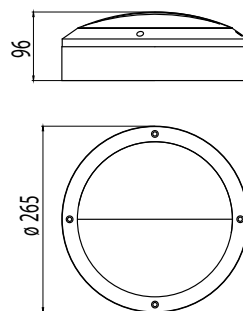


Forte S with eye-lid

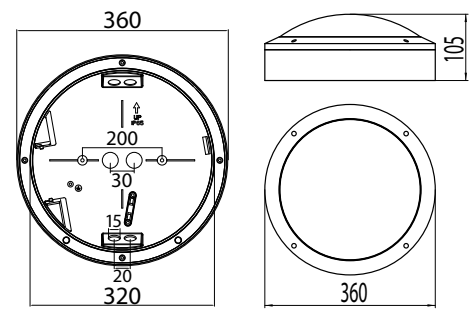

Forte L

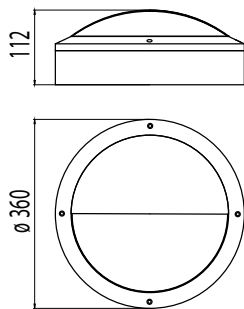

Forte L with eye-lid

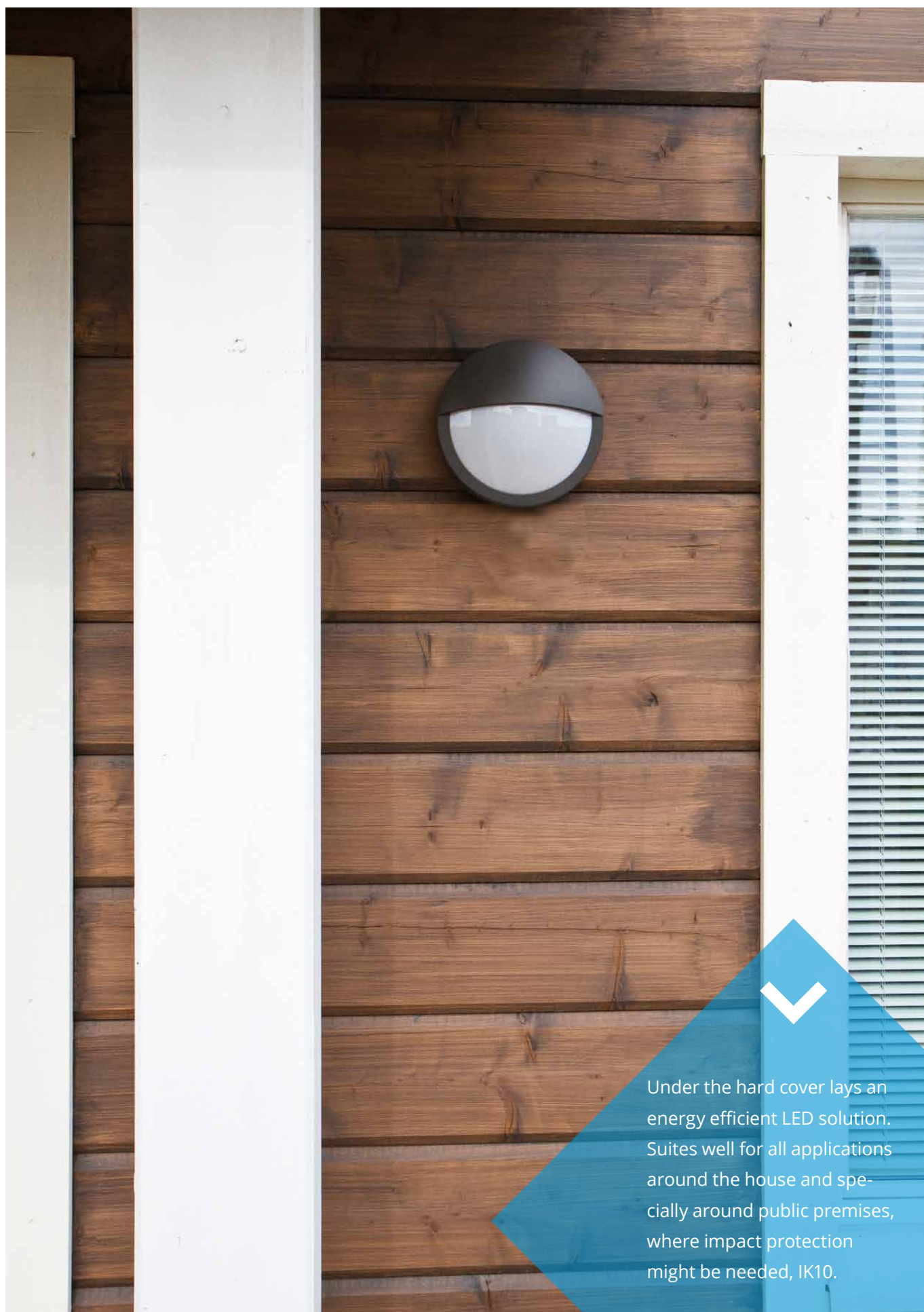

Under the hard cover lays an energy efficient LED solution. Suits well for all applications around the house and specially around public premises, where impact protection might be needed, IK10.

