

Lumia Spot

GU10



AVN01GH

Stylish, graphite grey colour and modern design make the Lumia-series luminaires an obvious choice for modern gardens and houses. The series provides models for general lighting and spotlights. Series of Lumia luminaires can be combined with Gala outdoor graphite grey pole and bollard model luminaires.



"Spotlight for home wall
or summer cottage.
Durable and affordable."



AVN03GH



AVN07GH



AVN08GH

Structure


- › Body is aluminium
- › Protective glass (AVN01GH, AVN03GH, AVN07GH and AVN08GH)
- › Colour graphite grey=GH

Selection


- › GU10-based models for spot lighting, light source alternatives:
 GU10 CFL 9W
 GU10 LED max. 7W
 GU10 halogen max. 35W
 Light source max. height 76 mm

Mounting


- › To wall, -o 3x1,5 mm²
- › AVN01GH-model equipped with ground spike and 5,5 m rubber cable (H05RN-F 2x1,0 mm²) and plug

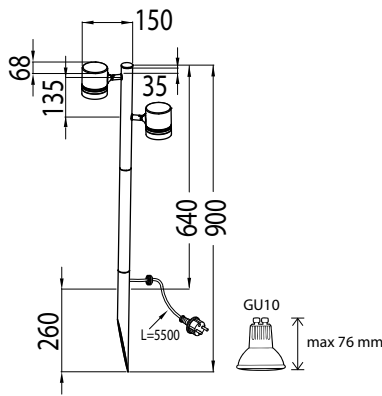


AVN01GH

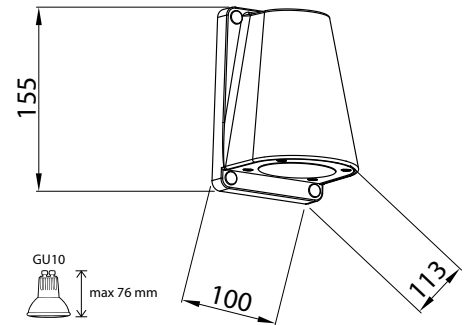

AVN03GH

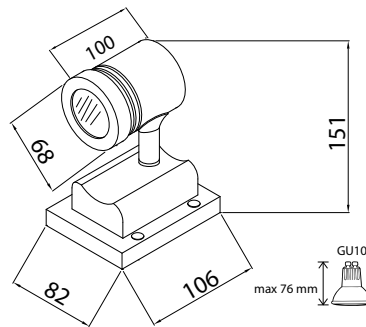

AVN07GH

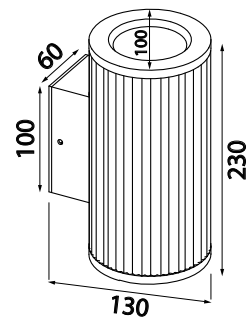

AVN08GH

E number	Type	Product name	Base	Model	Kg
Lumia Spike, 2xGU10, spike and 5,5 m rubber cable with Schuko plug, CL2					
41 031 49	AVN01GH	AVN01GH IP44 2X35W GU10 G C GH	GU10	pole	1,6
Lumia wallspot					
41 031 51	AVN03GH	AVN03GH IP44 50W GU10 G C GH	GU10	wall	0,7
Lumia wallspot, adjustable					
41 031 52	AVN07GH	AVN07GH IP44 35W GU10 G C GH	GU10	wall	0,6
Lumia wallspot up-down					
41 031 85	AVN08GH	AVN08GH IP44 2X35W GU10 G C GH	GU10	wall	1,1

