

Lumia

LED | E27



AVN260GHLED

Stylish, graphite grey colour and modern design make the Lumia-series luminaires an obvious choice for modern gardens and houses. The series provides models for general lighting and spotlights. Series of Lumia luminaires can be combined with Gala outdoor graphite grey pole and bollard model luminaires.



“Durable and stylish aluminium fixture for wall and ceiling.”



AVN260LGH



AVN260L

Structure



- › Body powder-coated aluminium
- › Diffuser UV resistant polycarbonate
- › Colour graphite grey=GH or white=VA
- › IK08

Selection


- › E27-based models for general- and house number lighting max. 60W, 11-18W energy saving bulbs are recommended. Light source width max. 45 mm and length max. 145 mm
- › LED-models:
 AVN260...- Connected load 8W, luminaire luminous flux 572 lm (with frame) / 370 lm (with eye-lid), 4000 K
 Ra>80, power factor 0,92
 Ambient temperature - 20 °C - + 30 °C
 LED-module lifespan 30 000 h (L70), T_a=30 °C

Mounting

- › To the wall and ceiling, through-wiring 3x1,5 mm²

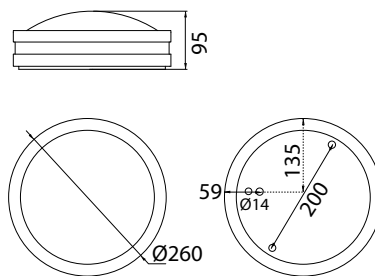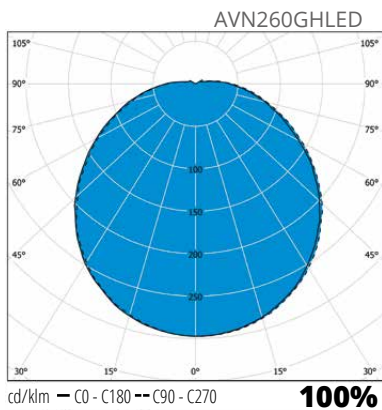

AVN260GH

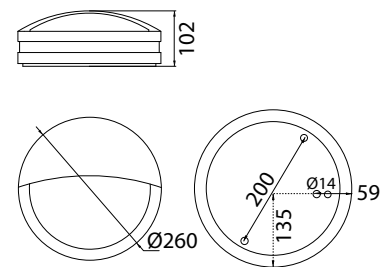

AVN260LGH

E number	Type	Product name	Base	Model	Colour	Kg
LED-models						
41 032 08	AVN260GHLED	AVN260GHLED IP54 9W/840 PC GH	LED	wall/ceiling	graphite grey	1,2
41 032 11	AVN260LGHLED	AVN260LGHLED IP54 9W/840 PC GH	LED	wall	graphite grey	1,2
Wall-/ ceiling luminaire						
41 032 06	AVN260	AVN260 IP54 60W E27 PC O WH	E27		white	1,2
41 031 54	AVN260GH	AVN260GH IP54 60W E27 PC O GH	E27		graphite grey	1,2
Wall luminaire with eyelid						
41 032 09	AVN260L	AVN260L IP54 60W E27 PC O WH	E27		white	1,2
41 031 55	AVN260LGH	AVN260LGH IP54 60W E27 PC O GH	E27		graphite grey	1,2

