

Lumo

LED



Modern, versatile and stylish Lumo is made for residential and public spaces. Lumo is a next generation all-around luminaire which secretly hides multiple functions inside. Changeable lumen output as well as colour temperature give Lumo the leading edge in lighting the premises.

DALI

DALI drivers enable luminaires to be connected to DALI based control systems and Smart Buildings. Compared to a fixed output installation, the dimming and individual control capability provided by DALI enables considerable energy savings and control, depending on luminaire specifications.


DualWhite

Ensto luminaires with DualWhite -solution are equipped with integrated option for light colour temperature switching. You can easily switch between 3000K and 4000K which saves your SKUs and gives you possibility to change colour temperature according to project, with one luminaire.



Dual White

1 Luminaire,
2 Colour temperatures

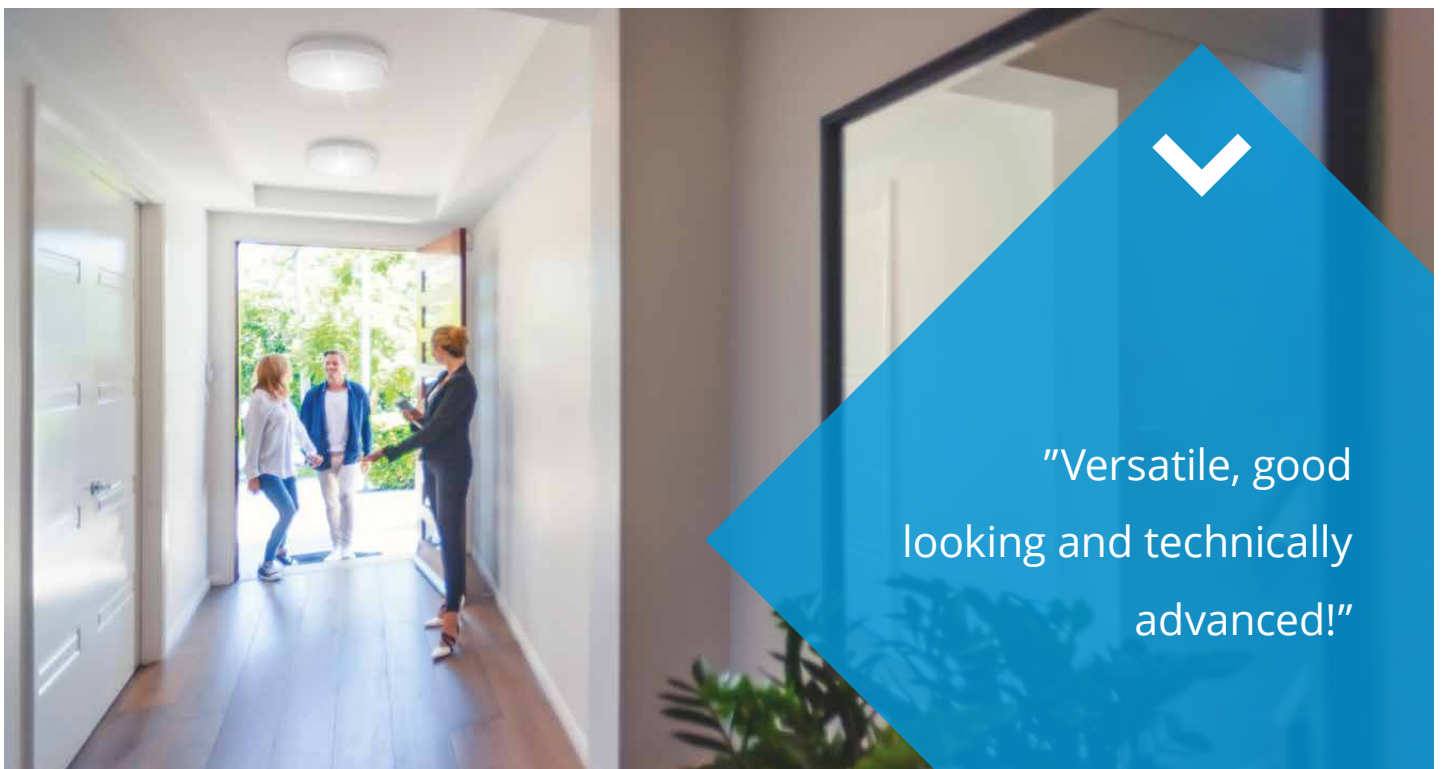

“Versatile, good looking and technically advanced!”



LU267.900/DW



LU267BL.900/DW



Structure

- › Diffuser opal polycarbonate
- › Body white coloured polycarbonate, also available in black frame colour
- › LED DualWhite models:
9W, luminaire luminous flux 900 lm and 450 lm (4000 K),
15W, luminaire luminous flux 1500 lm, 1000 lm and 700 lm (4000 K),
23W, luminaire luminous flux 2300 lm, 1500 lm and 1000 lm (4000 K),
3000 K/4000 K, selected from circuit board switch under diffuser
Ra > 80, power factor 0,90
Ambient temperature - 20 °C - + 25 °C
LED-luminaire lifespan 100 000 h, T_a=25 °C

Control






- › Lumo RADAR-type of luminaires are sensor luminaires equipped with high-frequency radar to detect motion (Radar) in which are settings for time (1-30 min.), sensitivity and twilight switch function
- › DALI

Mounting

- › To the ceiling and to the wall
- › Snap-in terminal block 3x2,5 mm² with through wiring
- › Sensor luminaire models see more accurate information at WEB-site
RADAR-models:
To the ceiling max. 6 meters height
To the wall 1,7-2,7 meters height
Suitable for stand-alone and master-slave installation. NOTICE! Master-slave installation is possible only with other Lumo luminaires.

E number	Type	Product name	Base	Kg	Colour	Luminous flux
Lumo LED						
41 035 75	LU267.900/DW	LUMO IP44 LED 9W 830/840	LED	0,67	white	900/450 lm
41 173 53	LU267.900BL/DW	LUMO IP44 LED 9W 830/840 BL	LED	0,67	black	800/400 lm
41 035 77	LU335.1500/DW	LUMO IP44 LED 15W 830/840	LED	1,06	white	1500/1000/700 lm
41 173 35	LU335.2300/DW	LUMO IP44 LED 23W 830/840	LED	1,06	white	2300/1500/1000 lm
41 173 58	LU335.2300BL/DW	LUMO IP44 LED 23W 830/840 BL	LED	1,06	black	2000/1300/870 lm
Lumo LED radar sensor luminaires						
41 035 76	LU267R.900/DW	LUMO IP44 LED 10.5W 830/840 R	LED	0,72	white	900/450 lm
41 173 55	LU267R.900BL/DW	LUMO IP44 LED 10.5W 830/840 R BL	LED	0,72	black	800/400 lm
41 173 49	LU335R.2300/DW	LUMO IP44 LED 24.5W 830/840 R	LED	1,11	white	2300/1500/1000 lm
41 173 61	LU335R.2300BL/DW	LUMO IP44 LED 23W 830/840 R BL	LED	1,11	black	2000/1300/870 lm
Lumo LED with battery back-up						
41 173 32	LU335.1500/DW/1M	LUMO IP44 LED 15W 830/840 1M	LED	1,26	white	1500/1000/700 lm (270 lm)
41 173 50	LU335.2300/DW/1M	LUMO IP44 LED 23W 830/840 1M	LED	1,26	white	2300/1500/1000 lm (270 lm)
Lumo LED radar sensor luminaire with battery back-up						
41 173 34	LU335R.1500/DW/1M	LUMO IP44 LED 15W 830/840 R 1M	LED	2,4	white	1500/1000/700 lm (270 lm)
41 173 52	LU335R.2300/DW/1M	LUMO IP44 LED 23W 830/840 R 1M	LED	2,4	white	2300/1500/1000 lm (270 lm)
Lumo LED DALI						
41 035 79	LU267DDL.900/DW	LUMO IP44 LED 9W 830/840 DA	LED	1,26	white	-
41 035 80	LU335DDL.1500/DW	LUMO IP44 LED 15W 830/840 DA	LED	1,26	white	-



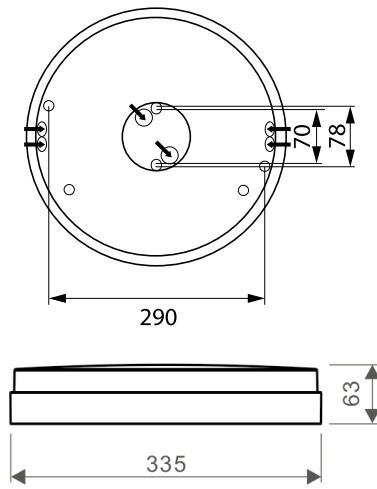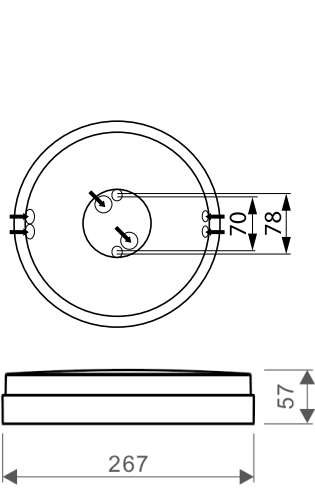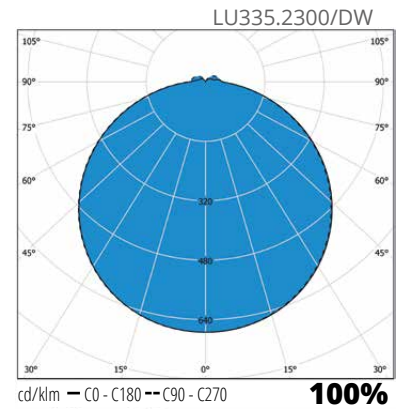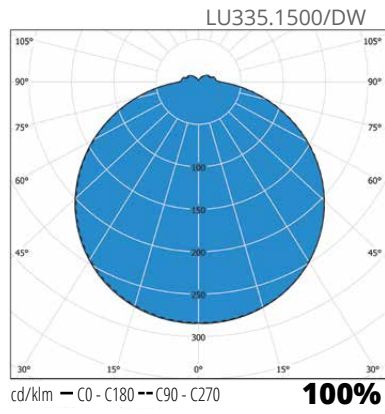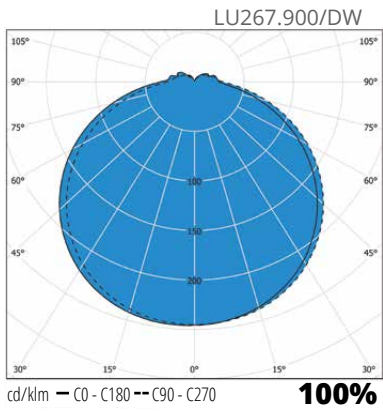



✓

The elegant and versatile luminaires in the Lumo range distribute soft light and offer a wide range of options for general lighting, allowing you the freedom of choice.

