



White

Opus

LED

Opus is recessed outdoor downlight which is suitable for illuminate public buildings entrances and canopies. Opus luminaire is IP65 so it can be installed in several places in outdoor premises.



“Opus illuminates and invites to step in.”



Black



Opus with connection box

Structure

- › Body aluminium
- › Diffuser tempered bright glass
- › Colours: Black and white
- › Luminaires IP-class is IP65. Connection box IP21
- › Selection:
 - Power 28W, luminous flux 3000 lm
 - Power 41W, luminous flux 4500 lm
- › Colour temperature 4000 K, Ra>80
- › Power factor 0,95
- › Ambient temperature -20 °C - +30 °C
- › LED-module lifetime 68 000h (L90B10) T_a=25 °C



Mounting

- › Recessed installation, through wiring 3x1,5 mm²
- › Cut-out diameters
 - OPU30: ø 140 mm
 - OPU45: ø 165 mm
- › Separate connection box (IP21) with two break throughs



Made to order

- › DALI-versions
- › 3000 K-versions



28W	3000 lm	41W	4500 lm
-----	---------	-----	---------

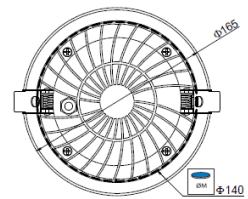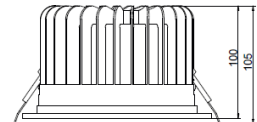

OPU30L

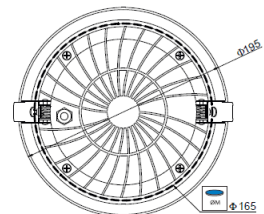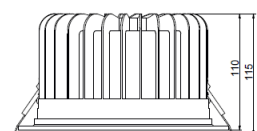

OPU45L

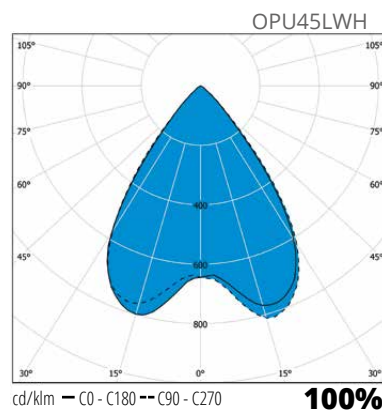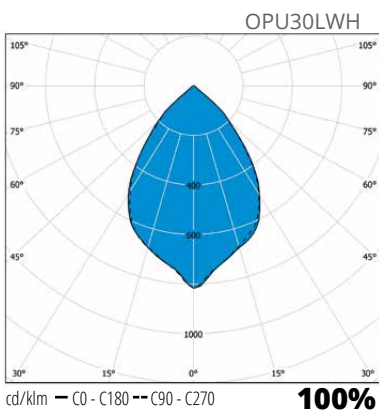

E number	Type	Product name	Power	Base	Kg	Colour	Luminous flux
Opus							
45 032 36	OPU30LWH	OPU30LWH IP65 3000LM 840 GL WH	28W	LED	1,50	White	3000 lm
45 032 46	OPU30LBL	OPU30LBL IP65 3000LM 840 GL BL	28W	LED	1,50	Black	3000 lm
45 032 37	OPU45LWH	OPU45LWH IP65 4500LM 840 GL WH	41W	LED	1,70	White	4500 lm
45 032 47	OPU45LBL	OPU45LBL IP65 4500LM 840 GL BL	41W	LED	1,70	Black	4500 lm