


Show

LED

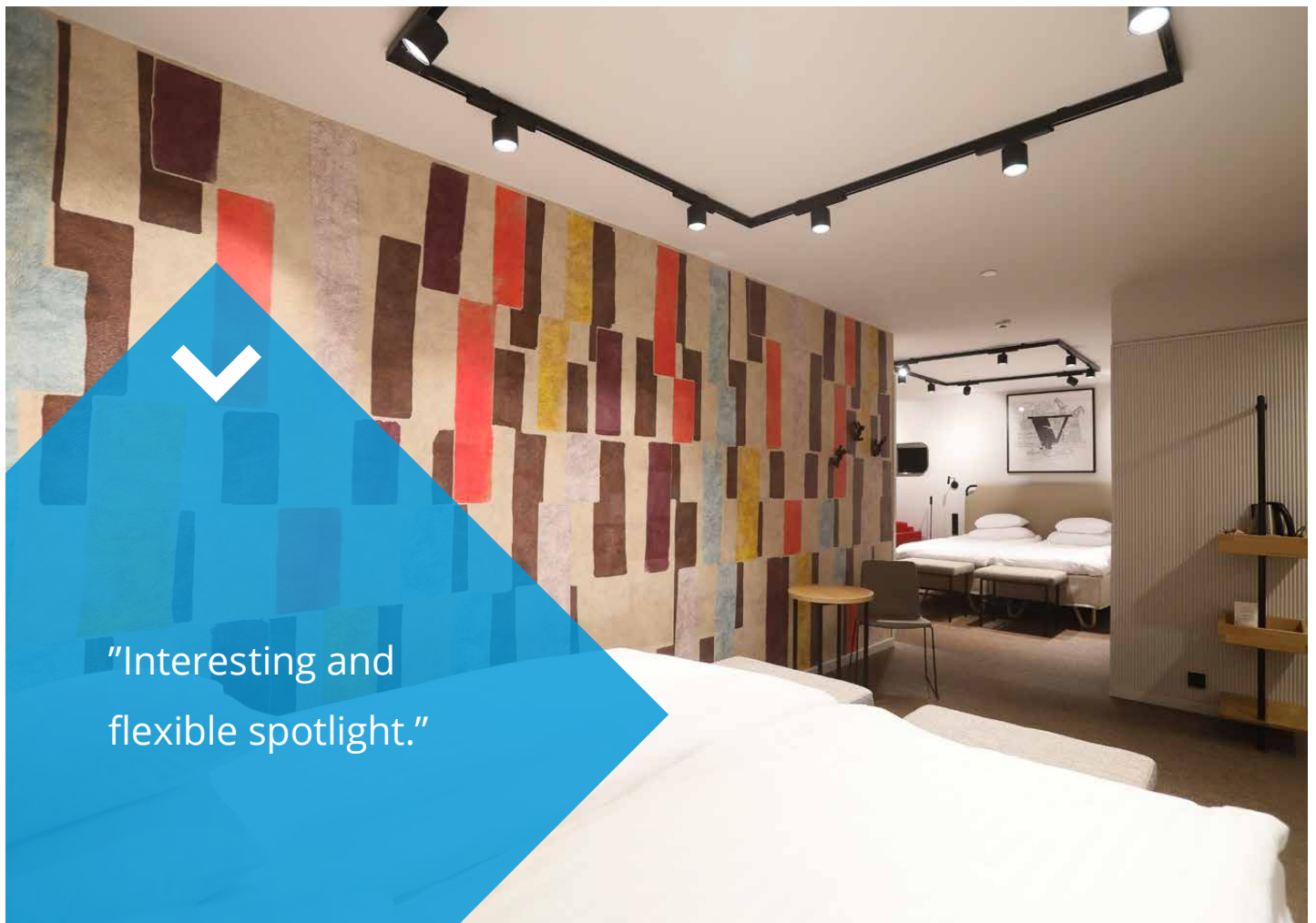

Show is a versatile spotlight which transforms for the requirements in different projects in restaurants, offices and even private homes. Spotlight has dual light beam, which can be easily adjusted and in-built triac dimming which makes Show interesting and flexible luminaire for your project.






Structure

- › Housing: powder coated aluminium
- › Housing colours: White and black
- › Connected power: 13W
- › Beam angles: Dual Beam – selectable 24° or 36°
- › Lumen output: 950 lm and 1000 lm
- › 2800K and 4000K, Ra>80
- › MacAdams 3-SDCM
- › LED module lifetime: 25 000h L80
- › Triac-dimmable with universal led-dimmer, both leading edge & trailing edge

Mounting

- › 3 phase track

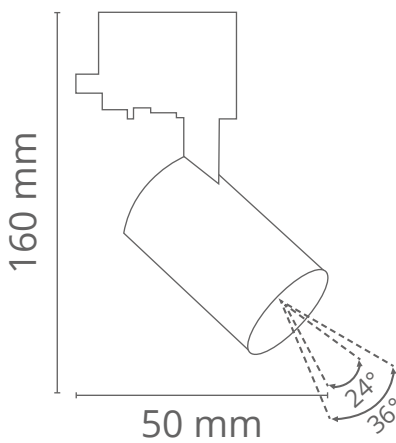

E number	Type	Product name	Base	Colour	Kg	Beam angle	Connected load	Luminous flux
Show								
42 170 45	SH950DWH	SHOW 950LM 13W 828 D DB WH	LED	White	0,5	24° / 36°	13W	950 lm
42 170 42	SH950DBL	SHOW 950LM 13W 828 D DB BL	LED	Black	0,5	24° / 36°	13W	950 lm
42 170 39	SH1000DWH	SHOW 1000LM 13W 840 D DB WH	LED	White	0,5	24° / 36°	13W	1000 lm
42 170 36	SH1000DBL	SHOW 1000LM 13W 840 D DB BL	LED	Black	0,5	24° / 36°	13W	1000 lm

