


# Solo

LED



White

Solo illuminates the terraces and entrances in outdoor spaces and canopies. Surface-mounted Solo is a compact, durable and stylish downlight which is suitable for its appearance both home and public spaces.

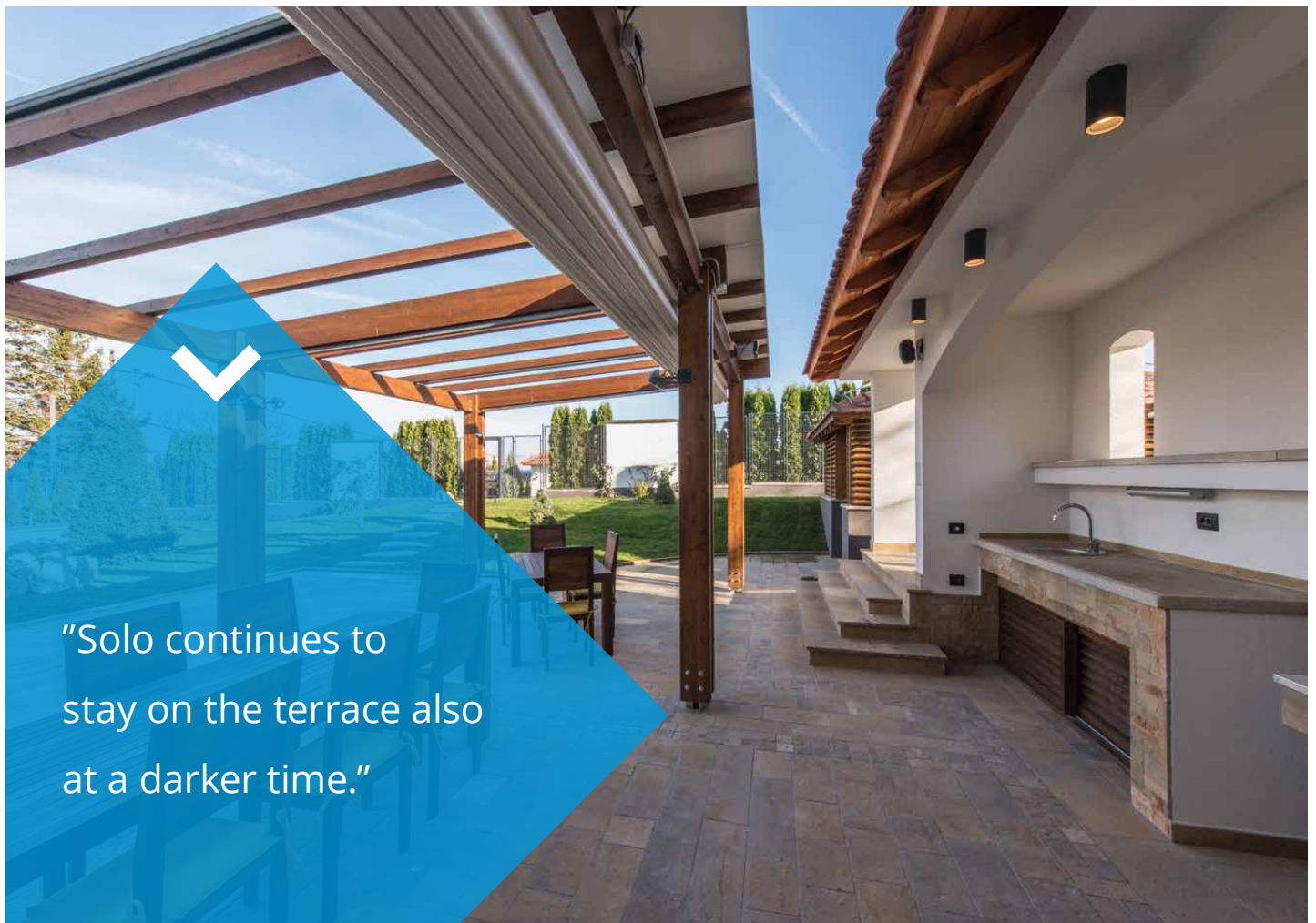

"Solo continues to stay on the terrace also at a darker time."



Black

### Structure

- › Body aluminium
- › Diffuser tempered matt glass
- › Colours: Black and white
- › Selection:
  - Power 20W, luminous flux 1800 lm
  - Power 28W, luminous flux 2400 lm
  - Power 40W, luminous flux 3300 lm
- › Colour temperature 4000 K, Ra>80
- › Power factor 0,95
- › Ambient temperature -20 °C - +30 °C
- › LED-module lifetime 68 000h(L90B10) T<sub>a</sub>=25 °C



### Mounting

- › Installation on the ceiling surface, ended 3x1,5 mm<sup>2</sup>
- › Breakthrough in the installation plate and the connection box
- › Fixing screws are not included

### Made to order

- › DALI-versions
- › 3000 K-versions

20W	1800 lm	28W	2400 lm	40W	3300 lm
-----	---------	-----	---------	-----	---------

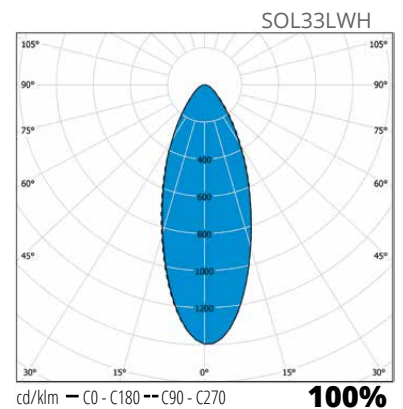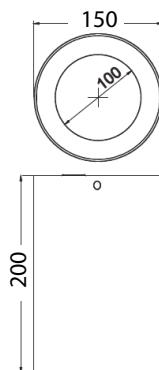

E number	Type	Product name	Power	Base	Kg	Colour	Luminous flux
<b>Solo</b>							
45 032 40	SOL18LWH	SOL18LWH IP65 1800LM 840 GL WH	20W	LED	1,00	White	1800 lm
45 032 38	SOL18LBL	SOL18LBL IP65 1800LM 840 GL BL	20W	LED	1,00	Black	1800 lm
45 032 43	SOL24LWH	SOL24LWH IP65 2400LM 840 GL WH	28W	LED	1,00	White	2400 lm
45 032 41	SOL24LBL	SOL24LBL IP65 2400LM 840 GL BL	28W	LED	1,00	Black	2400 lm
45 032 45	SOL33LWH	SOL33LWH IP65 3300LM 840 GL WH	40W	LED	1,00	White	3300 lm
45 032 44	SOL33LBL	SOL33LBL IP65 3300LM 840 GL BL	40W	LED	1,00	Black	3300 lm

