

Tube

LED

Tube is tough and affordable LED-luminaire for many different locations and projects. Through wired Tube is easy and fast to install and fits perfectly to garages, parking halls and warehouses.



"Affordable luminaire
for many projects."



Structure





- › Body and diffuser polycarbonate
- › Toggles stainless steel
- › Led not changeable
- › IP65, IK08
- › 4000 K, Ra>80
- › Ambient temperature -30 °C – +45 °C
- › LED-module lifespan 50 000 h (L70), T_a=25 °C

Control

- › On/off
- › DALI

Mounting

- › To the ceiling or lighting suspension rail
- › Through-wired, cable entries at the both ends of the luminaire

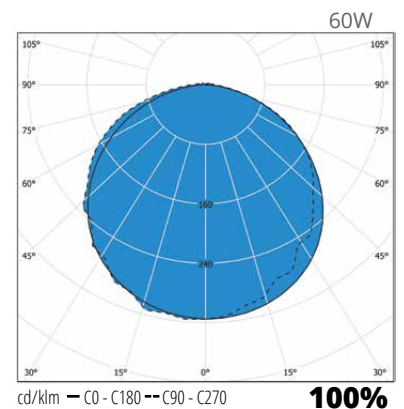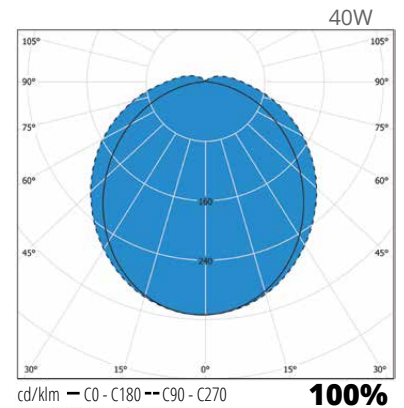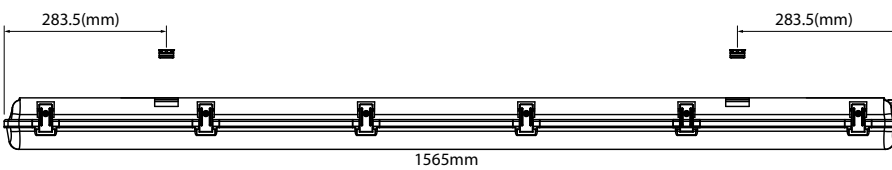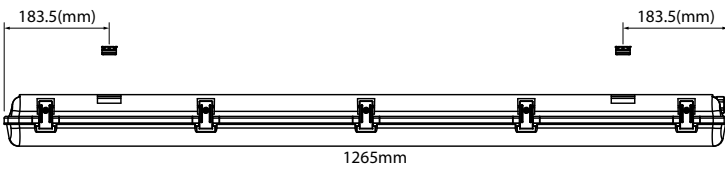

Luminaires per miniature circuit breaker	B10	B16	C10	C16
TU12.4000	11	18	18	30
TU12.4000ED	10	17	16	28
TU15.6000	21	34	35	57
TU15.6000ED	6	10	10	16

E number	Type	Product name	Output	Kg	Length	Width	Height	Luminous flux
Tube								
43 611 83	TU12.4000	TU12.4000 IP65 40W 840 PC O	40W	2,4	1265	130	90	4000 lm
43 611 84	TU12.4000ED	TU12.4000ED IP65 40W 840 PC O DALI	40W	2,6	1265	130	90	4000 lm
43 611 85	TU15.6000	TU15.6000 IP65 60W 840 PC O	60W	2,8	1565	130	90	6000 lm
43 611 86	TU15.6000ED	TU15.6000ED IP65 60W 840 PC O DALI	60W	3,0	1565	130	90	6000 lm