

Velox Frameless

LED

Velox product family is designed to cover basic needs of lighting at home by LED-solutions. Frameless Velox LED-panels fit excellent for universal lighting at home both in new construction and renovations.



ALFD155PU



ALFD125NU

DALI

DALI drivers enable luminaires to be connected to DALI based control systems and Smart Buildings. Compared to a fixed output installation, the dimming and individual control capability provided by DALI enables considerable energy savings and control, depending on luminaire specifications.

Dimming

Ensto can provide many dimming possibilities for luminaires. 1-10V, Switch Dim, DALI and base light are just few examples of possibilities to change the light output to fit your premises.



“Unlimited lighting for all premises.”



ALFD215PU



ALFD125WNU

Structure

- ▶ Body aluminium
- ▶ Front plate made of light spreading opal sheet
- ▶ Dimmable (triac) LED-driver included
- ▶ Models:
DALI
Connected load 11W, 15W, 22W, 30W
See the luminaire luminous flux from the table below
4000 K or 3000 K, Ra > 80, power factor 0,92
Ambient temperature - 20 °C - + 30 °C
LED-luminaire lifespan 50 000 h (L70), T_a=25 °C
Triac-dimmable, check the recommended dimmers at the WEB-site www.ensto.com


Mounting

- ▶ Recess mounting
- ▶ -o- 2x1,5 mm², a separate junction box is included in the delivery

E number	Type	Product name	Output	Base	Kg	Luminous flux
Square						
41 034 45	ALFD125NU	ALFD125NU IP44 11W/840 LED	11W	LED	0,3	820 lm
41 034 49	ALFD125WNU	ALFD125WNU IP44 11W/830 LED	11W	LED	0,3	800 lm
41 035 74	ALFD215NU	ALFD215NU IP44 27W 840	27W	LED	0,7	2050 lm
41 173 17	ALFD215WNU	ALFD215NU IP44 27W 830	27W	LED	0,7	1870 lm
Square, DALI						
41 035 95	ALFD125NUED	ALFD125NU IP44 11W 840 DALI	11W	LED	0,3	820 lm
41 035 97	ALFD125WNUED	ALFD125WNU IP44 11W 830 DALI	11W	LED	0,3	800 lm
41 172 98	ALFD215NUED	ALFD215NU IP44 27W 840 DALI	27W	LED	0,7	2050 lm
41 173 19	ALFD215WNUED	ALFD215WNU IP44 27W 830 DALI	27W	LED	0,7	1870 lm
Round						
41 034 46	ALFD125PU	ALFD125PU IP44 11W/840 LED	11W	LED	0,3	760 lm
41 034 51	ALFD125WPU	ALFD125WPU IP44 11W/830 LED	11W	LED	0,3	740 lm
41 034 52	ALFD155PU	ALFD155PU IP44 15W/840 LED	15W	LED	0,4	1120 lm
41 034 54	ALFD155WPU	ALFD155WPU IP44 15W/830 LED	15W	LED	0,4	1100 lm
41 034 55	ALFD185PU	ALFD185PU IP44 22W/840 LED	22W	LED	0,5	1490 lm
41 034 56	ALFD185WPU	ALFD185WPU IP44 22W/830 LED	22W	LED	0,5	1470 lm
41 034 57	ALFD215PU	ALFD215PU IP44 30W/840 LED	30W	LED	0,7	2130 lm
41 034 58	ALFD215WPU	ALFD215WPU IP44 30W/830 LED	30W	LED	0,7	1950 lm
Round, DALI						
41 035 96	ALFD125PUED	ALFD125PU IP44 11W 840 DALI	11W	LED	0,3	760 lm
41 035 98	ALFD125WPUED	ALFD125WPU IP44 11W 830 DALI	11W	LED	0,3	740 lm
41 035 99	ALFD155PUED	ALFD155PU IP44 15W 840 DALI	15W	LED	0,4	1120 lm
41 171 10	ALFD155WPUED	ALFD155WPU IP44 15W 830 DALI	15W	LED	0,4	1100 lm
41 172 90	ALFD185PUED	ALFD185PU IP44 22W 840 DALI	22W	LED	0,5	1490 lm
41 172 92	ALFD185WPUED	ALFD185WPU IP44 22W 830 DALI	22W	LED	0,5	1470 lm
41 172 93	ALFD215PUED	ALFD215PU IP44 30W 840 DALI	30W	LED	0,7	2130 lm
41 172 95	ALFD215WPUED	ALFD215WPU IP44 30W 830 DALI	30W	LED	0,7	1950 lm




ALFD125NU

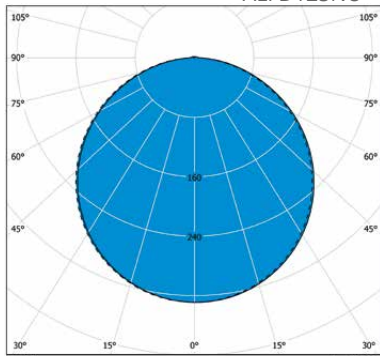



cd/klm — C0 - C180 -- C90 - C270 **100%**

ALFD185PU

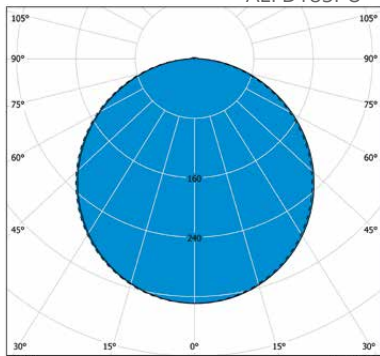

cd/klm — C0 - C180 -- C90 - C270 **100%**

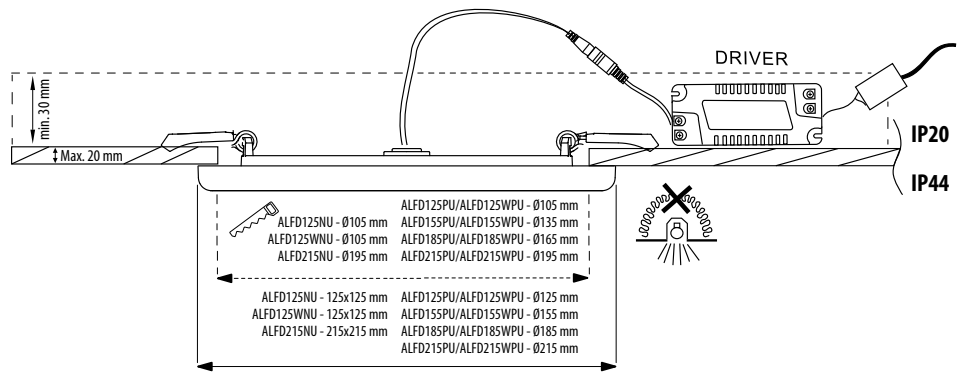

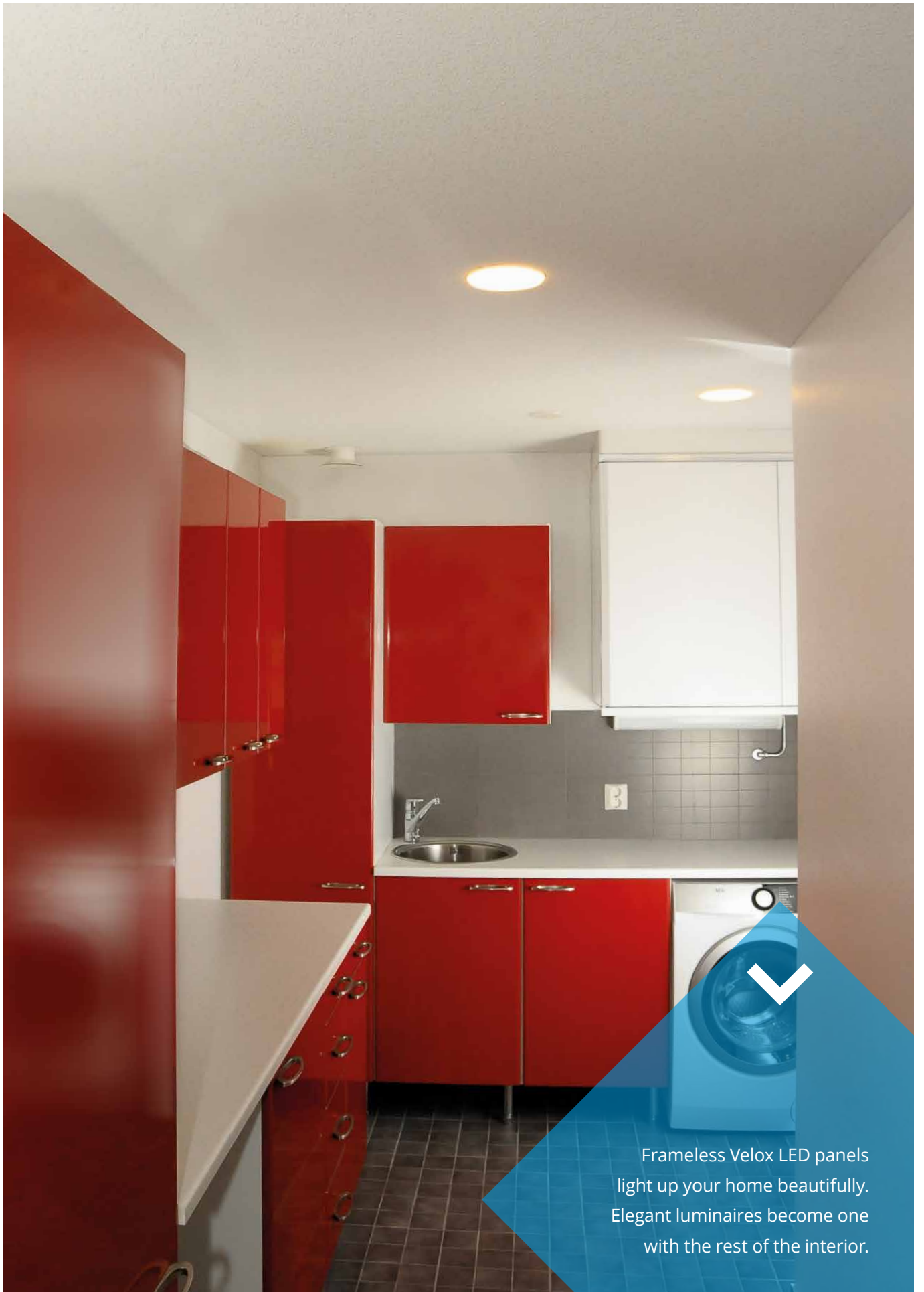

Frameless Velox LED panels
light up your home beautifully.
Elegant luminaires become one
with the rest of the interior.

