



Viva

LED

Experience the New Era of Outdoor Lighting With Viva, where innovation and practicality seamlessly come together. The Viva façade luminaire is not only stylish but also a practical solution, equipped with integrated power outlets, long-lasting components, and adjustable color temperature.



DualWhite

Ensto luminaires with DualWhite -solution are equipped with integrated option for light colour temperature switching. You can easily switch between 3000K and 4000K which saves your SKUs and gives you possibility to change colour temperature according to project, with one luminaire.



Dual White

1 Luminaire,
2 Colour temperatures



"VIVA - Lighting
and Power in Perfect
Harmony!"



VIVA12.SGH/DW





VIVA12.SWH/DW

Structure

- › Body casted aluminium
- › The color temperature can be selected and both the up and down light can be controlled using the driver device's DIP switches
- › Connected load 10W, total luminous flux 1200 lm (400 lm uplight, 800 lm downlight)
- › Uplight on/off selectable via dipswitch
- › Ra>80, power factor 0,92
- › Ambient temperature - 40 °C - + 25 °C
- › LED driver lifetime T_a=25 °C: 100 000 h (L80)

Mounting

- › To the surface
- › Snap-in terminal block 3x1,5 mm² - 3x2,5 mm²
- › Versions with electrical sockets: double schuko 16A/250V

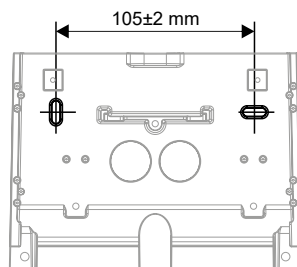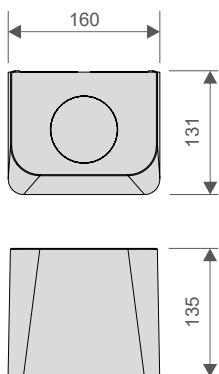

E number	Type	Product name	Base	Kg	Luminous flux	Additional information
Viva						
45 033 71	VIVA12.GH/DW	VIVA GH 10W 830/840 IP44	LED	0,95	1200 lm	grey
45 033 73	VIVA12.WH/DW	VIVA WH 10W 830/840 IP44	LED	0,95	1200 lm	white
Viva with a socket						
45 033 72	VIVA12.SGH/DW	VIVA SGH 10W 830/840 IP44	LED	1,0	1200 lm	grey
45 033 74	VIVA12.SWH/DW	VIVA SWH 10W 830/840 IP44	LED	1,0	1200 lm	white

