


FC54/50 → FC54/100 - FASCLIC+




FC54/150 → FC54/600 - FASCLIC+

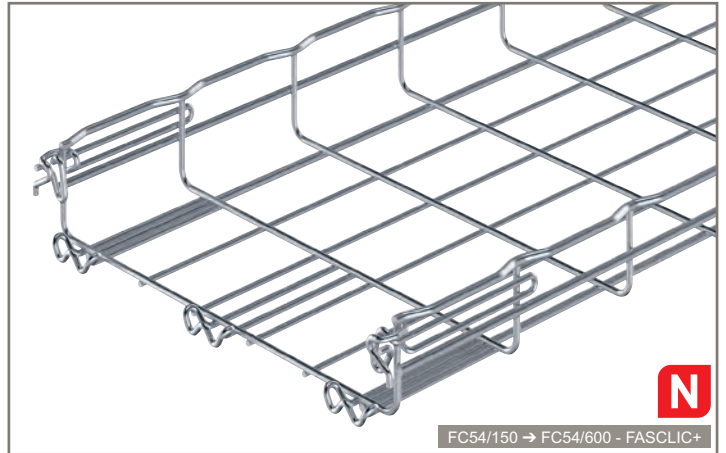





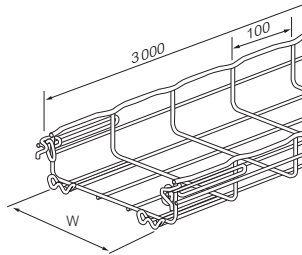


 Loading graphs **p. 65**
Dimensions and technical information **p. 65**

NOTE : please use Cat. No. when placing your order

FC54 - FASCLIC+ – straight lengths (3 m)


↓ 54 mm ↔ 50 mm → 600 mm ↔ 3 m









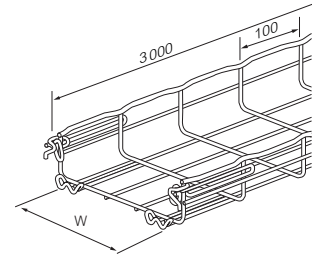


Pack	Cat. Nos.				
	EZ	HR			
1	CM200061	CM200066	FC54/50	50	
1	CM200071	CM200076	FC54/100	100	
1	CM200081	CM200086	FC54/150	150	
1	CM200091	CM200096	FC54/200	200	
1	CM200101	CM200106	FC54/300	300	
1	CM200201	CM200206	FC54/400	400	
1	CM200251	CM200256	FC54/450	450	
1	CM200301	CM200306	FC54/500	500	
1	CM200401	CM200406	FC54/600	600	

FC54 - FASCLIC+ stainless steel – straight lengths (3 m)

↓ 54 mm ↔ 50 mm → 600 mm ↔ 3 m



Pack	Cat. Nos.				
	304L	316L			
1	CM200068	CM200064	FC54/50	50	
1	CM200078	CM200074	FC54/100	100	
1	CM200088	CM200084	FC54/150	150	
1	CM200098	CM200094	FC54/200	200	
1	CM200108	CM200104	FC54/300	300	
1	CM200208	CM200204	FC54/400	400	
1	CM200258	CM200254	FC54/450	450	
1	CM200308	CM200304	FC54/500	500	
1	CM200408	CM200404	FC54/600	600	

Key: **EZ** Electrogalvanised after manufacture **304L** Stainless steel 304 L
HR High Resistance* **316L** Stainless steel 316 L

* For more information on High Resistance finish **p. 12-13, 150** For detailed information related to finishes, refer to **p. 150-151**

All dimensions (mm) are nominal