
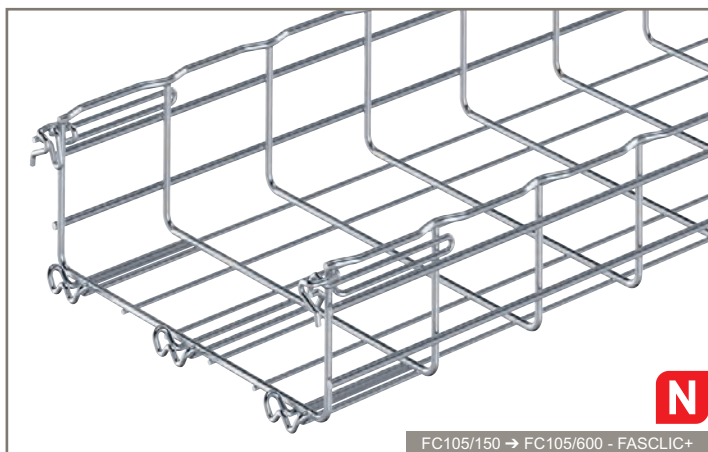


straight lengths - FC105 - FASCLIC+ N

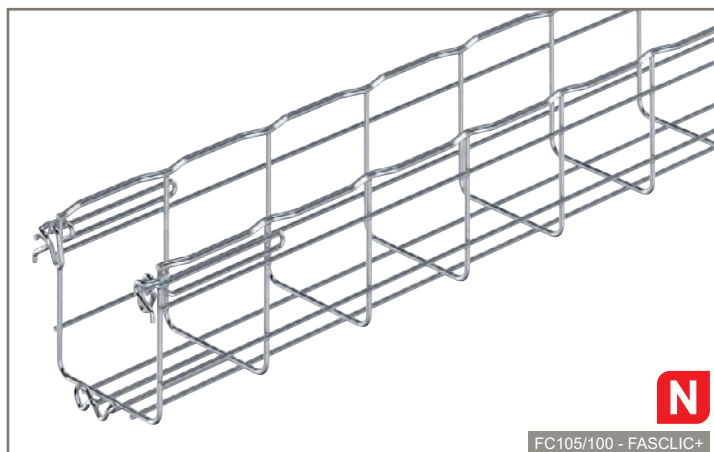

Loading graphs **p. 66**
 Dimensions and technical information **p. 66**

NOTE : please use Cat. No. when placing your order

Pack	Cat. Nos.		FC105 - FASCLIC+ – straight lengths (3 m)	
			$\downarrow \uparrow 105 \text{ mm}$	$\leftarrow \rightarrow 100 \text{ mm} \rightarrow 600 \text{ mm} \rightleftarrows 3 \text{ m}$
	EZ	HR	Width (mm)	
1	CM200891	CM200896	FC105/100	100
1	CM200901	CM200906	FC105/150	150
1	CM200911	CM200916	FC105/200	200
1	CM200921	CM200926	FC105/300	300
1	CM200931	CM200936	FC105/400	400
1	CM201931	CM201936	FC105/450	450
1	CM200941	CM200946	FC105/500	500
1	CM201031	CM201036	FC105/600	600

Pack	Cat. Nos.		FC105 - FASCLIC+ stainless steel – straight lengths (3 m)	
			$\downarrow \uparrow 105 \text{ mm}$	$\leftarrow \rightarrow 100 \text{ mm} \rightarrow 600 \text{ mm} \rightleftarrows 3 \text{ m}$
	304L	316L	Width (mm)	
1	CM200898	CM200894	FC105/100	100
1	CM200908	CM200904	FC105/150	150
1	CM200918	CM200914	FC105/200	200
1	CM200928	CM200924	FC105/300	300
1	CM200938	CM200934	FC105/400	400
1	CM201938	CM201934	FC105/450	450
1	CM200948	CM200944	FC105/500	500
1	CM201038	CM201034	FC105/600	600

Key: EZ	Electrogalvanised after manufacture	304L	Stainless steel 304 L
HR	High Resistance*	316L	Stainless steel 316 L
* For more information on High Resistance finish p. 12-13, 150		For detailed information related to finishes, refer to p. 150-151	

All dimensions (mm) are nominal