


straight lengths - CF105

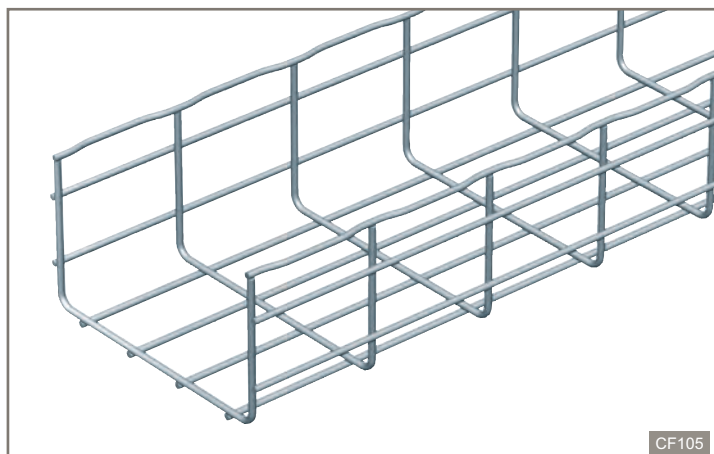

Loading graphs **p. 70**
 Dimensions and technical information **p. 70**

NOTE : please use Cat. No. when placing your order

Pack	Cat. Nos.		CF105 – straight lengths (3 m)	
			For length to length coupling options : • EDRN, see p. 32 • ED275 + KITFIXTR / KITFIXVS, see p. 32, 37 • KITASSTR / KITASSVS, see p. 37	
			Width (mm)	
	EZ	GC		
1	CM000891	CM000893	CF105/100	
1	CM000901	CM000903	CF105/150	
1	CM000911	CM000913	CF105/200	
1	CM000921	CM000923	CF105/300	
1	CM000931	CM000933	CF105/400	
1	CM001931	CM001933	CF105/450	
1	CM000941	CM000943	CF105/500	
1	CM001031	CM001033	CF105/600	
		HR		
1	CM000896		CF105/100	
1	CM000906		CF105/150	
1	CM000916		CF105/200	
1	CM000926		CF105/300	
1	CM000936		CF105/400	
1	CM001936		CF105/450	
1	CM000946		CF105/500	
1	CM001036		CF105/600	

Pack	Cat. Nos.		CF105 stainless steel – straight lengths (3 m)	
			For length to length coupling options : • ED275 + CE25 + BTRCC 6 x 20, see p. 32, 36, 61 • KITINOX, see p. 37	
			Width (mm)	
	304L	316L		
1	CM000898	CM000894	CF105/100	
1	CM000908	CM000904	CF105/150	
1	CM000918	CM000914	CF105/200	
1	CM000928	CM000924	CF105/300	
1	CM000938	CM000934	CF105/400	
1	CM001938	CM001934	CF105/450	
1	CM000948	CM000944	CF105/500	
1	CM001038	CM001034	CF105/600	

Key: EZ	Electrogalvanised after manufacture	304L	Stainless steel 304 L
GC	Hot dip galvanised after manufacture	316L	Stainless steel 316 L
HR	High Resistance*		

* For more information on High Resistance finish **p. 12-13, 150**

For detailed information related to finishes, refer to **p. 150-151**

All dimensions (mm) are nominal