
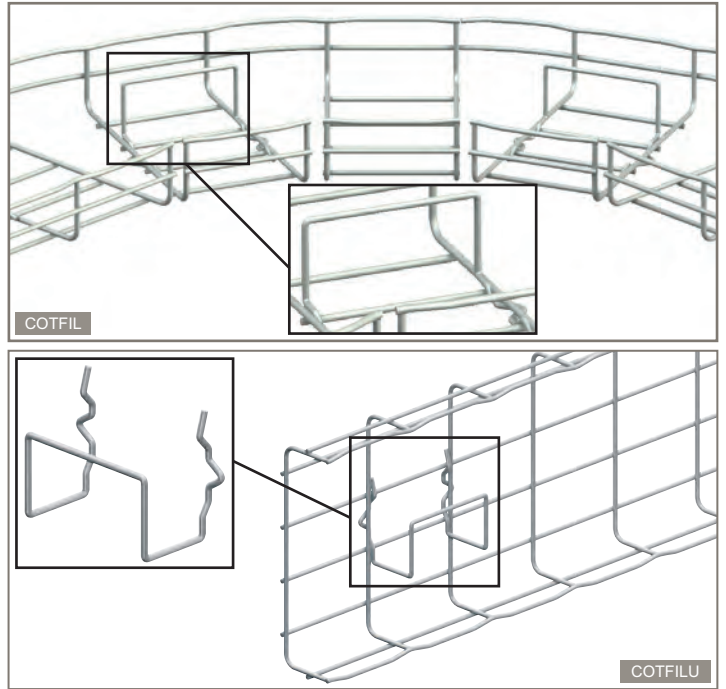


## straight length dividers - COT - COT J

## bend dividers - COTFIL - COTFILU

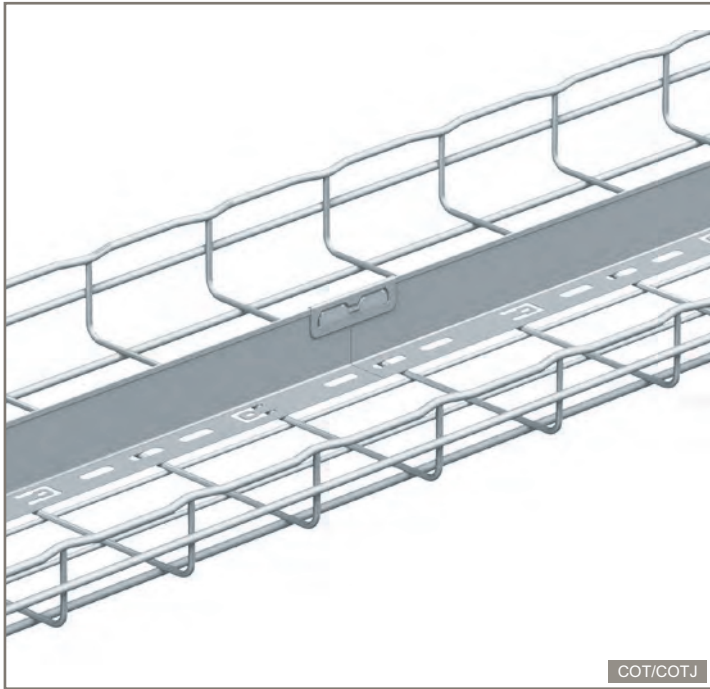

Dimensions and technical information p. 78

Dimensions and technical information p. 79

**NOTE : please use Cat. No. when placing your order**

**NOTE : please use Cat. No. when placing your order**

Pack	Cat. Nos.	COT – dividers (3 m)	H mm
		↓↑ 30 → 105 mm ↻ 100 → 600 mm	
1	<b>GS</b> CM923010   <b>HR</b> CM923013	For tray depth 30 mm (CF30) COT30	24
1	CM923020   CM923023	For tray depth 54 mm (CF54) COT50	48
1	CM923040   CM923043	For tray depth 105 mm (CF105 and CF150) COT100	96

Pack	Cat. Nos.	COT stainless steel – dividers (3 m)	H mm
		↓↑ 30 → 105 mm ↻ 100 → 600 mm	
1	<b>304L</b> -   <b>316L</b> CM923014	For tray depth 30 mm (CF30) COT30	24
1	CM923028   CM923024	For tray depth 54 mm (CF54) COT50	48
1	CM923048   CM923044	For tray depth 105 mm (CF105 and CF150) COT100	96

Pack	Cat. Nos.	COT J – divider connectors	H mm
		↓↑ 30 → 105 mm ↻ 100 → 600 mm	
1	<b>GS</b> CM923050   <b>316L</b> CM923054		21

Pack	Cat. Nos.	COTFIL – bend dividers	H mm
		↓↑ 30 → 105 mm ↻ 100 → 600 mm	
1	<b>EZ</b> CM586711   <b>304L</b> CM586718	For tray depth 30 mm (CF30) COTFIL30	24
1	CM586721   CM586728	For tray depth 54 mm (CF54) COTFIL50	44
1	CM586741   CM586748	For tray depth 105 mm (CF105) COTFIL100	94

Pack	Cat. Nos.	COTFILU – cable guide	H mm
		↓↑ 54 mm ↻ 150 → 600 mm	
12	<b>EZ</b> CM350524   <b>304L</b> CM350531	For tray depth 54 mm (CF54 see p. 22)	47

<b>Key:</b> <b>GS</b> Pre-galvanised	<b>304L</b> Stainless steel 304 L
<b>EZ</b> Electrogalvanised after manufacture	<b>316L</b> Stainless steel 316 L
<b>HR</b> High Resistance*	

\* For more information on High Resistance finish p. 12-13, 150

For detailed information related to finishes, refer to p. 150-151

All dimensions (mm) are nominal