



EDRN



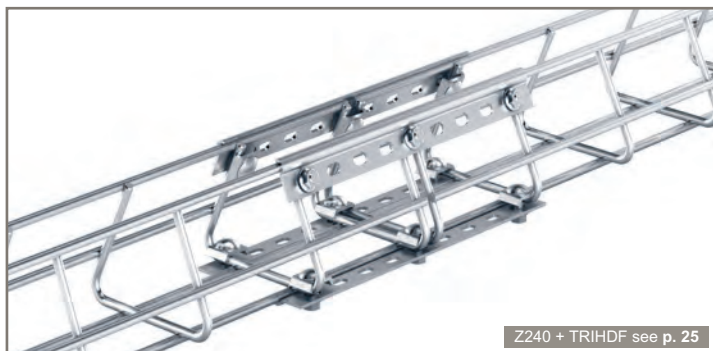

 

Z240 + TRIHDF see p. 25

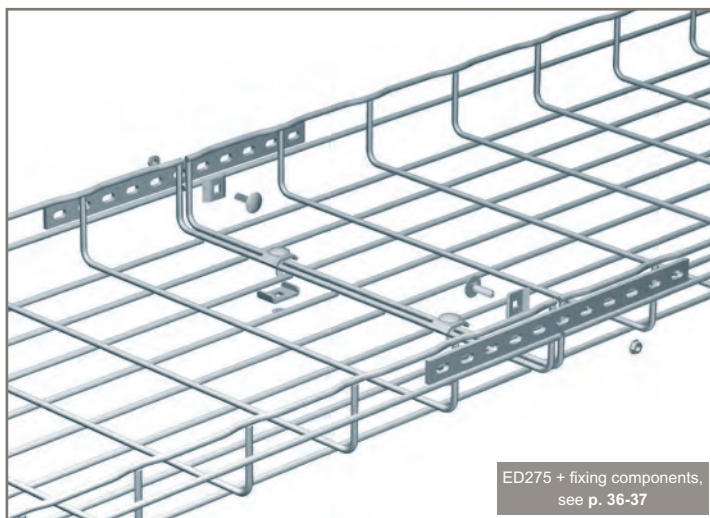


ED275 + fixing components, see p. 36-37

 Dimensions and technical information **p. 81-83**


NOTE : please use Cat. No. when placing your order


Pack	Cat. Nos.	EDRN – couplers
50	 CM558241  CM558246	↳ 30 → 150 mm ↳ 50 → 600 mm Supplied with one fixing tool in each pack of 50 couplers For technical information, see p. 81
50	 CM558242	
1	 CM558244	


EZ+ colour : black

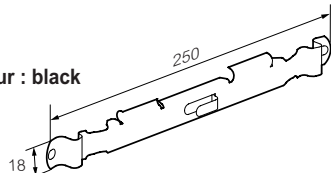



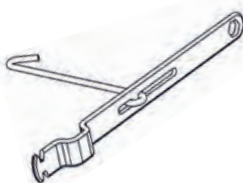


Pack	Cat. Nos.	OUTCAB – fixing tool
5	 CM558260	For EDRN couplers
1	-	

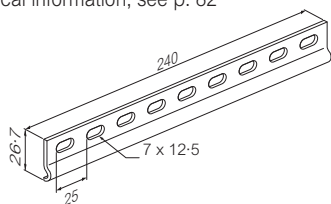






Pack	Cat. Nos.	Z240 – joint strips
50	 CM558293	↳ 80 mm ↳ 100 mm For TRIHDF, see p. 25 For technical information, see p. 82

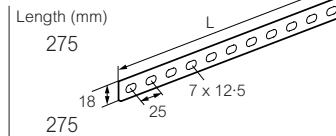


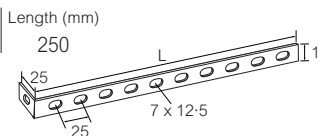
Pack	Cat. Nos.	ED275 – joint strips
50	 CM558221  CM558226	↳ 30 → 150 mm ↳ 50 → 600 mm For fixing kits KITASSTR, KITFIXVS, KITASSVS and KITINOX, see p. 37 For technical information, see p. 83
1	 CM558228  CM558224	





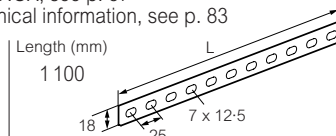




Pack	Cat. Nos.	ED1100 – joint strips
1	 CM558201  CM558206	↳ 30 → 150 mm ↳ 50 → 600 mm Cut to specific length required For fixing kits KITASSTR, KITFIXVS, KITASSVS and KITINOX, see p. 37 For technical information, see p. 83
1	 -  CM558204	



Pack	Cat. Nos.	ED250/90 – angle joint strips
50	 CM558211	↳ 30 → 150 mm ↳ 50 → 600 mm For technical information, see p. 82



Key:	 Electrogalvanised after manufacture	 Stainless steel 304 L
	 Additional coating after electrogalvanisation (black)	 Stainless steel 316 L
	 Hot dip galvanised after manufacture	 Stainless steel 301 L
	 High Resistance*	

* For more information on High Resistance finish **p. 12-13, 150**

For detailed information related to finishes, refer to **p. 150-151**

All dimensions (mm) are nominal