



ceiling mounting - AS - CSNC

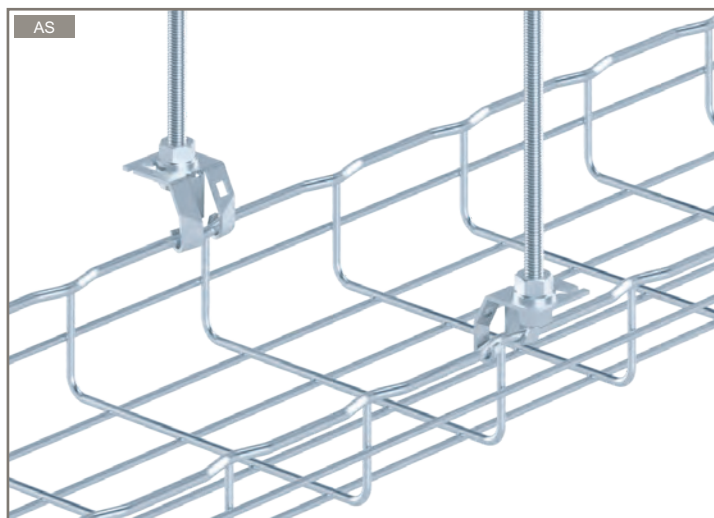

Dimensions and technical information p. 116-117

NOTE : please use Cat. No. when placing your order

Pack	Cat. Nos.	AS – suspension hooks
		$\downarrow \uparrow$ 30 → 150 mm \curvearrowright 100 → 600 mm For technical information, see p. 116
1	CM350581 CM350582 	\downarrow daN 100
1	CM350583	100

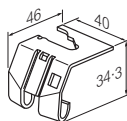

Pack	Cat. Nos.	CSNC – profile roof cantilever arms																																																																																				
		$\downarrow \uparrow$ 30 → 150 mm \curvearrowright 100 → 450 mm For technical information, see p. 117																																																																																				
		<table border="1"> <thead> <tr> <th></th> <th></th> <th></th> <th></th> <th>L1 mm</th> <th>L2 mm</th> <th>\downarrow daN</th> </tr> </thead> <tbody> <tr> <td>1</td> <td>CM556300</td> <td>CM556303</td> <td>CSNC100</td> <td>170</td> <td>178</td> <td>120</td> </tr> <tr> <td>1</td> <td>CM556310</td> <td>CM556313</td> <td>CSNC150</td> <td>170</td> <td>228</td> <td>100</td> </tr> <tr> <td>1</td> <td>CM556320</td> <td>CM556323</td> <td>CSNC200</td> <td>170</td> <td>278</td> <td>80</td> </tr> <tr> <td>1</td> <td>CM556330</td> <td>CM556333</td> <td>CSNC300</td> <td>288</td> <td>378</td> <td>70</td> </tr> <tr> <td>1</td> <td>CM556340</td> <td>CM556343</td> <td>CSNC400</td> <td>288</td> <td>478</td> <td>48</td> </tr> <tr> <td>1</td> <td>CM556350</td> <td>CM556353</td> <td>CSNC450</td> <td>288</td> <td>528</td> <td>44</td> </tr> <tr> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> <td></td> </tr> <tr> <td>1</td> <td>CM556304</td> <td></td> <td>CSNC100</td> <td>170</td> <td>178</td> <td>120</td> </tr> <tr> <td>1</td> <td>CM556314</td> <td></td> <td>CSNC150</td> <td>170</td> <td>228</td> <td>100</td> </tr> <tr> <td>1</td> <td>CM556324</td> <td></td> <td>CSNC200</td> <td>170</td> <td>278</td> <td>80</td> </tr> <tr> <td>1</td> <td>CM556334</td> <td></td> <td>CSNC300</td> <td>170</td> <td>378</td> <td>70</td> </tr> </tbody> </table>					L1 mm	L2 mm	\downarrow daN	1	CM556300	CM556303	CSNC100	170	178	120	1	CM556310	CM556313	CSNC150	170	228	100	1	CM556320	CM556323	CSNC200	170	278	80	1	CM556330	CM556333	CSNC300	288	378	70	1	CM556340	CM556343	CSNC400	288	478	48	1	CM556350	CM556353	CSNC450	288	528	44								1	CM556304		CSNC100	170	178	120	1	CM556314		CSNC150	170	228	100	1	CM556324		CSNC200	170	278	80	1	CM556334		CSNC300	170	378	70
				L1 mm	L2 mm	\downarrow daN																																																																																
1	CM556300	CM556303	CSNC100	170	178	120																																																																																
1	CM556310	CM556313	CSNC150	170	228	100																																																																																
1	CM556320	CM556323	CSNC200	170	278	80																																																																																
1	CM556330	CM556333	CSNC300	288	378	70																																																																																
1	CM556340	CM556343	CSNC400	288	478	48																																																																																
1	CM556350	CM556353	CSNC450	288	528	44																																																																																
1	CM556304		CSNC100	170	178	120																																																																																
1	CM556314		CSNC150	170	228	100																																																																																
1	CM556324		CSNC200	170	278	80																																																																																
1	CM556334		CSNC300	170	378	70																																																																																

Pack	Cat. Nos.	EPVCSN – end caps
1	CM559605	For use with CSNC cantilever arms



Key: Pre-galvanised Stainless steel 316 L

Hot dip galvanised after manufacture PVC

High Resistance*

* For more information on High Resistance finish p. 12-13, 150 For detailed information related to finishes, refer to p. 150-151

All dimensions (mm) are nominal