


ceiling mounting - CB - R41SP - PFR41S

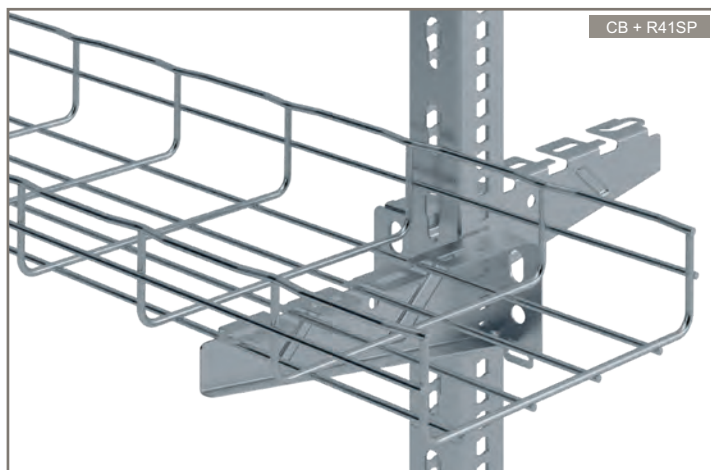

Dimensions and technical information p. 98-99, 121

NOTE : please use Cat. No. when placing your order

Pack	Cat. Nos.		CB – compact cantilever arms for universal mounting 50-600				
			$\downarrow \uparrow$ 30 → 150 mm $\leftarrow \rightarrow$ 50 → 600 mm For technical information, including safe working load, see p. 98-99				
			CB100-400				
	GS	HR		L mm	H mm	\downarrow daN	For tray widths mm
1	CM350800	—	CB50	81	71	80	100
1	CM350810	CM350816	CB100	131	71	110	100
1	CM350820	CM350826	CB150	181	75	100	150
1	CM350830	CM350846	CB200	231	75	110	200
1	CM350840	CM350856	CB300	335	88	150	300
1	CM350850	CM350866	CB400	435	102	150	400
	316L	EZ+		L mm	H mm	\downarrow daN	For tray widths mm
1	CM350804	—	CB50	81	71	80	100
1	CM350814	CM350812	CB100	131	71	110	100
1	CM350824	CM350822	CB150	181	75	100	150
1	CM350834	CM350832	CB200	231	75	110	200
1	CM350844	CM350842	CB300	335	88	150	300
1	CM350854	CM350852	CB400	435	102	150	400
			CB450-600				
	GS	HR		L mm	H mm	\downarrow daN	For tray widths mm
1	CM350895	CM350896	CB450	485	137	200	500
1	CM350860	CM350876	CB500	535	137	200	500
1	CM350870	CM350806	CB600	638	137	160	600
	316L	EZ+		L mm	H mm	\downarrow daN	For tray widths mm
1	CM350894	—	CB450	485	137	200	500
1	CM350864	CM350862	CB500	535	137	200	500
1	CM350874	CM350872	CB600	638	137	160	600

Pack	Cat. Nos.		R41SP – pendants / mounting rails (heavy duty)				
			$\downarrow \uparrow$ 30 → 150 mm $\leftarrow \rightarrow$ 100 → 600 mm For technical information, see p. 121				
			R41SP E20 3000				
1	GS	GC		L mm	H mm		
1	CM343930	CM343933	R41SP E20 3000	3000	2		
1	HR	316L		L mm	H mm		
1	CM343936	CM343934	R41SP E20 3000	3000	2		
	GS		PFR41S – pendant mounting plate (heavy duty)				
			$\downarrow \uparrow$ 30 → 150 mm $\leftarrow \rightarrow$ 100 → 600 mm For technical information, see p. 121				
			PFR41S E20 3000				
1	GS			L mm	H mm		
1	CM595380		PFR41S E20 3000	3000	2		

Key:	GS Pre-galvanised	HR High Resistance*
	GC Hot dip galvanised after manufacture	316L Stainless steel 316 L
	EZ+ Additional coating after electrogalvanisation (black)	
* For more information on High Resistance finish p. 12-13, 150		For detailed information related to finishes, refer to p. 150-151

All dimensions (mm) are nominal