
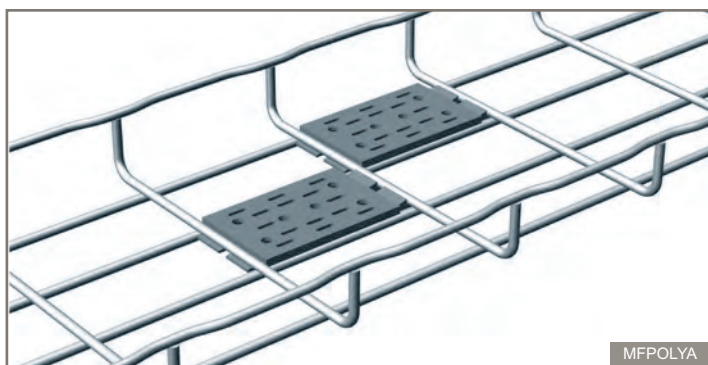
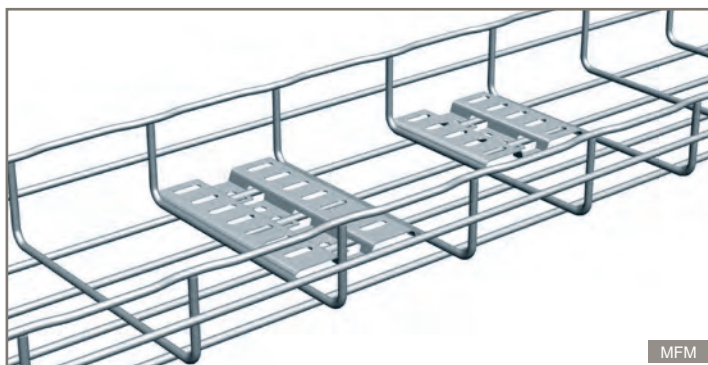


# other mounting - luminaire supports - SL50 - SL100 - MFM - MFPOLYA

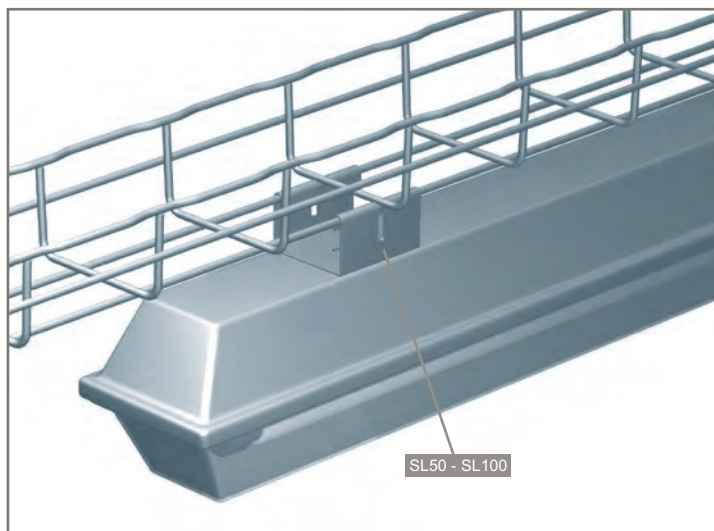

Dimensions and technical information p. 135-136

**NOTE : please use Cat. No. when placing your order**

Pack	Cat. Nos.	Luminaire supports								
1	<div style="text-align: center;">                       CM585180                 </div>	<b>SL50 – luminaire support</b> ⤴ 30 → 54 mm ⤵ 50 mm For technical information see p. 135 <table border="0" style="margin-top: 10px;"> <tr> <td style="text-align: center;">H</td> <td style="text-align: center;">↓ F</td> <td rowspan="2" style="text-align: center;"> </td> </tr> <tr> <td style="text-align: center;">mm</td> <td style="text-align: center;">daN</td> </tr> <tr> <td style="text-align: center;">SL50</td> <td style="text-align: center;">56   150</td> <td></td> </tr> </table>	H	↓ F		mm	daN	SL50	56   150	
H	↓ F									
mm	daN									
SL50	56   150									
1	<div style="text-align: center;">                       CM585190                 </div>	<b>SL100 – luminaire support</b> ⤴ 30 → 105 mm ⤵ 100 → 600 mm For technical information see p. 135 <table border="0" style="margin-top: 10px;"> <tr> <td style="text-align: center;">H</td> <td style="text-align: center;">↓ F</td> <td rowspan="2" style="text-align: center;"> </td> </tr> <tr> <td style="text-align: center;">mm</td> <td style="text-align: center;">daN</td> </tr> <tr> <td style="text-align: center;">SL100</td> <td style="text-align: center;">43   150</td> <td></td> </tr> </table>	H	↓ F		mm	daN	SL100	43   150	
H	↓ F									
mm	daN									
SL100	43   150									

Pack	Cat. Nos.	Luminaire supports (continued)								
1	<div style="display: flex; justify-content: space-around;"> <div style="text-align: center;">                       CM585140                      CM585150                 </div> <div style="text-align: center;">                       CM585143                      CM585153                 </div> </div>	<b>MFM – multifix base plates</b> ⤴ 30 → 150 mm ⤵ 100 → 600 mm For technical information see p. 136 <table border="0" style="margin-top: 10px;"> <tr> <td style="text-align: center;">L</td> <td style="text-align: center;">mm</td> <td rowspan="2" style="text-align: center;"> </td> </tr> <tr> <td style="text-align: center;">MFM100</td> <td style="text-align: center;">100</td> </tr> <tr> <td style="text-align: center;">MFM150</td> <td style="text-align: center;">150</td> <td></td> </tr> </table>	L	mm		MFM100	100	MFM150	150	
L	mm									
MFM100	100									
MFM150	150									
1	<div style="text-align: center;">                       CM585144                 </div>	MFM100 100								
1	<div style="text-align: center;">                       CM585154                 </div>	MFM150 150								
20	<div style="text-align: center;">                       CM585145                 </div>	<b>MFPOLYA – multifix base plate</b> ⤴ 30 → 150 mm ⤵ 100 → 600 mm For technical information see p. 136 <table border="0" style="margin-top: 10px;"> <tr> <td style="text-align: center;">L</td> <td style="text-align: center;">mm</td> <td rowspan="2" style="text-align: center;"> </td> </tr> <tr> <td style="text-align: center;">MFPOLYA</td> <td style="text-align: center;">109</td> </tr> </table>	L	mm		MFPOLYA	109			
L	mm									
MFPOLYA	109									

<b>Key:</b> Pre-galvanised	Stainless steel 316 L
High Resistance*	Plastic
* For more information on High Resistance finish p. 12-13, 150	For detailed information related to finishes, refer to p. 150-151

All dimensions (mm) are nominal