


Armoires 19" Altis™

Dimensions (mm)

Armoires PC IP 55 - IK 10


Réf. 0 474 00/01/02

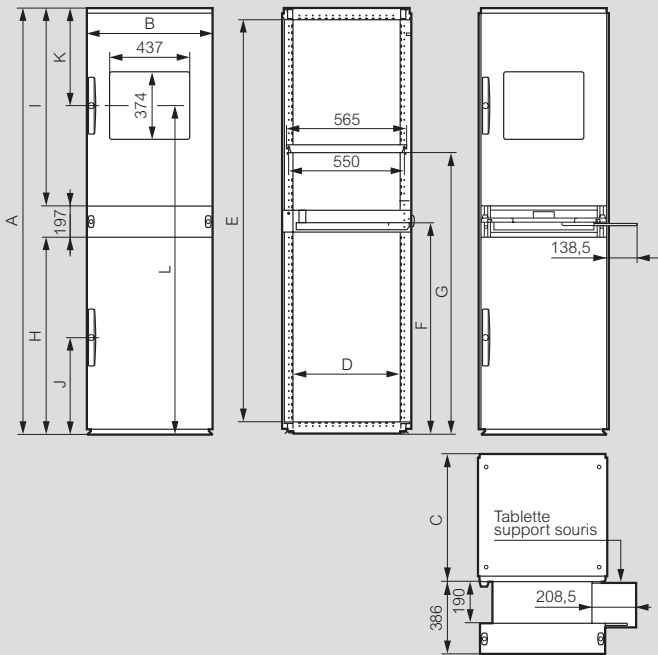

Réf.	Dim.	A	B	C	D	E	F
0 474 00	1600 x 600 x 600	1625	599	606	508	1507	960
0 474 01	1800 x 600 x 600	1825	599	606	508	1707	960
0 474 02	1800 x 600 x 800	1825	599	806	508	1707	960
Réf.	Dim.	G	H	I	J	K	L
0 474 00	1600 x 600 x 600	1135	860	560	460	360	1295
0 474 01	1800 x 600 x 600	1335	860	760	460	410	1495
0 474 02	1800 x 600 x 800	1335	860	760	460	410	1495

Armoires Altis 19"


Hauteur 2000 mm, capacité 42U

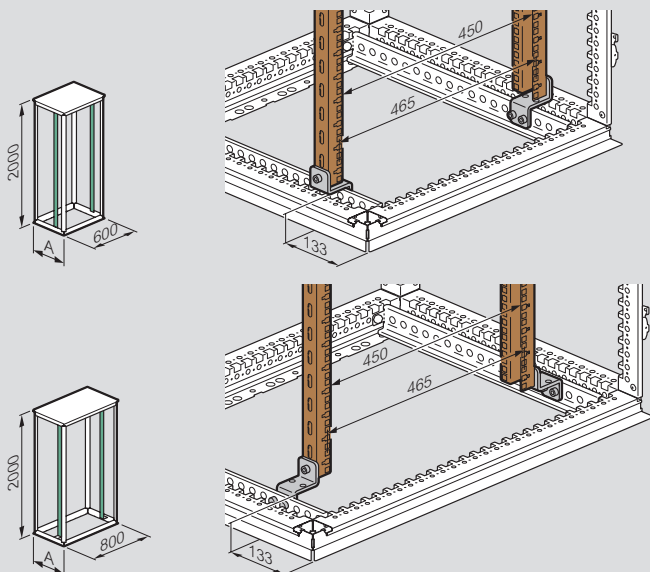


Dim. armoires Haut. x Larg. x Prof.	A
2000 x 600 x 600	599
2000 x 600 x 800	799
2000 x 800 x 600	599
2000 x 800 x 800	799

Montants 19"

Réf. 0 482 20

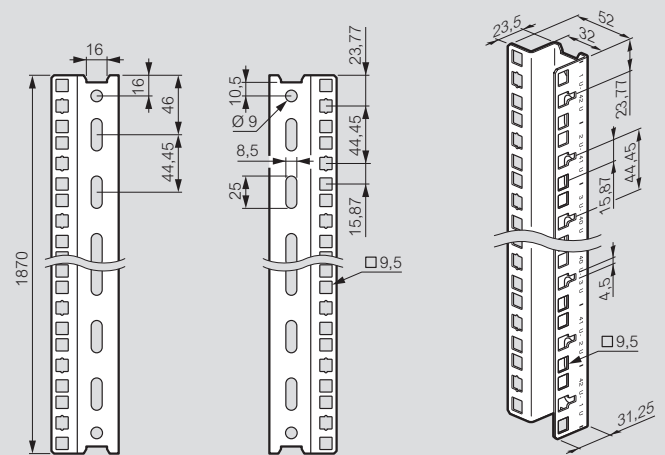


Châssis pivotants 19"

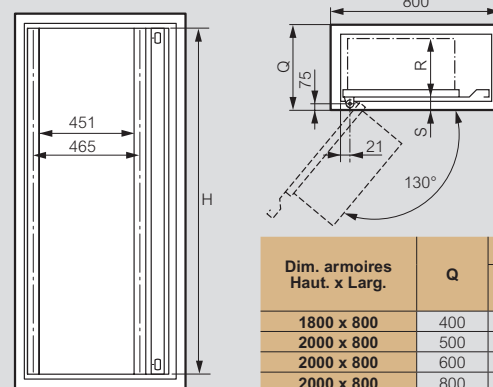

Dim. armoires Haut. x Larg.	Q	Réf. 0 482 03/04		
		R maxi	S	H
1800 x 800	400	300	55	1592
2000 x 800	500	400	55	1792
2000 x 800	600	450	55	1792
2000 x 800	800	450	55	1792

Tablettes

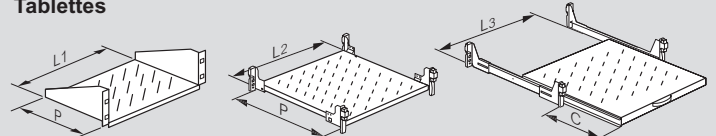

Réf.	P	Largeur utile			C (course)
		L1	L2	L3	
0 465 01	200	435	-	-	-
0 465 02	360	435	-	-	-
0 465 05	425	-	440	-	-
0 465 06	625	-	440	-	-
0 465 08	425	-	-	425	320
0 465 09	625	-	-	425	420