


DRX™ 250 HP accessories



0 271 78



6 693 04

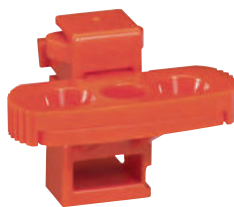

0 271 80



0 271 40



0 271 51



0 271 65

Pack	Cat.Nos	Rotary handles
1	0 271 78	Direct Standard (grey)
1	0 271 79	Vari-depth handle Comprising: connecting rod, bracket, drilling template, mounting accessories, door locking mechanism Standard (grey)
Connection accessories		
Insulating shields Used to isolate the connection between each pole For DRX 125 HP and DRX 250 HP		
1	3P 6 693 00	Set of 2
1	4P 6 693 01	Set of 3
1	6 693 12 6 693 13	Sealable terminal shields Set of 2
1	6 693 04 6 693 05	Cage terminals Up to 250 A
1	6 250 14 6 250 18	Spreaders Set of incoming or outgoing spreaders
Rear terminals Used to convert a fixed version with front terminals into a fixed version with rear terminals		
1	6 693 10	Set of 3 rear terminals
1	6 693 11	Set of 4 rear terminals
1	0 271 80	Padlock for DRX 125, 250, DRX 125 HP and DRX 250 HP For locking on "OFF" position (up to 3 locks)



Pack	Cat.Nos	Control and signalling auxiliaries for DRX 125, DRX 250, DRX 125 HP and DRX 250 HP
Auxiliary contact blocks For left-hand side mounting Up to 250 V~ and =		
1	0 271 40	Block with 1 auxiliary
1	0 271 41	Block with 1 alarm
1	0 271 42	Block with 1 auxiliary + 1 alarm
Shunt trips		
1	0 271 50	12 V~ and =
1	0 271 51	24 V~ and =
1	0 271 52	48 V~ and =
1	0 271 53	100/130 V~
1	0 271 54	200/277 V~
1	0 271 55	380/480 V~
Undervoltage releases		
1	0 271 60	12 V~ and =
1	0 271 61	24 V~ and =
1	0 271 62	48 V~ and =
1	0 271 68	110 V~
1	0 271 63	110/130 V~
1	0 271 64	200/240 V~
1	0 271 67	277 V~
1	0 271 65	380/415 V~
1	0 271 66	440/480 V~

