



DPX<sup>3</sup> 630

■ Dimensions



Fixed version, front terminals

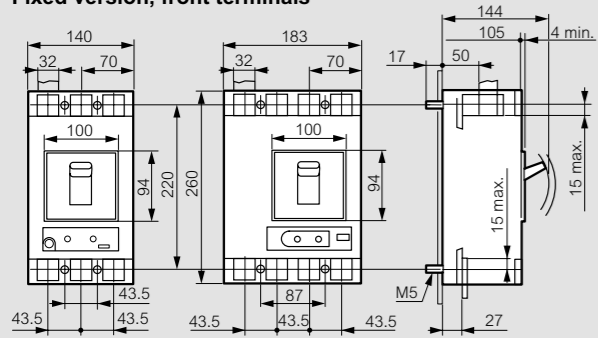



Fixed version with earth leakage module mounted underneath

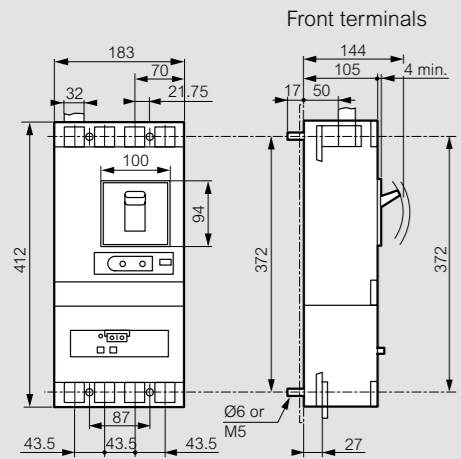



Plug-in version, front terminals

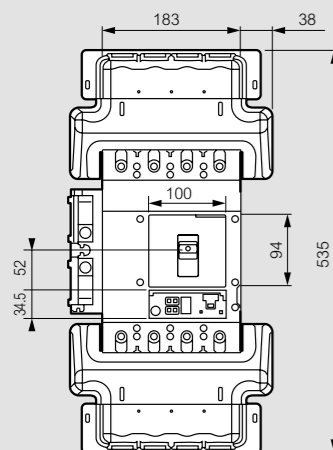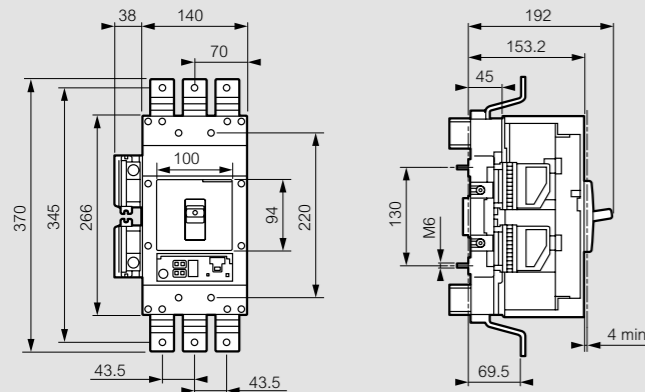




Plug-in version, rear terminals

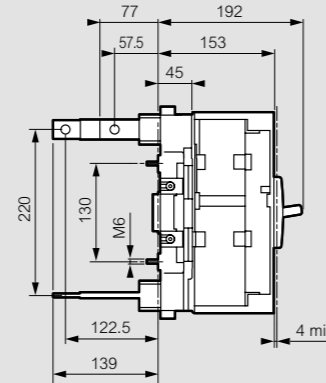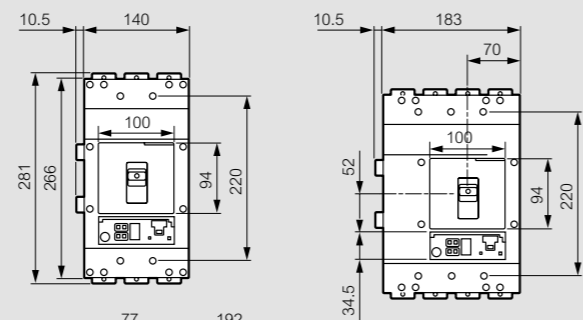


Draw-out version, front terminals

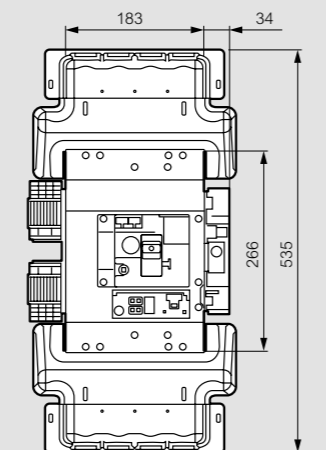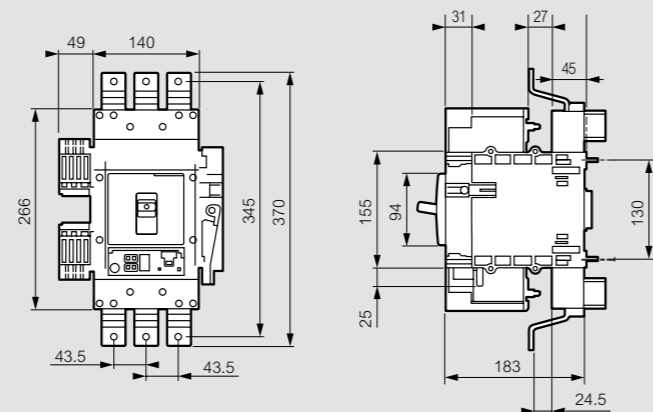


Draw-out version, rear terminals

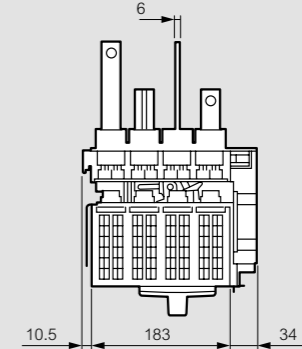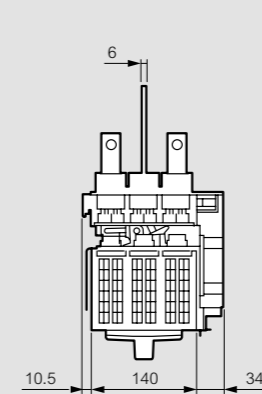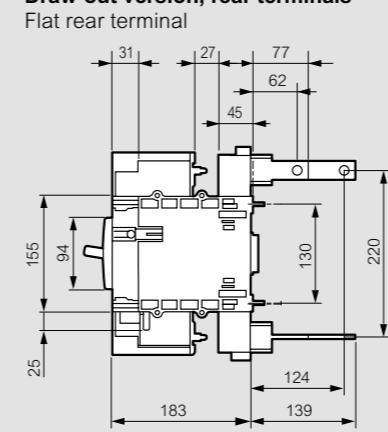

Rotary handle-direct on DPX<sup>3</sup>

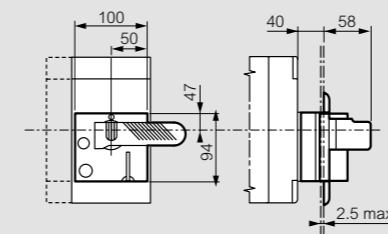


Terminal shields

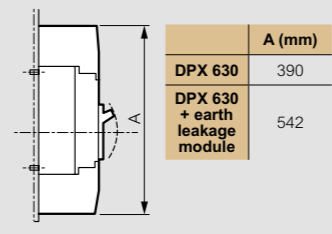

	A (mm)
DPX 630	390
DPX 630 + earth leakage module	542

Rotary handle-vari-depth handle on door

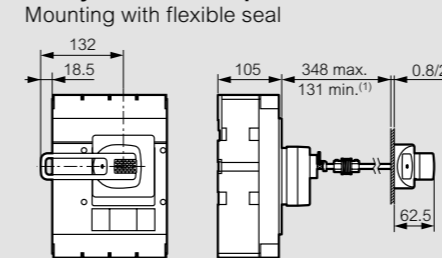

1: 75 mm without mechanical system