


# XL<sup>3</sup> S 4000

equipment for mounting DPX<sup>3</sup> 160/250 on a plate

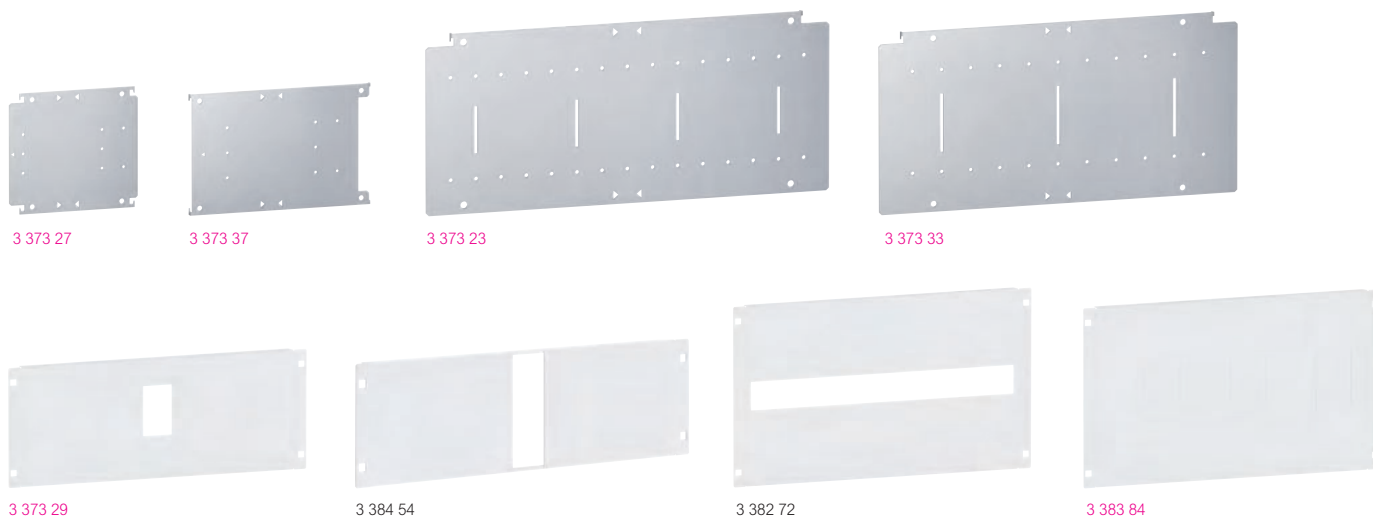

Selection chart p. 344 to 353  
Installation principle p. 368

Pack	Cat.Nos	Fixing plates for DPX <sup>3</sup> 160/250 horizontal mounting on crosspieces
1	3P/4P 3 373 27	<b>DPX<sup>3</sup> 160</b> For 24 or 36-module enclosure
1	3 373 37	<b>DPX<sup>3</sup> 250</b> For 24 and 36-module enclosure
<b>Fixing plates for DPX<sup>3</sup> 160/250 - vertical mounting on crosspieces</b>		
For devices with or without e.l.c.b and with or without rotary or motor-driven handle		
1	3P/4P 3 373 21	<b>DPX<sup>3</sup> 160 without e.l.c.b</b> For 16-module enclosure
1	3 373 23	For 24-module enclosure
1	3 373 25	For 36-module enclosure
1	4P 3 373 22	<b>DPX<sup>3</sup> 160 with e.l.c.b</b> For 16-module enclosure
1	3 373 24	For 24-module enclosure
1	3 373 26	For 36-module enclosure
1	3P/4P 3 373 31	<b>DPX<sup>3</sup> 250 without e.l.c.b</b> For 16-module enclosure
1	3 373 33	For 24-module enclosure
1	3 373 35	For 36-module enclosure
1	4P 3 373 32	<b>DPX<sup>3</sup> 250 with e.l.c.b</b> For 16-module enclosure
1	3 373 34	For 24-module enclosure
1	3 373 36	For 36-module enclosure
1	3P/4P 3 373 28	<b>DPX<sup>3</sup> 160/250 transfer switch with or without e.l.c.b</b> For 24 and 36-module enclosure

Pack	Cat.Nos	Faceplates for DPX <sup>3</sup> 160/250 and DRX 125 HP/250 HP - horizontal mounting
Fixed with 1/4 turn screws or screws		
<b>DPX<sup>3</sup> 160 with or without e.l.c.b and without rotary or motor-driven handle</b>		
Height: 200 mm		
1	3P/4P 3 373 29	For 24-module enclosure
1	3 373 30	For 36-module enclosure
<b>DPX<sup>3</sup> 250 with or without e.l.c.b and without rotary or motor-driven handle</b>		
Height: 200 mm		
1	3 384 54	For 24-module enclosure
1	3 384 57	For 36-module enclosure
<b>Faceplates for DPX<sup>3</sup> 160/250, DRX 250 HP and DPX-IS 250 - vertical mounting</b>		
Fixed with 1/4 turn screws or screws		
<b>Height 300 mm</b>		
1	3P/4P 3 382 71	For 16-module enclosure
1	3 382 72	For 24-module enclosure
1	3 382 73	For 36-module enclosure
<b>DPX<sup>3</sup> 160/250 with or without e.l.c.b and with rotary handle</b>		
Height: 300 mm		
1	3 383 83	For 16-module enclosure
1	3 383 84	For 24-module enclosure
1	3 383 85	For 36-module enclosure

