


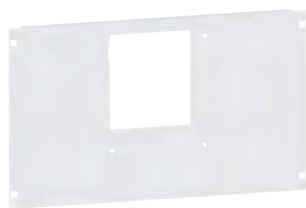

3 374 58



3 374 65



3 387 74



3 374 54



3 374 44

Selection chart p. 344 to 353  
Installation principle p. 368

Pack	Cat.Nos	Faceplates for DPX <sup>3</sup> 630 and DRX 630 - horizontal mounting on crosspieces
		Fixed with 1/4 turn screws or screws
1	3P/4P 3 374 58	<b>DRX/DPX<sup>3</sup> 630 without e.l.c.b, with or without rotary or motor driven handle, fixed version</b> Height: 300 mm For 24-module enclosure
1	3 374 59	For 36-module enclosure
1	4P 3 374 60	<b>DPX<sup>3</sup> 630 with e.l.c.b, with or without rotary or motor driven handle, fixed version,</b> Height: 300 mm For 36-module enclosure
1	3P/4P 3 374 62	<b>DPX<sup>3</sup> 630 without e.l.c.b, with or without rotary or motor driven handle, plug-in version</b> Height: 300 mm For 24-module enclosure
1	3 374 63	For 36-module enclosure
1	4P 3 374 64	<b>DPX<sup>3</sup> 630 with e.l.c.b, with or without rotary or motor driven handle, plug-in version</b> Height: 300 mm For 36-module enclosure
1	3P/4P 3 374 65	<b>DPX<sup>3</sup> 630 without e.l.c.b, with or without rotary handle, draw-out version</b> Height: 300 mm For 24-module enclosure
1	3 374 67	For 36-module enclosure
1	4P 3 374 69	<b>DPX<sup>3</sup> 630 with e.l.c.b, with or without rotary handle, draw-out version</b> Height: 300 mm For 36-module enclosure
1	3P/4P 3 374 66	<b>DPX<sup>3</sup> 630 without e.l.c.b, with motor-driven handle, draw-out version</b> Height: 300 mm For 24-module enclosure
1	3 374 68	For 36-module enclosure
1	4P 3 374 70	<b>DPX<sup>3</sup> 630 with e.l.c.b, with motor-driven handle, draw-out version,</b> Height: 300 mm For 36-module enclosure
1	3P/4P 3 374 61	<b>DPX<sup>3</sup> 630 transfer switch, fixed version</b> Height: 600 mm For 24-module enclosure
1	3P/4P 3 374 71	<b>DPX<sup>3</sup> 630 transfer switch, draw-out version,</b> Height: 600 mm For 24-module enclosure

Pack	Cat.Nos	Faceplates for DPX <sup>3</sup> 630 and DRX 630 - vertical mounting on crosspieces
		Fixed with 1/4 turn screws or screws
1	3P/4P 3 387 70	<b>DRX/DPX<sup>3</sup> 630 without e.l.c.b, with or without rotary or motor-driven handle, fixed version</b> Height: 400 mm For 16-module enclosure
1	3 387 74	For 24-module enclosure
1	3 387 77	For 36-module enclosure
1	4P 3 387 71	<b>DPX<sup>3</sup> 630 with e.l.c.b, with or without rotary or motor-driven handle, fixed version</b> Height: 600 mm For 16-module enclosure
1	3 387 75	For 24-module enclosure
1	3 387 78	For 36-module enclosure
1	3P/4P 3 383 92	<b>DRX/DPX<sup>3</sup> 630 without e.l.c.b, with rotary or motor-driven handle, fixed version</b> Height: 400 mm For 16-module enclosure
1	3 383 93	For 24-module enclosure
1	3 383 94	For 36-module enclosure
1	3P/4P 3 374 52	<b>DPX<sup>3</sup> 630 without e.l.c.b, with or without rotary or motor-driven handle, plug-in version</b> Height: 400 mm For 16-module enclosure
1	3 374 54	For 24-module enclosure
1	3 374 56	For 36-module enclosure
1	4P 3 374 53	<b>DPX<sup>3</sup> 630 with e.l.c.b, with or without rotary or motor-driven handle, plug-in version</b> Height: 600 mm For 16-module enclosure
1	3 374 55	For 24-module enclosure
1	3 374 57	For 36-module enclosure
1	3P/4P 3 374 41	<b>DPX<sup>3</sup> 630 without e.l.c.b, with or without rotary handle, draw-out version</b> Height: 400 mm For 16-module enclosure
1	3 374 44	For 24-module enclosure
1	3 374 48	For 36-module enclosure
1	4P 3 374 43	<b>DPX<sup>3</sup> 630 with e.l.c.b, with or without rotary or motor-driven handle, draw-out version</b> Height: 600 mm For 16-module enclosure
1	3 374 46	For 24-module enclosure
1	3 374 50	For 36-module enclosure
1	3P/4P 3 374 42	<b>DPX<sup>3</sup> 630 without e.l.c.b, with motor-driven handle, draw-out version</b> Height: 400 mm For 16-module enclosure
1	3 374 45	For 24-module enclosure
1	3 374 49	For 36-module enclosure

Red catalogue numbers: New products