


XL³ S 4000 - equipment for mounting DPX³ 630 and DRX 630 on a plate (continued)

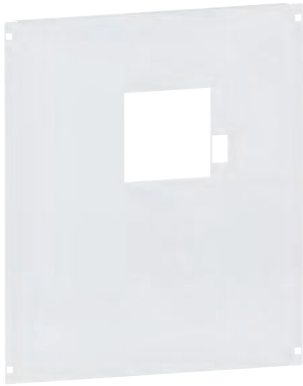

XL³ S 4000 equipment for mounting DPX-IS 630 on a plate




3 374 47




3 384 84



3 374 90

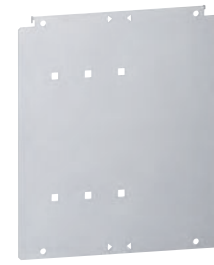

3 374 88

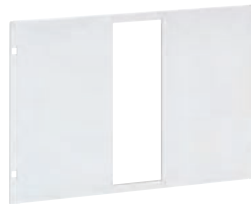

3 390 41




3 390 50

Selection chart p. 344 to 353
Installation principle p. 368

Faceplates for DPX³ 630 and DRX 630 - vertical mounting on crosspieces (continued)

Pack	Cat.Nos	Faceplates for DPX ³ 630 and DRX 630 - vertical mounting on crosspieces (continued)
1	4P 3 374 47	Fixed with 1/4 turn screws or screws DPX³ 630 with e.l.c.b, with motor-driven handle, draw-out version Height: 600 mm For 24-module enclosure For 36-module enclosure
1	3 374 51	
1	3P/4P 3 384 84	DPX³ 630 transfer switch, fixed version Height: 400 mm For 24-module enclosure For 36-module enclosure
1	3 384 85	

 

Selection chart p. 344 to 353
Installation principle p. 368

Fixing plates for DPX-IS 630 - horizontal mounting on crosspieces


Pack	Cat.Nos	Fixing plates for DPX-IS 630 - horizontal mounting on crosspieces
1	3P/4P 3 374 90	For 24 and 36-module enclosure

Fixing plates for DPX-IS 630 - vertical mounting on crosspieces

Pack	Cat.Nos	Fixing plates for DPX-IS 630 - vertical mounting on crosspieces
1	3P/4P 3 374 88	For 16-module enclosure
1	3 374 89	For 24 and 36-module enclosure

Faceplates for DPX-IS 630 - horizontal mounting on crosspieces

Pack	Cat.Nos	Faceplates for DPX-IS 630 - horizontal mounting on crosspieces
1	3P/4P 3 390 41	Fixed with 1/4 turn screws or screws Height: 300 mm For 24-module enclosure For 36-module enclosure
1	3 390 43	

 

Faceplates for DPX-IS 630 - vertical mounting on crosspieces

Pack	Cat.Nos	Faceplates for DPX-IS 630 - vertical mounting on crosspieces
1	3P/4P 3 390 50	Fixed with 1/4 turn screws or screws Height: 400 mm For 16-module enclosure For 24-module enclosure For 36-module enclosure
1	3 390 52	
1	3 390 54	

