


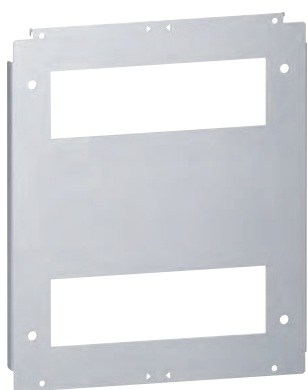

3 374 76



3 374 74



3 374 81



3 374 77






3 374 75



3 374 73

Selection chart p. 344 to 353
Installation principle p. 368

Pack	Cat.Nos	Fixing plates for DPX ³ 1600 and DPX-IS 1600 - horizontal mounting on crosspieces
1	3P/4P 3 374 75	For devices with or without rotary or motor driven handle DPX³ 1600 and DPX-IS 1600, fixed version For 24 and 36-module enclosure
1	3 374 76	DPX³ 1600 and DPX-IS 1600, draw-out version For 24 and 36-module enclosure
Fixing plates for DPX³ 1600 and DPX-IS 1600 - vertical mounting on crosspieces		
For devices with or without rotary or motor driven handle		
1	3P 3 374 72	DPX³ 1600 and DPX-IS 1600, fixed version For 16-module enclosure
1	3P/4P 3 374 73	For 24 and 36-module enclosure
1	3 374 74	DPX³ 1600 and DPX-IS 1600, draw-out version For 24 and 36-module enclosure
Faceplates for DPX³ 1600 - horizontal mounting on crosspieces		
Fixed with 1/4 turn screws or screws		
1	3P/4P 3 388 42	DPX³ 1600 with or without rotary or motor driven handle, fixed version Height: 400 mm For 24-module enclosure
1	3 388 44	For 36-module enclosure
1	3 374 81	DPX³ 1600 without rotary or motor-driven handle, draw-out version Height: 600 mm For 24-module enclosure
1	3 374 83	For 36-module enclosure
1	3 374 82	DPX³ 1600 with rotary or motor-driven handle, draw-out version Height: 600 mm For 24-module enclosure
1	3 374 84	For 36-module enclosure

   

Pack	Cat.Nos	Faceplates for DPX ³ 1600 - vertical mounting on crosspieces
Fixed with 1/4 turn screws or screws		
1	3P 3 388 50	DPX³ 1600 with or without rotary or motor-driven handle, fixed version, Height: 350 mm For 16-module enclosure
1	3P/4P 3 388 52	For 24-module enclosure
1	3 388 54	For 36-module enclosure
DPX³ 1600 without rotary or motor-driven handle, draw-out version		
Height: 600 mm		
1	3 374 77	For 24-module enclosure
1	3 374 79	For 36-module enclosure
DPX³ 1600 with rotary or motor-driven handle, draw-out version		
Height: 600 mm		
1	3 374 78	For 24-module enclosure
1	3 374 80	For 36-module enclosure
Faceplates for DPX-IS 1600 - horizontal mounting on crosspieces		
Fixed with 1/4 turn screws or screws		
1	3P/4P 3 388 62	DPX-IS 1600 fixed version Height: 400 mm For 24-module enclosure
Faceplates for DPX-IS 1600 - vertical mounting on crosspieces		
Fixed with 1/4 turn screws or screws		
1	3P 3 374 91	DPX-IS 1600 fixed version Height: 350 mm For 16-module enclosure
1	3P/4P 3 374 92	For 24-module enclosure
1	3 374 93	For 36-module enclosure

