


Equipment for XL³ 4000

for mounting on fixed plate: DPX³ 250 HP



Equipment for XL³ 4000

for mounting on fixed plate: DPX³ 630 and DPX³ 1600

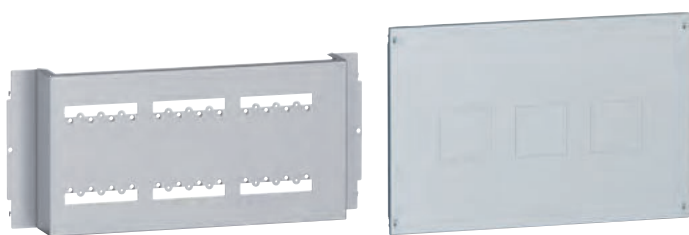

0 213 04

0 213 10



0 213 09

0 213 14

Selection chart p. 376 to 379

Plates for DPX³ 250 HP, with front terminals

Pack	Cat.Nos	Description
1	24 modules 0 213 04	Direct fixing on functional uprights
1	0 213 05	Devices in vertical position For 1 to 3 DPX ³ 250 HP
1	0 213 06	For 1 to 3 DPX ³ 250 HP with rotary handle or motor-driven handle
1	0 213 07	For 1 to 3 DPX ³ 250 HP plug-in version or for 1 to 2 DPX ³ 250 HP draw-out version
1	0 213 08	Devices in horizontal position For 1 DPX ³ 250 HP
1	0 213 09	For 1 DPX ³ 250 HP plug-in or draw-out version

Metal faceplates for devices in vertical position

1	24 modules 0 213 10 ¹	For 1 to 3 DPX ³ 250 HP fixed or plug-in version or with rotary or motor-driven handle With captive screws	
1	0 213 11	For 1 to 3 DPX ³ 250 HP draw-out version With hinges and lock	
1	0 213 12	For 2 DPX ³ 250 HP in transfer switch With captive screws	

Metal faceplates for devices in horizontal position

1	24 modules 0 213 13 ¹	For 1 DPX ³ 250 HP fixed or plug-in version With captive screws	
1	0 213 14	For 1 DPX ³ 250 HP draw-out version With hinges and lock	

1: Hinges Cat.No 0 209 59 available as an option



0 206 20

0 208 20

Selection chart p. 376 to 379

Plates for fixed version DPX³ 630/1600, with front terminals

Pack	Cat.Nos	Description
1	24 modules 0 206 20 ¹	Direct fixing on functional uprights
1	0 206 22 ¹	Devices in vertical position For 1 to 3 DPX ³ 630
1	0 211 00	For 1 to 3 DPX ³ 630 with earth leakage module
1	0 211 02	For 1 DPX IS 1600 or 1 DPX ³ 1600 front terminal
1	0 206 23	Devices in horizontal position For cut-out protection for cable passing, use seal Cat.No 0 202 40 (p. 394)
1	0 211 00	For 1 DPX ³ 630 with or without earth leakage module
1	0 211 02	For 1 DPX IS 1600 or 1 DPX ³ 1600 front terminal

Metal faceplates for devices in vertical position

1	24 modules 0 208 20 ²	For 1 to 3 DPX³ 630 only 1/4 turn With captive screws	
1	0 209 20 ³	For 1 to 3 DPX³ 630 with downstream earthleakage module 1/4 turn With captive screws	
1	0 211 10 ²	For 1 DPX³ 1600 1/4 turn With captive screws	
1	0 211 11 ³		
1	0 209 70 ³		
1	0 209 72 ³		

Metal faceplates for devices in vertical position

1	24 modules 0 208 23 ²	For 1 DPX³ 630 with or without earth leakage module without motor 1/4 turn With captive screws	
1	0 209 21 ³		
1	0 209 23 ³	For 1 DPX³ 630 with or without earth leakage module with motor With captive screws	
1	24 modules 0 208 34 ³	For 1 DPX³ 1600 1/4 turn With captive screws	
1	0 209 34 ³		
1	36 modules 0 209 84 ³		

1: For 2 DPX 630 4P
2: For fastening and sealing
3: Hinges Cat.No 0 209 59 (p. 394) available as an option