 


Equipment for XL³ 4000 - for mounting on plate: DMX³ 1600 and DMX³-I fixed or draw-out version





0 207 80




0 209 38

Selection chart p. 376 to 379
Installation principle p. 393

Pack	Cat.Nos	Fixing devices for DMX ³ 1600 and DMX ³ -I
1	0 207 80	Fixing plates for XL³ 4000 - 24 modules For 1 DMX ³ 1600 or DMX ³ -I
1	0 207 81	Fixing plates for XL³ 4000 - 36 modules For 1 or 2 DMX ³ 1600 or DMX ³ -I
1	0 207 79	Fixing plates for cable sleeve For 1 DMX ³ 1600 or DMX ³ -I
1	0 210 84	Metal faceplates for DMX³ 1600 and DMX³-I fixed and draw-out versions Width 600 mm For 1 DMX ³ 1600 or DMX ³ -I fixed version
	0 210 85	
1	0 210 86	Width 850 mm For 1 DMX ³ 1600 or DMX ³ -I fixed version
1	0 210 87	For 1 DMX ³ 1600 or DMX ³ -I draw-out version
1	0 210 88	For 2 DMX ³ 1600 or DMX ³ -I fixed version side by side
1	0 210 89	For 2 DMX ³ 1600 or DMX ³ -I draw-out version side by side
1	0 210 80	Faceplates for cable sleeve For 1 DMX ³ 1600 or DMX ³ -I fixed version
1	0 210 81	For 1 DMX ³ 1600 or DMX ³ -I draw-out version
1	0 210 82	Metal solid faceplates for cable sleeve Height (mm) 200
	0 210 83	

  

Equipment for XL³ 4000 - for mounting on plate: DMX³ 2500 and 4000 and DMX³-I fixed or draw-out version

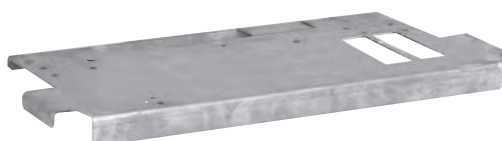

0 207 51



0 209 38

Selection chart p. 376 to 379
Installation principle p. 393

Pack	Cat.Nos	Fixing devices for DMX ³ 2500 / 4000 and DMX ³ -I
1	0 207 51	For DMX³ fixed version For 1 DMX ³ 2500/4000, N/H/L, 3P/4P, and DMX ³ -I Width 600 mm
1	0 207 52	For DMX³ fixed version For 1 DMX ³ 2500/4000, N/H/L, 3P/4P, and DMX ³ -I Width 850 mm
1	0 207 53	For DMX³ draw-out version For 1 DMX ³ 2500/4000, N/H/L, 3P/4P, and DMX ³ -I Width 600 mm
1	0 207 54	For DMX³ draw-out version For 1 DMX ³ 2500/4000, N/H/L, 3P/4P, and DMX ³ -I Width 850 mm
1	0 209 38	Metal faceplates for DMX³ 2500 / 4000 and DMX³-I fixed or draw-out version Faceplates with hinges and lock
		Width 600 mm For 1 DMX ³ 2500/4000, N/H/L, 3P, or 1 DMX ³ 2500, N/H, 4P or 1 DMX ³ -I 2500
1	0 209 39	For 1 DMX ³ -L 2500, 4P, or 1 DMX ³ 4000, N/H/L, 4P or 1 DMX ³ -I 4000
1	0 209 48	Width 850 mm For 1 DMX ³ 2500/4000, N/H/L, 3P/4P or 1 DMX ³ -I 2500/4000

