


Equipment for Atlantic metal cabinets (continued)

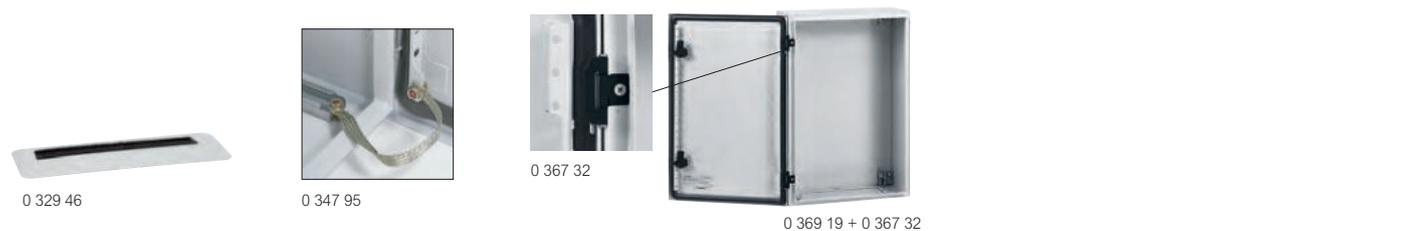

Cabinet and equipment selection chart **p. 414-415**
 Technical characteristics **p. 420-421**

Pack	Cat.Nos	Cable entries for Atlantic cabinets 600 or 800 mm width		
1	0 329 46	IP 43 cable entry plate with brush (cable feed-through 385 x 30 mm)		
		Protective conductor		
		Earth braid		
		Capacity (mm ²)	Fixing spacing (mm)	∅ of holes (mm)
20	0 347 95	6	200	8.5
20	0 347 96	16	200	8.5
10	0 347 97	30	200	8.5
20	0 363 95	Green/yellow wire		
		6	200	6.5
		Paint touch-up		
1	0 365 97	Aerosol paint spray RAL 7035 Capacity: 150 ml		
10	0 365 91	Touch-up brush For protecting the sheet metal after cutting Anti-corrosion paint RAL 7035 Other colours on request		
10	0 395 99	Temporary marking Water-soluble marker pen		
1	0 367 32	180° hinges RAL 7016 Enable 180° cabinet doors opening without drilling, by replacing existing hinges IP of the cabinet maintained Kit of 2 hinges for Atlantic metal cabinets For 1-door or 2-door cabinets up to 600 mm height For 2-door cabinets order 2 kits		
1	0 367 33	Kit of 3 hinges for Atlantic metal cabinets For 1-door or 2-door cabinets form 700 mm height upwards For 2-door cabinets order 2 kits		

Pack	Cat.Nos	Accessories	
1	0 367 43	Set of 4 slides for depth adjustment For 250 mm depth cabinets (starting with 600 mm width x 600 mm height cabinets)	
1	0 367 44	For 300 mm depth cabinets	
1	0 367 45	For 400 mm depth cabinets	
		Wall-mounting lugs (set of 4)	
		For load up to 300 kg Zamak RAL 7035 Horizontal or vertical installation With a roof, horizontal installation only	
1	0 364 01	Supplied with cover finish	
1	0 364 04	Anti-corrosion steel treatment	
5	0 367 35	Attachment lugs for rail	
		Used to attach the 15 mm depth symmetric rail	
		on door profile strand-holder	
		Supplied with M6 screws	
		Set of 2	