


Equipment for Marina enclosures

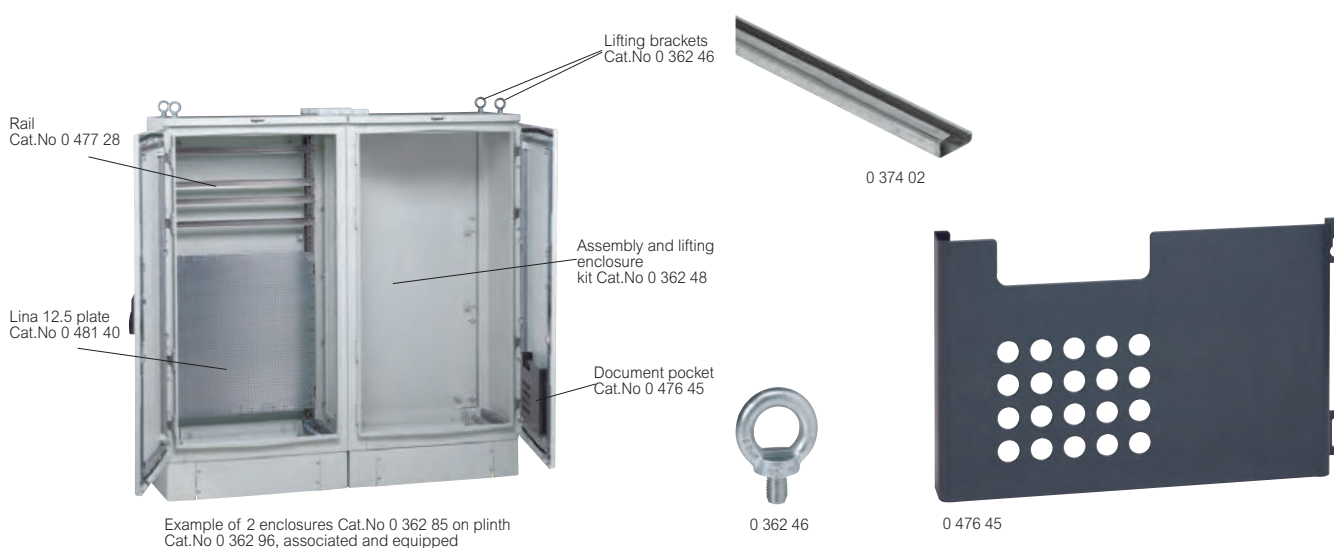

Example of 2 enclosures Cat.No 0 362 85 on plinth Cat.No 0 362 96, associated and equipped

Pack	Cat.Nos	Equipment
		Plain plates Galvanized steel. Pre-marked pitch 100 mm Admissible load: 200 kg/m ²
		For enclosures
		Height x Width (mm) Net weight (kg)
1	0 349 59	1400 x 800 27
1	0 349 50	1600 x 800 30.5
1	0 344 18	1800 x 800 34
		Lina 12.5 plates Galvanized steel With drilling for fixing equipment without marking Automatic bracket: - Ø6.5 mm for plastic rivet Cat.No 0 366 44 (trunking) - Ø3.3 mm for equipment with screw Cat.No 0 347 45 For installation of Cat. No 0 481 40/43, use Lina 25 sectionned uprights (p. 431) Cat. No 0 364 08 can be fixed directly on the back of the enclosure (1400 mm height enclosures) Admissible load: 150 kg/m ²
		Plates Net weight (kg)
		Height x Width (mm)
1	0 481 40	800 x 800 5.9
1	0 481 43	1000 x 800 7.6
1	0 346 08	1400 x 800 14.6
		Lina 25 perforated plates Zinc steel For mounting with sectionned uprights (except plain plate Cat.No 0 346 09) Admissible load: 50 kg/m ²
		Plates Net weight (kg)
		Height x Width (mm)
1	0 474 90	800 x 800 3.9
1	0 474 95	1000 x 800 5
1	0 346 09	1400 x 800 6.7
		Internal doors RAL 7035 IP xxB steel. Textured polyester coated steel Double bar lock. Take key barrels and other knockouts (p. 438) Distance between enclosure door and internal door 78 mm Right or left opening, handle included
		For cabinets Door dim. (mm) Door usable dim. (mm)
		Height x Width (mm) Height x Width Height x Width
1	0 363 66	1400 x 800 1280 x 675 1200 x 580
1	0 363 67	1600 x 800 1480 x 675 1400 x 580
1	0 363 68	1800 x 800 1680 x 675 1600 x 580

Pack	Cat.Nos	Screws
500	0 366 44	Rivet reinforced plastic Ø6 mm for drilling Ø6.5 mm
100	0 347 45	Screw head H 4.8 x 16 mm self-drilling, self-tapping for Ø3.3 mm
200	0 347 50	Screw caps for isolation of screw head Cat.No 0 347 45 inside the trunking
		Sectionned uprights For Lina 25 rail, Lina rail and Lina 12.5 or Lina 25 plates Set of 2 uprights galvanized steel
		For enclosures Length (mm)
		Height (mm)
1	0 363 92	1800 1684
		Rails
		Lina 25 rail Galvanized steel For enclosures width 800 mm Lina 15 mm depth
5	0 477 28	
		Rail to be cut EN 60715 Length: 2 m
10	0 374 02	
		Lifting accessories
1	0 362 46	Lifting brackets M14 Set of 4 brackets for max. load 500 kg/m ³ Supplied with blanking plates
1	0 362 48	Assembly and lifting enclosures kit: - 2 support brackets - screws - weatherproof seal For 500 kg/m ³ lifting, order separately one set of 4 brackets Cat.No 0 362 46
		Metal document holder (for plans) RAL 7012. Fixed on door width 600/800/1000 mm Internal dimensions: W. 425 x H. 275 x D. 50 mm For A3 format documents
1	0 476 45	



Legrand custom made ranges
Please, consult your Area Commercial Manager

