


# Atlantic, Atlantic stainless steel and Marina cabinets: plain plates and perforated plates

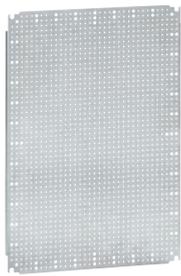

0 360 58



0 360 31



0 360 18



Lina 12.5 plate  
Cat.No 0 360 22 vertical  
mounting inside Atlantic  
enclosure Cat.No 0 369 26



Lina 12.5 plate Cat.No 0 360 22  
horizontal mounting inside Atlantic  
enclosure Cat.No 0 369 77

Cabinet and equipment selection chart **p. 414-415**  
Technical characteristics **p. 430**

Pack	Cat.Nos	Plain plates				
		Galvanized steel			Horizontal mounting for cabinets	
		Vertical mounting for cabinets			Horizontal mounting for cabinets	
		Height (mm)	Width (mm)	Weight (kg)	Height (mm)	Width (mm)
1	0 360 50 <sup>2</sup>	300	200	0.6		
1	0 360 49 <sup>1</sup>	300	220	0.9		
1	0 360 69	300	300	1		
1	0 360 52	400	300	1.3	300	400
1	0 360 70	400	400	1.7		
1	0 360 55	500	400	2.7		
1	0 360 71	500	500	3.5		
1	0 360 56	600	400	3.3	400	600
1	0 360 84	600	500	4.9		
1	0 360 57	600	600	6.2		
1	0 360 54	600	1000	10.6	1000	600
1	0 360 58	700	500	6		
1	0 360 59	800	600	8.4	600	800
1	0 360 60	800	800	11.4		
1	0 360 61	800	1000	14.4	1000	800
1	0 360 85	1200	600	12.1		
1	0 360 64	1200	800	18.5		
1	0 360 65	1200	1000	23	1000	1200
1	0 360 67 <sup>2</sup>	1400	800	26.4		

Pack	Cat.Nos	Lina 12.5 plates				
		Galvanized steel.				
		With drilling for fixing equipment without marking.				
		Automatic bracket:				
		- Ø6.5 mm for plastic rivet Cat.No 0 366 44 (trunking)				
		- Ø3.3 mm for equipment with screw Cat.No 0 347 45				
		Vertical mounting for cabinets			Horizontal mounting for cabinets	
		Height (mm)	Width (mm)	Weight (kg)	Height (mm)	Width (mm)
1	0 360 00 <sup>2</sup>	300	200	0.4		
1	0 360 01 <sup>1</sup>	300	220	0.47		
1	0 360 02	300	300	0.6		
1	0 360 04	400	300	0.8	300	400
1	0 360 05	400	400	1.1		
1	0 360 09	500	400	1.5		
1	0 360 14	500	500	1.85		
1	0 360 22	600	400	2.2	400	600
1	0 360 24	600	600	3.7		
1	0 360 40	600	1000	6.8	1000	600
1	0 360 31	700	500	3.7		
1	0 360 33	800	600	5.2	600	800
1	0 360 34	800	800	7		
1	0 360 42	1000	800	9.2	800	1000
1	0 360 46	1200	800	11.1		
1	0 360 47	1200	1000	13.9	1000	1200
1	0 360 75 <sup>2</sup>	1400	800	13		

Pack	Cat.Nos	Lina 25 perforated plates	
		Galvanized steel	
		<b>Common for all types of cabinets</b>	
		For cabinets	Weight
		Height x Width (mm)	(kg)
1	0 360 07 <sup>2</sup>	300 x 200	0.4
1	0 360 99 <sup>1</sup>	300 x 220	0.4
1	0 360 91	300 x 300	0.5
1	0 360 11	300 x 400	0.6
1	0 360 12	400 x 300	0.6
1	0 360 92	400 x 400	0.8
1	0 360 13	400 x 600	1.1
1	0 360 15	500 x 400	0.9
1	0 360 93	500 x 500	1.1
1	0 360 16	600 x 400	1.3
1	0 360 17	600 x 600	2.1
1	0 360 06	600 x 800	3.1
1	0 360 08	600 x 1000	3.7
1	0 360 18	700 x 500	2
1	0 360 19	800 x 600	3.1
1	0 360 20	800 x 800	4
1	0 360 94	800 x 1000	5
1	0 360 23	1000 x 600	3.7
1	0 360 21	1000 x 800	4.9
1	0 360 10	1000 x 1200	8.5
1	0 360 87	1200 x 800	7.1
1	0 360 90 <sup>2</sup>	1400 x 800	7.8
		<b>Clip-nuts for perforated plates</b>	
		Supplied without screw	
100	0 364 40	For M4 screws	
100	0 364 41	For M5 screws	
100	0 364 42	For M6 screws	

Pack	Cat.Nos	Accessories
500	0 366 44	Rivet reinforced plastic Ø6 mm for drilling Ø6.5 mm
100	0 347 45	Screw head 4.8 x 16 mm self-drilling, self-tapping for Ø3.3 mm
200	0 347 50	Screw cover for isolation of screw head Cat.No 0 347 45 inside the trunking

1: For Marina cabinets  
2: For Atlantic