

# Atlantic, Atlantic stainless steel and Marina cabinets

 
 
 
 


 
 
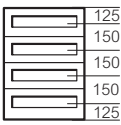
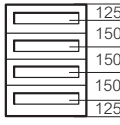
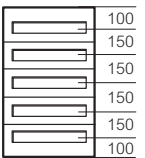
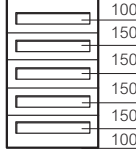
ready-to-use chassis



Marina cabinet 0 362 55 + plastic chassis Cat.No 4 330 03



Atlantic cabinet with glass door Cat.No 0 369 36 + metal chassis Cat.No 4 330 13

Pack	Cat.Nos	Chassis with plastic faceplates RAL 7035	Pack	Cat.Nos	Chassis with metal faceplates RAL 7035
1	4 330 00	<p>Supplied complete with U rails depth 15 mm, functional and faceplate support uprights, and faceplates Self-extinguishing at 750°C according to standard EN/IEC 60695-2-11 Individual faceplates, height 150 mm The chassis frame can be removed for wiring outside the cabinet Suitable for all cabinet depths For Atlantic, Atlantic stainless steel and Marina cabinets</p> <p><b>For cabinets 400 x 300 mm</b> 30 modules (3 rows of 10) Supplied with 1 blanking plate</p> 	1	4 330 10	<p>Supplied complete with U rails depth 15 mm, functional and faceplate support uprights, and faceplates Self-extinguishing at 750°C according to standard EN/IEC 60695-2-11 Monobloc faceplates The chassis frame can be removed for wiring outside the cabinet Suitable for all cabinet depths For Atlantic and Atlantic stainless steel cabinets</p> <p><b>For cabinets 400 x 300 mm</b> 30 modules (3 rows of 10) Supplied with 1 blanking plate</p> 
1	4 330 01	<p><b>For cabinets 500 x 400 mm</b> 48 modules (3 rows of 16) Supplied with 1 blanking plate</p> 	1	4 330 11	<p><b>For cabinets 500 x 400 mm</b> 48 modules (3 rows of 16) Supplied with 1 blanking plate</p> 
1	4 330 02	<p><b>For cabinets 500 x 500 mm</b> 63 modules (3 rows of 21) Supplied with 1 blanking plate</p> 	1	4 330 12	<p><b>For cabinets 500 x 500 mm</b> 63 modules (3 rows of 21) Supplied with 1 blanking plate</p> 
1	4 330 03	<p><b>For cabinets 600 x 400 mm</b> 48 modules (3 rows of 16) Supplied with 1 blanking plate</p> 	1	4 330 13	<p><b>For cabinets 600 x 400 mm</b> 48 modules (3 rows of 16) Supplied with 1 blanking plate</p> 
1	4 330 04	<p><b>For cabinets 700 x 500 mm</b> 84 modules (4 rows of 21) Supplied with 2 blanking plates</p> 	1	4 330 14	<p><b>For cabinets 700 x 500 mm</b> 84 modules (4 rows of 21) Supplied with 2 blanking plates</p> 
1	4 330 05	<p><b>For cabinets 800 x 600 mm</b> 135 modules (5 rows of 27) Supplied with 2 blanking plates</p> 	1	4 330 15	<p><b>For cabinets 800 x 600 mm</b> 135 modules (5 rows of 27) Supplied with 2 blanking plates</p> 
10	0 361 00	<p><b>Blanking plate</b> 38 modules, length 684 mm</p>			