



IP 68 CABLE GLANDS

Quick, simple & hermetic tightening cable glands

A wide range of ISO and PG plastic or metal cable glands, able to ensure the protection and clamping of cables and perfectly adapted to industrial environments and applications.



IP 68 metal cable glands

See p. 445



Grey RAL 7001 IP 68 plastic cable glands supplied with locking nuts


See p. 446



Black RAL 9011 IP 68 plastic cable glands supplied without locking nuts

See p. 446

Atlantic, Atlantic stainless steel and Marina cabinets internal doors

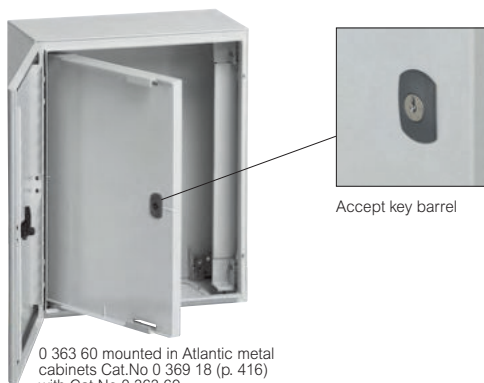

0 363 60 mounted in Atlantic metal cabinets Cat.No 0 369 18 (p. 416) with Cat.No 0 363 69

Cabinet and equipment selection chart p. 414-415

Pack	Cat.Nos	Insulating internal doors RAL 7035		
		For direct routing in Marina and Atlantic stainless steel cabinets, with Cat.No 0 363 69 in Atlantic metal cabinets IP XXB Polyester fiber glass reinforced, height 4 mm Self-extinguishing 960°C acc. to IEC EN 60695-2-11 Grid lines integrated on back Centre marking on front Adjustable distance between cabinet door and internal door: 42 to 50 mm for Atlantic cabinets, more than 100 mm for Marina cabinets Right or left opening, captive hinge pins Double bar key: 1 key for 400 to 600 mm height, 2 keys for height from 700 mm Take key barrels and other barrels		
		For cabinets Height x Width(mm)	Dim. (mm) Height x Width	Usable dim. (mm) Height x Width
1	0 363 59	400 x 300	341 x 236	306 x 205
1	0 363 60	500 x 400	441 x 336	406 x 270
1	0 363 61	600 x 400	541 x 336	505 x 270
1	0 363 62	700 x 500	642 x 436	500 x 360
1	0 363 63	800 x 600	742 x 536	600 x 460
1	0 363 64	1000 x 800	942 x 736	800 x 660
1	0 363 65	1200 x 800	942 x 736	800 x 660