


Uprights, rails and fixing accessories for cabinets and enclosures

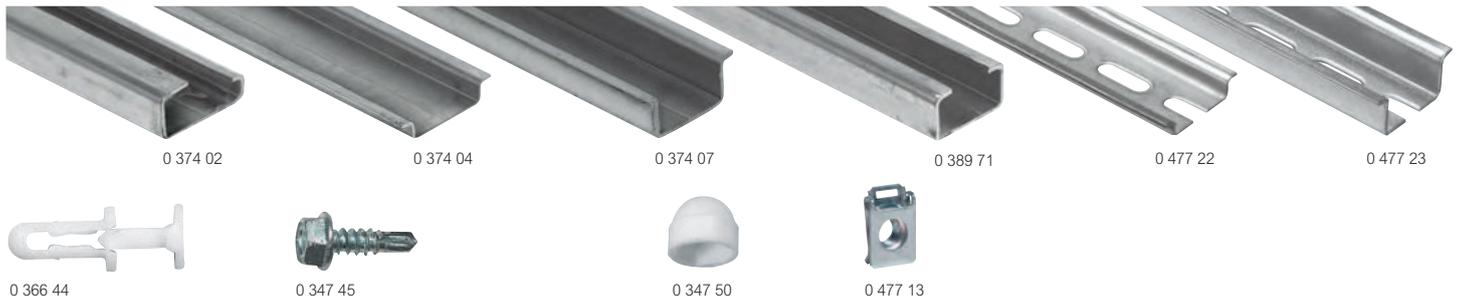

For mounting chassis and fixing wiring accessories

Pack	Cat.Nos	Uprights to be cut	Pack	Cat.Nos	Fixing accessories (continued)
10	0 361 92	Lina 25 Length: 3 m - L Section	20	0 364 66	Adaptor For mounting on rail □ equipment fitting on rail □ Width 17 mm Increase equipment height of 6 mm
10	0 389 71	On C profile rail □ Section Length: 2 m	100	0 364 78	On rails EN 60 715 □ □ For M4 screws
10	0 374 02	Rails to be cut Length 2 m □ EN 60 715	100	0 364 79	For M6 screws
10	0 374 04	□ EN 60 715 depth 7.5 mm	10	0 044 16	On rails EN 60 715 □ Claw width 10 mm Threaded hole for M4 screw
10	0 374 07	□ depth 15 mm	50	0 044 17	Claw width 17.5 mm Smooth hole 3.8 mm Supplied with fixing screw Ø3.5 mm Length 13 mm
10	0 389 71	□ Section	100	0 374 39	Claw width 35 mm Holes for M4 and M6 screws
10	0 477 22	□ depth 7.5 mm with oblongs	40	0 364 69	Fixomega for M4 screws
10	0 477 23	□ depth 15 mm with oblongs	100	0 364 82	On C profile rail Stirrup for M6 screws
10	0 394 49	45° mounting bracket Set of 2 supports for 45° rail slope Supplied with 4 M6 screws Ø6 mm, nuts and washers	20	0 367 60	Nut with CBL screw 6 x 10
100	0 347 46	Fixing accessories On plain plates CBL Z 5.5 x 16 PZ No 3 self-tapping screw	20	0 364 50	Cage nuts For mounting on square perforation 8.3 x 8.3 mm M4
100	0 347 47	CBL Z 5.5 x 19 self-drilling tapping screw	20	0 364 51	M5
500	0 366 44 ¹	On Lina 12.5 plates Rivet reinforced plastic Ø6 mm for drilling Ø6.5 mm	20	0 364 52	M6
100	0 347 45	Screw head H 4.8 x 16 mm self-drilling, self-tapping for Ø3.3 mm	50	0 367 75	HF screw with contact washer M 6-10 HF screws with contact washers
200	0 347 50	Screw caps for isolation of screw head Cat.No 0 347 45			
100	0 364 40	On Lina 25 perforated plates Clip-nuts supplied without screw			
100	0 364 41	For M4 screws			
100	0 364 42	For M5 screws			
50	0 477 12	On cabinet frame and crosspieces Clip-nuts with pins which provide earth continuity			
50	0 477 13	For M6 screws			
100	0 364 61	On rails EN 60 715 □ Fixobar for M4 screws			
100	0 364 62	Fixobar for M5 screws			
100	0 364 63	Fixobar for M6 screws			

1: Can also be used on Lina 25 perforated plate